

サンコータイト ⊕ Sタイプトラス



30000003

鉄

30020003


ステンレス

30030003

SUS 410

30190003

SUS ASL516

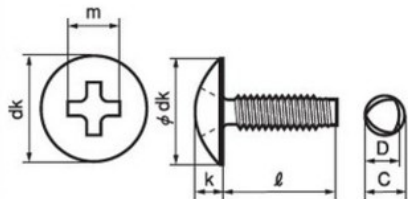

ねじの 呼び	ピッチ	dk		k		十字穴				ねじ径			
		基準 寸法	許容差	基準 寸法	許容差	m	Q		十字穴	C		D	
							最大	最大		最小	最大	最小	最大
2	0.4	4.5	0 -0.4	1.20	±0.1	2.2	1.21	0.85	1	2.03	1.95	1.95	1.87
2.3	0.4	5.2		1.40		2.7	1.52	1.14		2.33	2.25	2.25	2.17
2.6	0.45	5.9		1.60		2.9	1.72	1.34		2.64	2.56	2.55	2.47
3	0.5	6.9	0 -0.5	1.90	±0.15	3.2	1.63	1.11		2	3.04	2.96	2.94
3.5	0.6	8.1		2.20		4.3	2.13	1.60	3.55		3.47	3.43	3.35
4	0.7	9.4		2.50		4.7	2.53	1.99	4.06		3.98	3.92	3.84
5	0.8	11.8	0 -0.6	3.1		4.7	2.53	1.99	5.08		5.00	4.92	4.84

2.0				
長さ	入り数	鉄	ステンレス	ニッケル
4	16000×10	●	●	●
5	12000×10	●	●	●
6	12000×10	●	●	●
8	10000×10	●	●	●
10	8000×10	●	●	●

3.0														
長さ	入り数	クロメート	クロメイト	三価クロム	ニッケル	クロム	亜鉛黒	ステンレス	黒ニッケル	三価クロム	クロム	クロム	クロム	クロム
4	6000×10	●	●	●	●	●	●	●	●	●	●	●	●	●
5	5000×10	●	●	●	●	●	●	●	●	●	●	●	●	●
6	2000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
6	5000×10	●	●	●	●	●	●	●	●	●	●	●	●	●
8	2000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
8	4000×10	●	●	●	●	●	●	●	●	●	●	●	●	●
10	1500×20	●	●	●	●	●	●	●	●	●	●	●	●	●
10	3500×10	●	●	●	●	●	●	●	●	●	●	●	●	●
12	1500×20	●	●	●	●	●	●	●	●	●	●	●	●	●
12	3000×10	●	●	●	●	●	●	●	●	●	●	●	●	●

4.0														
長さ	入り数	クロメート	クロメイト	三価クロム	ニッケル	クロム	亜鉛黒	ステンレス	黒ニッケル	三価クロム	クロム	クロム	クロム	クロム
5	2000×10	●	●	●	●	●	●	●	●	●	●	●	●	●
6	1000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
6	2000×10	●	●	●	●	●	●	●	●	●	●	●	●	●
8	1000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
8	2000×10	●	●	●	●	●	●	●	●	●	●	●	●	●
10	1000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
10	1500×10	●	●	●	●	●	●	●	●	●	●	●	●	●
12	1500×10	●	●	●	●	●	●	●	●	●	●	●	●	●
12	500×20	●	●	●	●	●	●	●	●	●	●	●	●	●
14	1500×10	●	●	●	●	●	●	●	●	●	●	●	●	●
14	500×20	●	●	●	●	●	●	●	●	●	●	●	●	●
16	1000×10	●	●	●	●	●	●	●	●	●	●	●	●	●
16	500×20	●	●	●	●	●	●	●	●	●	●	●	●	●
18	1000×10	●	●	●	●	●	●	●	●	●	●	●	●	●
20	1000×10	●	●	●	●	●	●	●	●	●	●	●	●	●
20	500×20	●	●	●	●	●	●	●	●	●	●	●	●	●

5.0														
長さ	入り数	クロメート	クロメイト	三価クロム	ニッケル	クロム	亜鉛黒	ステンレス	黒ニッケル	三価クロム	クロム	クロム	クロム	クロム
8	800×10	●	●	●	●	●	●	●	●	●	●	●	●	●
10	500×20	●	●	●	●	●	●	●	●	●	●	●	●	●
10	800×10	●	●	●	●	●	●	●	●	●	●	●	●	●
12	500×20	●	●	●	●	●	●	●	●	●	●	●	●	●
12	800×10	●	●	●	●	●	●	●	●	●	●	●	●	●
14	700×10	●	●	●	●	●	●	●	●	●	●	●	●	●
16	700×10	●	●	●	●	●	●	●	●	●	●	●	●	●
18	700×10	●	●	●	●	●	●	●	●	●	●	●	●	●
20	600×10	●	●	●	●	●	●	●	●	●	●	●	●	●