

サンコータイト ⊕ Bタイプ ナベ




30001000

鉄

30021000

ステンレス

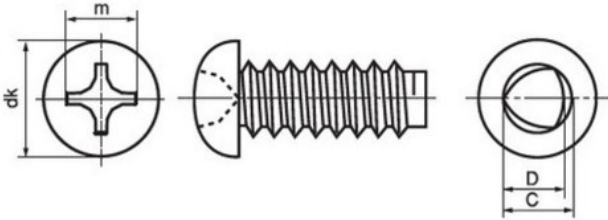

ねじの呼び	ピッチ (山/寸)	dk		k		十字穴			ねじ径				
		基準寸法	許容差	基準寸法	許容差	m		十字穴	C		D		
						最大	最小		最大	最小	最大	最小	
2	40	3.5	0 -0.4	1.3	±0.1	2.2	1.01	0.60	1	2.03	1.95	1.95	1.87
2.3	32	4.0		1.5		2.4	1.21	0.80		2.33	2.25	2.25	2.17
2.5	28	4.5		1.7		2.6	1.42	1.00		2.54	2.46	2.45	2.37
2.6	28	4.5		1.7		2.6	1.42	1.00		2.63	2.55	2.54	2.46
3	24	5.5	0 -0.5	2.0	±0.15	3.5	1.43	0.86	2	3.04	2.94	2.94	2.84
3.5	20	6.0		2.3		3.8	1.73	1.15		3.54	3.44	3.45	3.33
4	18	7.0		2.6		4.1	2.03	1.45		4.04	3.94	3.90	3.80
5	16	9.0		-0.6		3.3	4.8	2.73		2.14	5.06	4.94	4.9
6	14	10.50	0 -0.7	3.9	±0.20	6.3	2.86	2.26	3	6.08	5.92	5.88	5.72

2.0															
長さ	入り数	鉄										ステンレス			
		ユテロ	クロメート	三価ホウフタ	三価フッソ	ニッケル	クロム	亜鉛黒	黒ツヤ	メッキ	セロクロムS	メッキ	メッキ	生地	B5 (ステンレス)
3	20000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
4	10000×20													●	●
4	20000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5	18000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5	8000×20													●	●
6	16000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	7000×20													●	●
8	12000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	6000×20													●	●
10	10000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	5000×20													●	●
12	8000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
14	7000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	6000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●

2.3															
長さ	入り数	鉄										ステンレス			
		ユテロ	クロメート	三価ホウフタ	三価フッソ	ニッケル	クロム	亜鉛黒	黒ツヤ	メッキ	セロクロムS	メッキ	メッキ	生地	B5 (ステンレス)
4	16000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5	10000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	12000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	4000×20													●	●
8	10000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	3000×20													●	●
10	3000×20													●	●
10	8000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	7000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●

2.5															
長さ	入り数	鉄										ステンレス			
		ユテロ	クロメート	三価ホウフタ	三価フッソ	ニッケル	クロム	亜鉛黒	黒ツヤ	メッキ	セロクロムS	メッキ	メッキ	生地	B5 (ステンレス)
5	10000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	8000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	7000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	5000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	5000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●

2.6															
長さ	入り数	鉄										ステンレス			
		ユテロ	クロメート	三価ホウフタ	三価フッソ	ニッケル	クロム	亜鉛黒	黒ツヤ	メッキ	セロクロムS	メッキ	メッキ	生地	B5 (ステンレス)
4	10000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
4	5000×20													●	●
5	10000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5	5000×20													●	●
6	4000×20													●	●
6	8000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	3000×20													●	●
8	7000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	3000×20													●	●
10	6000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	2500×20													●	●
12	5000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
14	4000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	4000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
18	3000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●
20	2500×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●