

サンコータイト ⊕ Bタイプ 皿




30001001

鉄

30021001

ステンレス

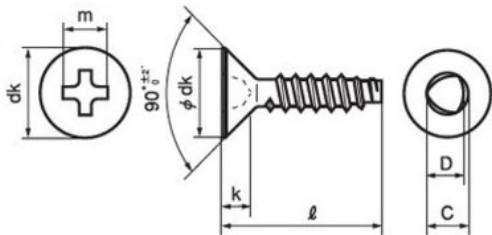

ねじの 呼び	ピッチ (山／寸)	dk		k		十字穴				ねじ径				
		基準 寸法	許容差	基準 寸法	許容差	m		Q		十字穴	C		D	
						最大	最大	最小	最大		最小	最大	最小	
2	40	4.0	0 －0.4	1.20	0 －0.2	2.2	1.01	0.65	1	2.03	1.95	1.95	1.87	
2.3	32	4.6		1.35		2.4	1.21	0.85		2.33	2.25	2.25	2.17	
2.6	28	5.2		1.50		2.6	1.42	1.05		2.63	2.55	2.54	2.46	
3	24	6.0	0	1.75	0 －0.3	3.6	1.43	0.91	2	3.04	2.94	2.94	2.84	
3.5	20	7.0	－0.5	2.00		4.1	1.93	1.40		3.54	3.44	3.45	3.33	
4	18	8.0	0 －0.6	2.30		4.5	2.33	1.79		4.04	3.94	3.90	3.80	

2.0													
長さ	入り数	鉄	鉄	鉄	鉄	鉄	鉄	鉄	鉄	鉄	鉄	鉄	鉄
		クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム
4	20000×10	●	●	●	●	●	●	●	●	●	●	●	●
5	20000×10	●	●	●	●	●	●	●	●	●	●	●	●
6	18000×10	●	●	●	●	●	●	●	●	●	●	●	●
8	14000×10	●	●	●	●	●	●	●	●	●	●	●	●
10	10000×10	●	●	●	●	●	●	●	●	●	●	●	●
12	8000×10	●	●	●	●	●	●	●	●	●	●	●	●
14	7000×10	●	●	●	●	●	●	●	●	●	●	●	●
16	6000×10	●	●	●	●	●	●	●	●	●	●	●	●
20	5000×10	●	●	●	●	●	●	●	●	●	●	●	●

2.3													
長さ	入り数	鉄	鉄	鉄	鉄	鉄	鉄	鉄	鉄	鉄	鉄	鉄	鉄
		クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム
6	15000×10	●	●	●	●	●	●	●	●	●	●	●	●
8	10000×10	●	●	●	●	●	●	●	●	●	●	●	●

2.6													
長さ	入り数	鉄	鉄	鉄	鉄	鉄	鉄	鉄	鉄	鉄	鉄	鉄	鉄
		クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム
5	12000×10	●	●	●	●	●	●	●	●	●	●	●	●
6	10000×10	●	●	●	●	●	●	●	●	●	●	●	●
8	3000×20	●	●	●	●	●	●	●	●	●	●	●	●
8	8000×10	●	●	●	●	●	●	●	●	●	●	●	●
10	7000×10	●	●	●	●	●	●	●	●	●	●	●	●
12	5000×10	●	●	●	●	●	●	●	●	●	●	●	●

3.0													
長さ	入り数	鉄	鉄	鉄	鉄	鉄	鉄	鉄	鉄	鉄	鉄	鉄	鉄
		クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム
5	8000×10	●	●	●	●	●	●	●	●	●	●	●	●
6	3000×20	●	●	●	●	●	●	●	●	●	●	●	●
6	8000×10	●	●	●	●	●	●	●	●	●	●	●	●
8	2000×20	●	●	●	●	●	●	●	●	●	●	●	●
8	6000×10	●	●	●	●	●	●	●	●	●	●	●	●
10	2000×20	●	●	●	●	●	●	●	●	●	●	●	●
10	5000×10	●	●	●	●	●	●	●	●	●	●	●	●
12	4000×10	●	●	●	●	●	●	●	●	●	●	●	●
14	3500×10	●	●	●	●	●	●	●	●	●	●	●	●
16	3000×10	●	●	●	●	●	●	●	●	●	●	●	●
18	2000×10	●	●	●	●	●	●	●	●	●	●	●	●

4.0													
長さ	入り数	鉄	鉄	鉄	鉄	鉄	鉄	鉄	鉄	鉄	鉄	鉄	鉄
		クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム
8	3500×10	●	●	●	●	●	●	●	●	●	●	●	●
10	1200×20	●	●	●	●	●	●	●	●	●	●	●	●
10	2500×10	●	●	●	●	●	●	●	●	●	●	●	●
12	2500×10	●	●	●	●	●	●	●	●	●	●	●	●
14	2000×10	●	●	●	●	●	●	●	●	●	●	●	●
16	1500×10	●	●	●	●	●	●	●	●	●	●	●	●