

サンコータイト ⊕ Bタイプトラス




30001003

鉄

30021003

ステンレス

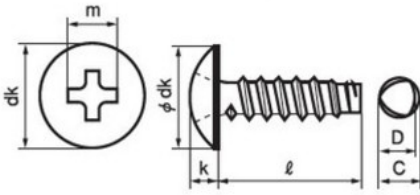

ねじの呼び	ピッチ (山/寸)	dk		k		十字穴			ねじ径				
		基準寸法	許容差	基準寸法	許容差	m		十字穴の番号	C		D		
						最大	最小		最大	最小	最大	最小	
2	40	4.5	0 -0.4	1.20	±0.1	2.2	1.21	0.85	1	2.03	1.95	1.95	1.87
2.3	32	5.2		1.40		2.7	1.52	1.14		2.33	2.25	2.25	2.17
2.6	28	5.9		1.60		2.9	1.72	1.34		2.63	2.55	2.54	2.46
3	24	6.9	0 -0.5	1.90	±0.15	3.2	1.63	1.11	2	3.04	2.94	2.94	2.84
3.5	20	8.1		2.20		4.3	2.13	1.60		3.54	3.44	3.45	3.33
4	18	9.4		2.50		4.7	2.53	1.99		4.04	3.94	3.90	3.80
5	16	11.8	0 -0.6	3.1		4.7	2.53	1.99		5.06	4.94	4.90	4.78

長さ		2.0												
長さ	入り数	鉄												
		クロロ	クロメート	三価ホウ酸	三価フッ素	ニッケル	クロム	亜鉛黒	ステンコート	黒マニル	三価ホウ酸	三価フッ素	セロロムS	セロロムS
4	16000×10	●	●	●	●	●	●	●	●	●	●	●	●	●
5	12000×10	●	●	●	●	●	●	●	●	●	●	●	●	●
6	12000×10	●	●	●	●	●	●	●	●	●	●	●	●	●
8	10000×10	●	●	●	●	●	●	●	●	●	●	●	●	●
10	8000×10	●	●	●	●	●	●	●	●	●	●	●	●	●

長さ		3.0												
長さ	入り数	鉄												
		クロロ	クロメート	三価ホウ酸	三価フッ素	ニッケル	クロム	亜鉛黒	ステンコート	黒マニル	三価ホウ酸	三価フッ素	セロロムS	セロロムS
4	6000×10	●	●	●	●	●	●	●	●	●	●	●	●	●
5	5000×10	●	●	●	●	●	●	●	●	●	●	●	●	●
6	5000×10	●	●	●	●	●	●	●	●	●	●	●	●	●
8	4000×10	●	●	●	●	●	●	●	●	●	●	●	●	●
10	3500×10	●	●	●	●	●	●	●	●	●	●	●	●	●
12	3000×10	●	●	●	●	●	●	●	●	●	●	●	●	●

長さ		4.0														
長さ	入り数	鉄											ステンレス			
		クロロ	クロメート	三価ホウ酸	三価フッ素	ニッケル	クロム	亜鉛黒	ステンコート	黒マニル	三価ホウ酸	三価フッ素	セロロムS	セロロムS	生地	BKメッキ
5	2000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	2000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	1000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	2000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	1000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	1500×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	1500×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	500×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
14	1300×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	1000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
20	1000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
25	800×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

長さ		5.0												
長さ	入り数	鉄												
		クロロ	クロメート	三価ホウ酸	三価フッ素	ニッケル	クロム	亜鉛黒	ステンコート	黒マニル	三価ホウ酸	三価フッ素	セロロムS	セロロムS
10	800×10	●	●	●	●	●	●	●	●	●	●	●	●	●
12	800×10	●	●	●	●	●	●	●	●	●	●	●	●	●
14	500×10	●	●	●	●	●	●	●	●	●	●	●	●	●
16	700×10	●	●	●	●	●	●	●	●	●	●	●	●	●
20	600×10	●	●	●	●	●	●	●	●	●	●	●	●	●

サンコータイト ⊕ Bタイプ バインド




30001004

鉄

30021004

ステンレス

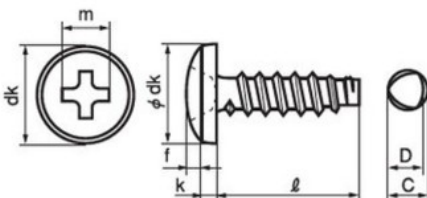

小ねじ
マフクロねじ
組込みねじ
タップピンねじ
タップタイト・ハイテックねじ
いたすら防止ねじ
建材用スクリーン
ボルト
キャップ・ボルト
ドリルねじ
座金
つまみねじ
ナット
樹脂製品
アンカーボルト