

2.0												
長さ	入り数	鉄										
		コクロ	クロメイト	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	黒ニッケル	ステンレス	ステンレス	ステンレス
4	16000×10	●	●	●	●	●	●	●	●	●	●	●
5	15000×10	●	●	●	●	●	●	●	●	●	●	●
6	10000×10	●	●	●	●	●	●	●	●	●	●	●
8	10000×10	●	●	●	●	●	●	●	●	●	●	●

2.6												
長さ	入り数	鉄										
		コクロ	クロメイト	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	黒ニッケル	ステンレス	ステンレス	ステンレス
5	6000×10	●	●	●	●	●	●	●	●	●	●	●
6	5000×10	●	●	●	●	●	●	●	●	●	●	●
8	5000×10	●	●	●	●	●	●	●	●	●	●	●
10	4000×10	●	●	●	●	●	●	●	●	●	●	●
16	3000×10	●	●	●	●	●	●	●	●	●	●	●

3.0												
長さ	入り数	鉄										
		コクロ	クロメイト	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	ステンレス	ステンレス	ステンレス	ステンレス
5	4000×10	●	●	●	●	●	●	●	●	●	●	●
6	4000×10	●	●	●	●	●	●	●	●	●	●	●
8	3000×10	●	●	●	●	●	●	●	●	●	●	●
10	1250×20	●	●	●	●	●	●	●	●	●	●	●
10	3000×10	●	●	●	●	●	●	●	●	●	●	●
12	1250×20	●	●	●	●	●	●	●	●	●	●	●
12	2500×10	●	●	●	●	●	●	●	●	●	●	●
14	2000×10	●	●	●	●	●	●	●	●	●	●	●
16	2000×10	●	●	●	●	●	●	●	●	●	●	●
20	1500×10	●	●	●	●	●	●	●	●	●	●	●
25	1000×10	●	●	●	●	●	●	●	●	●	●	●
30	1000×10	●	●	●	●	●	●	●	●	●	●	●
35	800×10	●	●	●	●	●	●	●	●	●	●	●


4.0												
長さ	入り数	鉄										
		コクロ	クロメイト	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	ステンレス	ステンレス	ステンレス	ステンレス
6	2000×10	●	●	●	●	●	●	●	●	●	●	●
8	1500×10	●	●	●	●	●	●	●	●	●	●	●
10	1500×10	●	●	●	●	●	●	●	●	●	●	●
12	1300×10	●	●	●	●	●	●	●	●	●	●	●
14	1200×10	●	●	●	●	●	●	●	●	●	●	●
16	1200×10	●	●	●	●	●	●	●	●	●	●	●
20	1000×10	●	●	●	●	●	●	●	●	●	●	●

鉄 サンコータイト TRXタンパー Bタイプ ナベ



30001U00

鉄

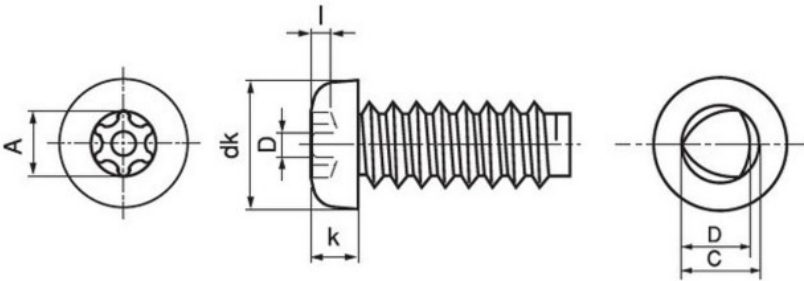

ねじの呼び d	ピッチ	ドライブ サイズ	dk		k		A	I	D
			基準寸法	許容差	基準寸法	許容差			
M3	0.5	T10	5.5	0 -0.5	2	±0.15	2.82	1.016	0.762

3.0									
長さ	入り数	コクロ	クロメイト	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	ステンレス
6	6000×10	●	●	●	●	●	●	●	●
8	5000×10	●	●	●	●	●	●	●	●
10	4000×10	●	●	●	●	●	●	●	●
12	3500×10	●	●	●	●	●	●	●	●
16	2500×10	●	●	●	●	●	●	●	●

4.0				
長さ	入り数	コクロ	クロメイト	三価ブラック
8	2500×10	●	●	●
10	2500×10	●	●	●
12	2000×10	●	●	●