


サンコータイト ⊕ Pタイプ ナベ



小ねじ
マフロねじ
組込みねじ
タップねじ
タップタイト・ハイテクねじ
いたすら防止ねじ
建材用スクリュー
ボルト
キャップホロー
ドリルねじ
座金
つまみねじ
ナット
樹脂製品
アンカーボルト

30002000	30022000	30032000
鉄	ステンレス	SUS 410

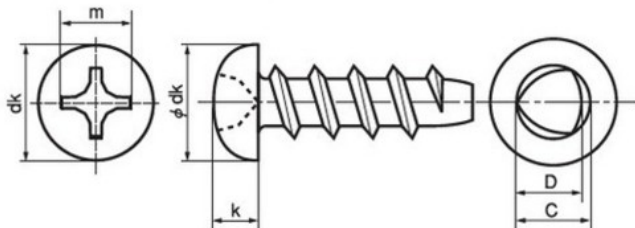

ねじの呼び	ピッチ (山/inch)	dk		k		十字穴			ねじ径				
		基準寸法	許容差	基準寸法	許容差	m	Q		十字穴の番号	C		D	
							最大	最小		最大	最小	最大	最小
2	32	3.5	0 -0.4	1.3	±0.1	2.2	1.01	0.60	1	2.11	2.01	2.03	1.93
2.3	28	4.0		1.5		2.4	1.21	0.80		2.42	2.32	2.34	2.24
2.5	24	4.5		1.7		2.6	1.42	1.00		2.63	2.53	2.54	2.44
2.6	24	4.5		1.7		2.6	1.42	1.00		2.72	2.62	2.63	2.53
3	20	5.5	0 -0.5	2.0	±0.15	3.5	1.43	0.86	2	3.14	3.02	3.04	2.92
3.5	18	6.0		2.3		3.8	1.73	1.15		3.65	3.53	3.56	3.44
4	16	7.0		2.6		4.1	2.03	1.45		4.15	4.03	4.01	3.89
5	14	9.0		-0.6		3.3	4.8	2.73		2.14	5.19	5.05	5.03
6	12	10.5	0 -0.7	3.9	±0.2	6.3	2.86	2.26	3	6.24	6.06	6.04	5.86

		2.0																
長さ mm	入り数	鉄														ステンレス		
		マフロ	クロメート	三価ホウ酸	三価フッ素	ニッケル	クロム	亜鉛黒	黒ニッケル	メッキ	メッキ	メッキ	メッキ	メッキ	メッキ	メッキ	生地	ボスワッシャー
3	20000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
4	10000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
4	20000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5	18000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5	8000×20																●	●
6	16000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	7000×20																●	●
8	12000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	6000×20																●	●
10	10000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	5000×20																●	●
12	4000×20																●	●
12	8000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
14	7000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	6000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
20	5000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

		2.3																
長さ mm	入り数	鉄														ステンレス		
		マフロ	クロメート	三価ホウ酸	三価フッ素	ニッケル	クロム	亜鉛黒	黒ニッケル	メッキ	メッキ	メッキ	メッキ	メッキ	メッキ	メッキ	生地	ボスワッシャー
4	10000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5	10000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	12000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	6000×20																●	●
8	10000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	5000×20																●	●
10	4000×20																●	●
10	8000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	7000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
14	5000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	5000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

		2.5																
長さ mm	入り数	鉄														ステンレス		
		マフロ	クロメート	三価ホウ酸	三価フッ素	ニッケル	クロム	亜鉛黒	黒ニッケル	メッキ	メッキ	メッキ	メッキ	メッキ	メッキ	メッキ	生地	ボスワッシャー
5	10000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	4000×20																●	●
6	8000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	3000×20																●	●
8	7000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	3000×20																●	●
10	5000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	2500×20																●	●
12	5000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
20	2500×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

		2.6																
長さ mm	入り数	鉄														ステンレス		
		マフロ	クロメート	三価ホウ酸	三価フッ素	ニッケル	クロム	亜鉛黒	黒ニッケル	メッキ	メッキ	メッキ	メッキ	メッキ	メッキ	メッキ	生地	ボスワッシャー
4	10000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5	10000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5	5000×20																●	●
6	4000×20																●	●
6	8000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	3000×20																●	●
8	7000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	3000×20																●	●
10	6000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	2500×20																●	●
12	5000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
14	4000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
15	4000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	1800×20																●	●
16	4000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
18	3000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
20	1500×20																●	●
20	2500×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
25	1800×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●