


サンコータイト ⊕ Pタイプ Ⅲ



小ねじ
 マフロねじ
 組込みねじ
 タツピンねじ
 タツタイト・
 ハイテクねじ
 いたすら防止ねじ
 建材用スクリーナー
 ボルト
 キャップ・ホロト
 ドリルねじ
 座金
 つまみねじ
 ナット
 樹脂製品
 アンカーボルト

30002001 鉄
 30022001 ステンレス

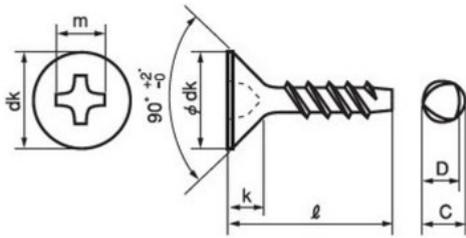

| ねじの呼び | ピッチ (山/寸) | dk | | k | | 十字穴 | | | ねじ径 | | | | |
|-------|-----------|------|-----------|------|-----------|-----|------|--------|-----|------|------|------|------|
| | | 基準寸法 | 許容差 | 基準寸法 | 許容差 | m | | 十字穴の番号 | C | | D | | |
| | | | | | | 最大 | 最小 | | 最大 | 最小 | 最大 | 最小 | |
| 2 | 32 | 4.0 | 0 -0.4 | 1.20 | 0 -0.2 | 2.2 | 1.01 | 0.65 | 1 | 2.11 | 2.01 | 2.03 | 1.93 |
| 2.3 | 28 | 4.6 | | 1.35 | | 2.4 | 1.21 | 0.85 | | 2.42 | 2.32 | 2.34 | 2.24 |
| 2.5 | 24 | 5.0 | | 1.45 | | 2.6 | 1.42 | 1.05 | | 2.63 | 2.53 | 2.54 | 2.44 |
| 2.6 | 24 | 5.2 | | 1.50 | | 2.6 | 1.42 | 1.05 | | 2.72 | 2.62 | 2.63 | 2.53 |
| 3 | 20 | 6.0 | 0 -0.5 | 1.75 | 0 -0.3 | 3.6 | 1.43 | 0.91 | 2 | 3.14 | 3.02 | 3.04 | 2.92 |
| 3.5 | 18 | 7.0 | | 2.00 | | 4.1 | 1.93 | 1.40 | | 3.65 | 3.53 | 3.56 | 3.44 |
| 4 | 16 | 8.0 | 0 -0.6 | 2.30 | | 4.5 | 2.33 | 1.79 | | 4.15 | 4.03 | 4.01 | 3.89 |
| 5 | 14 | 10 | | 2.80 | | 5.1 | 2.93 | 2.38 | | 5.19 | 5.05 | 5.03 | 4.89 |

| | | 2.0 | | | | | | | | | | | | | | ステンレス | |
|----|----------|-----|-------|-------|--------|------|-----|-----|-------|--------|--------|--------|--------|--------|--------|-------|---------|
| 長さ | 入り数 | 鉄 | | | | | | | | | | | | | | 生地 | P (メッキ) |
| | | ユフロ | クロメイト | 三価ホイト | 三価マシマシ | ニッケル | クロム | 亜鉛黒 | 黒ニッケル | くろくろくろ | くろくろくろ | くろくろくろ | くろくろくろ | くろくろくろ | くろくろくろ | | |
| 4 | 20000×10 | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 5 | 10000×20 | | | | | | | | | | | | | | | | ● |
| 5 | 20000×10 | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 6 | 18000×10 | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 6 | 8000×20 | | | | | | | | | | | | | | | | ● |
| 8 | 14000×10 | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 8 | 7000×20 | | | | | | | | | | | | | | | | ● |
| 10 | 10000×10 | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 10 | 5000×20 | | | | | | | | | | | | | | | | ● |
| 12 | 4000×20 | | | | | | | | | | | | | | | | ● |
| 12 | 8000×10 | | ● | ● | ● | | | | | | | | | | | | ● |
| 14 | 4000×20 | | | | | | | | | | | | | | | | ● |
| 14 | 7000×10 | | ● | ● | ● | | | | | | | | | | | | ● |
| 16 | 6000×10 | | ● | ● | ● | | | | | | | | | | | | ● |
| 20 | 5000×10 | | ● | ● | ● | | | | | | | | | | | | ● |

| | | 2.3 | | | | | | | | | | | | | | ステンレス | |
|----|----------|-----|-------|-------|--------|------|-----|-----|-------|--------|--------|--------|--------|--------|--------|-------|---------|
| 長さ | 入り数 | 鉄 | | | | | | | | | | | | | | 生地 | P (メッキ) |
| | | ユフロ | クロメイト | 三価ホイト | 三価マシマシ | ニッケル | クロム | 亜鉛黒 | 黒ニッケル | くろくろくろ | くろくろくろ | くろくろくろ | くろくろくろ | くろくろくろ | くろくろくろ | | |
| 6 | 14000×10 | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 8 | 8000×10 | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 10 | 8000×10 | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 12 | 7000×10 | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |

| | | 2.6 | | | | | | | | | | | | | | ステンレス | |
|----|----------|-----|-------|-------|--------|------|-----|-----|-------|--------|--------|--------|--------|--------|--------|-------|---------|
| 長さ | 入り数 | 鉄 | | | | | | | | | | | | | | 生地 | P (メッキ) |
| | | ユフロ | クロメイト | 三価ホイト | 三価マシマシ | ニッケル | クロム | 亜鉛黒 | 黒ニッケル | くろくろくろ | くろくろくろ | くろくろくろ | くろくろくろ | くろくろくろ | くろくろくろ | | |
| 5 | 10000×10 | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 5 | 5000×20 | | | | | | | | | | | | | | | | ● |
| 6 | 10000×10 | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 6 | 4000×20 | | | | | | | | | | | | | | | | ● |
| 8 | 3000×20 | | | | | | | | | | | | | | | | ● |
| 8 | 8000×10 | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 10 | 3000×20 | | | | | | | | | | | | | | | | ● |
| 10 | 7000×10 | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 12 | 2500×20 | | | | | | | | | | | | | | | | ● |
| 12 | 5000×10 | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 16 | 3000×10 | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 18 | 3000×10 | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |

| | | 3.0 | | | | | | | | | | | | | | ステンレス | |
|----|---------|-----|-------|-------|--------|------|-----|-----|-------|--------|--------|--------|--------|--------|--------|-------|---------|
| 長さ | 入り数 | 鉄 | | | | | | | | | | | | | | 生地 | P (メッキ) |
| | | ユフロ | クロメイト | 三価ホイト | 三価マシマシ | ニッケル | クロム | 亜鉛黒 | 黒ニッケル | くろくろくろ | くろくろくろ | くろくろくろ | くろくろくろ | くろくろくろ | くろくろくろ | | |
| 6 | 3000×20 | | | | | | | | | | | | | | | | ● |
| 6 | 8000×10 | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 8 | 2000×20 | | | | | | | | | | | | | | | | ● |
| 8 | 6000×10 | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 10 | 2000×20 | | | | | | | | | | | | | | | | ● |
| 10 | 5000×10 | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 12 | 2000×20 | | | | | | | | | | | | | | | | ● |
| 12 | 4000×10 | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 14 | 3500×10 | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 16 | 1000×20 | | | | | | | | | | | | | | | | ● |
| 16 | 3000×10 | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 18 | 2500×10 | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 20 | 2000×10 | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 20 | 500×20 | | | | | | | | | | | | | | | | ● |
| 25 | 1500×10 | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |