

# サンコータイト ⊕ Pタイプ ナベワッシャーヘッド




3000200W

3002200W

鉄

ステンレス

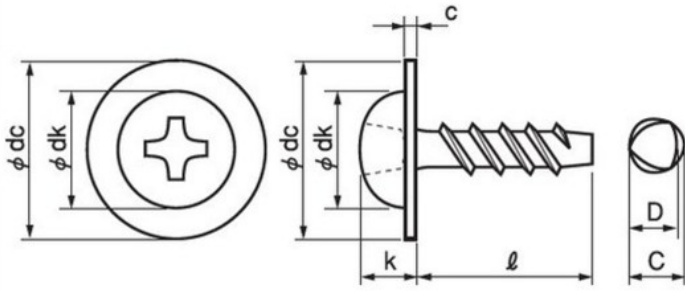

ねじの呼び	ピッチ (山/寸)	dk		dc		k		c 寸法	十字穴の番号	ねじ径			
		基準寸法	許容差	基準寸法	許容差	基準寸法	許容差			C		D	
										最大	最小	最大	最小
2	32	3.5	0 -0.4	4.3	0 -0.4	1.70	±0.1	( 0.4 )	1	2.11	2.01	2.03	1.93
2.3	28	4.0		4.6		1.90		( 0.4 )		2.42	2.32	2.34	2.24
2.6	24	4.5		6.5		2.10		( 0.5 )		2.72	2.62	2.63	2.53
3	20	5.5	0 -0.5	8.0	0 -0.5	2.20	±0.15	( 0.6 )	2	3.14	3.02	3.04	2.92
3.5	18	6.0		9.0		2.70		( 0.6 )		3.65	3.53	3.56	3.44
4	16	7.0		10.0		3.10		( 0.8 )		4.15	4.03	4.01	3.89
5	14	9.0		12.0		3.80		( 0.8 )		5.19	5.05	5.03	4.89

長さ		入り数	鉄																				
2.0			ユアラロ	クロメート	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	黒ツヤ	ステンコート	黒ツヤ	ニッケル	クロム	セロクロムS	セロクロムS	ステンコート	黒ツヤ	ニッケル	クロム	セロクロムS	セロクロムS	
4	16000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5	15000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	10000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	10000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	8000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

長さ		入り数	鉄																				
2.3			ユアラロ	クロメート	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	黒ツヤ	ステンコート	黒ツヤ	ニッケル	クロム	セロクロムS	セロクロムS	ステンコート	黒ツヤ	ニッケル	クロム	セロクロムS	セロクロムS	
6	7000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	6000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	6000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

長さ		入り数	鉄																				
2.6			ユアラロ	クロメート	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	黒ツヤ	ステンコート	黒ツヤ	ニッケル	クロム	セロクロムS	セロクロムS	ステンコート	黒ツヤ	ニッケル	クロム	セロクロムS	セロクロムS	
5	6000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	5000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	5000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	4000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

長さ		入り数	鉄													ステンレス			
3.0			ユアラロ	クロメート	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	ステンコート	黒ツヤ	三価ホワイト	三価ブラック	ニッケル	クロム	セロクロムS	セロクロムS	生地	ボルトナット
5	4000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	1250×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	4000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	1250×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	3000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	1250×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	3000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	2500×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
14	2000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	2000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
20	1300×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
25	1000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
30	1000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

長さ		入り数	鉄																			
4.0			ユアラロ	クロメート	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	ステンコート	黒ツヤ	ニッケル	クロム	セロクロムS	セロクロムS	ステンコート	黒ツヤ	ニッケル	クロム	セロクロムS	セロクロムS	
6	2000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	1500×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	1500×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	1300×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	1000×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
20	800×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

長さ		入り数	鉄																			
5.0			ユアラロ	クロメート	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	黒ツヤ	ニッケル	クロム	セロクロムS	セロクロムS	ステンコート	黒ツヤ	ニッケル	クロム	セロクロムS	セロクロムS		
10	800×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	800×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	700×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
20	500×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●