

# TRXタンパープルフ ナベ小ねじ




小ねじ  
 マフロねじ  
 組込みねじ  
 タッピンねじ  
 タツタイト  
 ハイエクねじ  
 いたずら防止ねじ  
 建材用スクリーン  
 ボルト  
 キャップボルト  
 ドリルねじ  
 座金  
 つまみねじ  
 ナット  
 樹脂製品  
 アンカーボルト

0000T100  
鉄

0002T100  
ステンレス

### 特長

●一般家庭にはない専用工具を使用しないと取り外し出来ないため、いたずら防止ねじとして使用されています。

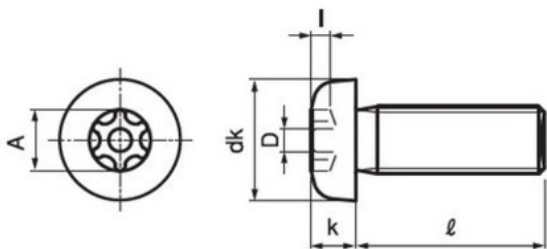

ねじの呼び (d)	ピッチ P	ドライブ サイズ	dk		k		A	I	D
			基準寸法	許容差	基準寸法	許容差			
M3	0.5	T10	5.5	0	2	±0.15	2.82	0.85	0.762
M4	0.7	T20	7	-0.5	2.6		3.94	1.20	1.350
M5	0.8	T25	9	0 -0.6	3.3	±0.2	4.52	1.40	1.778
M6	1.0	T30	10.5	0 -0.7	3.9		5.61	1.65	2.032

M2.0		
長さ dk	入り数	鉄
5	8000×20	●

		M3.0													
長さ dk	入り数	鉄								ステンレス					
		生地	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ
4	3000×24									●	●	●	●	●	●
5	3000×20	●	●	●	●	●	●	●	●						
5	3000×24									●	●	●	●	●	●
6	2500×20	●	●	●	●	●	●	●	●						
6	3000×24									●	●	●	●	●	●
8	2000×20	●	●	●	●	●	●	●	●						
8	2000×24									●	●	●	●	●	●
10	2000×20	●	●	●	●	●	●	●	●						
10	2000×24									●	●	●	●	●	●
12	2000×18									●	●	●	●	●	●
12	2500×14	●	●	●	●	●	●	●	●						
14	2000×14	●	●	●	●	●	●	●	●						
14	2000×18									●	●	●	●	●	●
15	1000×24									●	●	●	●	●	●
15	2000×14	●	●	●	●	●	●	●	●						
16	1000×24									●	●	●	●	●	●
16	2000×14	●	●	●	●	●	●	●	●						
18	1000×24									●	●	●	●	●	●
18	1500×14	●	●	●	●	●	●	●	●						
20	1000×24									●	●	●	●	●	●
20	1500×14	●	●	●	●	●	●	●	●						
25	1000×14	●													
25	1000×18									●	●	●	●	●	●

		M4.0													
長さ dk	入り数	鉄								ステンレス					
		生地	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	
5	2200×14	●	●	●	●	●	●	●	●						
6	2000×14	●	●	●	●	●	●	●	●						
6	2000×18									●	●	●	●	●	●
7	2000×14	●	●	●	●	●	●	●	●						
8	1000×24									●	●	●	●	●	●
8	2000×14	●	●	●	●	●	●	●	●						
10	1000×24									●	●	●	●	●	●
10	1500×14	●	●	●	●	●	●	●	●						
12	1000×24									●	●	●	●	●	●
12	1500×14	●	●	●	●	●	●	●	●						
15	1000×14									●	●	●	●	●	●
15	1000×18									●	●	●	●	●	●
16	1000×14									●	●	●	●	●	●
16	1000×18									●	●	●	●	●	●
18	500×24									●	●	●	●	●	●
20	500×24									●	●	●	●	●	●
20	900×14	●	●	●	●	●	●	●	●						
25	500×24									●	●	●	●	●	●
25	700×14	●	●	●	●	●	●	●	●						
30	500×14	●	●	●	●	●	●	●	●						
30	500×18									●	●	●	●	●	●
35	500×14	●	●												

		M5.0													
長さ dk	入り数	鉄								ステンレス					
		生地	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	
6	1000×18									●	●	●	●	●	●
8	1000×14	●	●	●	●	●	●	●	●						
8	1000×18									●	●	●	●	●	●
10	500×24									●	●	●	●	●	●
10	900×14	●	●	●	●	●	●	●	●						
12	500×24									●	●	●	●	●	●
12	800×14	●	●	●	●	●	●	●	●						
14	500×24									●	●	●	●	●	●
15	500×18									●	●	●	●	●	●
15	700×14	●	●	●	●	●	●	●	●						
16	500×18									●	●	●	●	●	●
16	700×14	●	●	●	●	●	●	●	●						
20	500×14	●	●	●	●	●	●	●	●						
20	500×18									●	●	●	●	●	●
21	400×18									●	●	●	●	●	●
25	400×18									●	●	●	●	●	●
25	700×10	●	●	●	●	●	●	●	●						
30	200×24									●	●	●	●	●	●
30	500×10	●													
40	400×10	●													
50	300×10	●													

		M6.0													
長さ dk	入り数	鉄								ステンレス					
		生地	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	マフロ	
8	500×24									●	●	●	●	●	●
8	600×14	●	●	●	●	●	●	●	●						
10	500×18									●	●	●	●	●	●
10	600×14	●	●	●	●	●	●	●	●						
12	500×14	●	●	●	●	●	●	●	●						
12	500×18									●	●	●	●	●	●
14	500×18									●	●	●	●	●	●
15	500×14	●	●	●	●	●	●	●	●						
15	500×18									●	●	●	●	●	●
16	200×24									●	●	●	●	●	●
16	400×14	●	●	●	●	●	●	●	●						
18	200×24									●	●	●	●	●	●
18	400×14	●	●	●	●	●	●	●	●						
20	200×24									●	●	●	●	●	●
20	300×14	●	●	●	●	●	●	●	●						
25	200×24									●	●	●	●	●	●
25	500×10	●	●	●	●	●	●	●	●						
30	200×18									●	●	●	●	●	●
30	400×10	●	●	●	●	●	●	●	●						