

TRXタンパープルーフ 皿小ねじ




0000T101

鉄

0002T101

ステンレス

いたずら防止ねじとして使用されています。

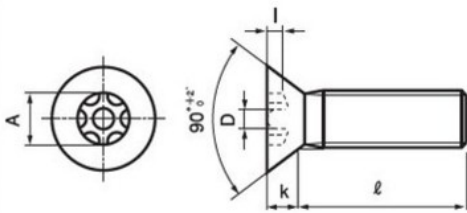

ねじの呼び	ピッチ	ドライブサイズ	dk		k		c	A	I		D
			基準寸法	許容差	基準寸法	許容差			参考	最大	
M3	0.5	T10	6	0	1.75	0	0.25	2.82	0.90	0.70	0.762
M4	0.7	T20	8	-0.5	2.3		0.3	3.94	1.25	1.05	1.35
M5	0.8	T25	10	0 -0.6	2.8	-0.3	0.3	4.52	1.60	1.40	1.778
M6	1.0	T30	12	0 -0.7	3.4	0 -0.4	0.4	5.61	1.90	1.65	2.032

M2.6

長さ	入り数	鉄							
		生地	クロメ	クロメコート	三層クロメコート	ニッケル	亜鉛黒	メッキ	メッキ
4	6000×20	●	●	●	●	●	●	●	●
5	6000×20	●	●	●	●	●	●	●	●
6	5000×20	●	●	●	●	●	●	●	●
8	4000×20	●	●	●	●	●	●	●	●
10	3000×20	●	●	●	●	●	●	●	●
12	2500×20	●	●	●	●	●	●	●	●

M3.0

長さ	入り数	鉄								ステンレス				
		生地	クロメ	クロメコート	三層クロメコート	ニッケル	クロム	亜鉛黒	メッキ	メッキ	生地	SC1	SC2	SC3
4	3000×24									●	●	●	●	●
4	4000×20	●	●	●	●	●	●	●	●					
5	3000×20	●	●	●	●	●	●	●	●					
5	3000×24									●	●	●	●	●
6	3000×20	●	●	●	●	●	●	●	●					
6	3000×24									●	●	●	●	●
8	2000×24									●	●	●	●	●
8	3000×20	●	●	●	●	●	●	●	●					
10	2000×20	●	●	●	●	●	●	●	●					
10	2000×24									●	●	●	●	●
12	2000×24									●	●	●	●	●
12	2500×14	●	●	●	●	●	●	●	●					
13	2000×14		●											
14	2000×18									●	●	●	●	●
15	2000×14	●	●	●	●	●	●	●	●					
16	1000×24									●	●	●	●	●
18	1500×14	●	●	●	●	●	●	●	●					

M4.0

長さ	入り数	鉄								ステンレス				
		生地	クロメ	クロメコート	三層クロメコート	ニッケル	クロム	亜鉛黒	メッキ	メッキ	生地	SC1	SC2	SC3
8	2000×14	●	●	●	●	●	●	●	●					
8	2000×18									●	●	●	●	●
9	1000×24									●	●	●	●	●
10	1000×24									●	●	●	●	●
10	1500×14	●	●	●	●	●	●	●	●					
12	1000×24									●	●	●	●	●
12	1500×14	●	●	●	●	●	●	●	●					
15	1000×18									●	●	●	●	●
16	1000×14	●	●	●	●	●	●	●	●					
16	1000×18									●	●	●	●	●
20	500×24									●	●	●	●	●
20	900×14	●	●	●	●	●	●	●	●					
25	500×24									●	●	●	●	●
30	500×14	●	●	●	●	●	●	●	●					
30	500×18									●	●	●	●	●

M5.0

長さ	入り数	鉄								ステンレス				
		生地	クロメ	クロメコート	三層クロメコート	ニッケル	クロム	亜鉛黒	メッキ	メッキ	生地	SC1	SC2	SC3
8	1000×18									●	●	●	●	●
10	1000×14	●	●	●	●	●	●	●	●					
10	1000×18									●	●	●	●	●
12	1000×14	●	●	●	●	●	●	●	●					
12	500×24									●	●	●	●	●
14	500×24									●	●	●	●	●
15	500×24									●	●	●	●	●
15	700×14	●	●	●	●	●	●	●	●					
16	500×24									●	●	●	●	●
16	700×14	●	●	●	●	●	●	●	●					
18	500×18									●	●	●	●	●
20	500×14	●	●	●	●	●	●	●	●					
20	500×18									●	●	●	●	●
25	700×10	●	●	●	●	●	●	●	●					
30	200×24									●	●	●	●	●

M6.0

長さ	入り数	鉄								ステンレス				
		生地	クロメ	クロメコート	三層クロメコート	ニッケル	クロム	亜鉛黒	メッキ	メッキ	生地	SC1	SC2	SC3
12	500×14	●	●	●	●	●	●	●	●					
12	500×18									●	●	●	●	●
15	500×14	●	●	●	●	●	●	●	●					
15	500×18									●	●	●	●	●
16	200×24									●	●	●	●	●
20	200×24									●	●	●	●	●
20	400×14	●	●	●	●	●	●	●	●					
25	200×24									●	●	●	●	●
25	500×10	●												
30	200×18									●	●	●	●	●
30	400×10	●	●	●	●	●	●	●	●					
35	200×18									●	●	●	●	●
40	100×24									●	●	●	●	●
45	100×24									●	●	●	●	●
50	100×24									●	●	●	●	●
55	100×24									●	●	●	●	●