

# TRXタンパープルーフトラス小ねじ



小ねじ  
 マフロねじ  
 組込みねじ  
 タツピンねじ  
 タツタイト  
 ハイエタねじ  
 いたずら防止ねじ  
 建材用スクリュー  
 ボルト  
 キヤップ・ホローク  
 ドリルねじ  
 座金  
 つまみねじ  
 ナット  
 樹脂製品  
 アンカーボルト


0000T103

鉄

0002T103

ステンレス

いたずら防止ねじとして使用されています。

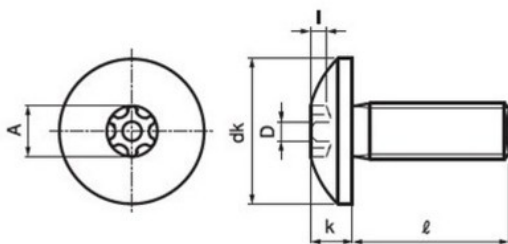

ねじの呼び (d)	ピッチ P	ドライブ サイズ	dk		k		参考	I 最小	D 参考
			基準寸法	許容差	基準寸法	許容差			
M3	0.5	T10	6.9	0	1.9	±0.15	2.82	1.016	0.762
M4	0.7	T20	9.4	-0.5	2.5		3.35	1.143	1.016
M5	0.8	T25	11.8	0 -0.6	3.1		4.52	1.397	1.778
M6	1.0	T30	14	0 -0.7	3.7	±0.2	5.00	1.651	2.032

M2.6										
長さ	入り数	鉄								ステンレス
		生地	クロメート	クロメート	三価ホウ酸	三価ホウ酸	ニッケル	クロム	亜鉛黒	三価ホウ酸
3	4000×20	●	●	●	●	●	●	●	●	●
4	4000×20	●	●	●	●	●	●	●	●	●
5	4000×20	●	●	●	●	●	●	●	●	●
6	3500×20	●	●	●	●	●	●	●	●	●
8	3000×20	●	●	●	●	●	●	●	●	●

M3.0										
長さ	入り数	鉄								ステンレス
		生地	クロメート	クロメート	三価ホウ酸	三価ホウ酸	ニッケル	クロム	亜鉛黒	三価ホウ酸
5	2000×24	●	●	●	●	●	●	●	●	●
5	2500×20	●	●	●	●	●	●	●	●	●
6	2000×20	●	●	●	●	●	●	●	●	●
6	2000×24	●	●	●	●	●	●	●	●	●
8	1500×20	●	●	●	●	●	●	●	●	●
8	2000×24	●	●	●	●	●	●	●	●	●
10	1500×20	●	●	●	●	●	●	●	●	●
10	2000×18	●	●	●	●	●	●	●	●	●
12	2000×14	●	●	●	●	●	●	●	●	●
12	2000×18	●	●	●	●	●	●	●	●	●
15	1000×24	●	●	●	●	●	●	●	●	●
15	1500×14	●	●	●	●	●	●	●	●	●
16	1500×14	●	●	●	●	●	●	●	●	●
20	1000×14	●	●	●	●	●	●	●	●	●

M4.0										
長さ	入り数	鉄								ステンレス
		生地	クロメート	クロメート	三価ホウ酸	三価ホウ酸	ニッケル	クロム	亜鉛黒	三価ホウ酸
5	1500×14	●	●	●	●	●	●	●	●	●
6	1000×24	●	●	●	●	●	●	●	●	●
6	1500×14	●	●	●	●	●	●	●	●	●
8	1000×24	●	●	●	●	●	●	●	●	●
8	1500×14	●	●	●	●	●	●	●	●	●
10	1000×14	●	●	●	●	●	●	●	●	●
10	1000×18	●	●	●	●	●	●	●	●	●
12	1000×14	●	●	●	●	●	●	●	●	●
12	1000×18	●	●	●	●	●	●	●	●	●
14	1000×14	●	●	●	●	●	●	●	●	●
15	1000×14	●	●	●	●	●	●	●	●	●
15	500×24	●	●	●	●	●	●	●	●	●
16	500×24	●	●	●	●	●	●	●	●	●
16	900×14	●	●	●	●	●	●	●	●	●
18	500×24	●	●	●	●	●	●	●	●	●
18	800×14	●	●	●	●	●	●	●	●	●
20	500×24	●	●	●	●	●	●	●	●	●
20	700×14	●	●	●	●	●	●	●	●	●
25	500×14	●	●	●	●	●	●	●	●	●
25	500×18	●	●	●	●	●	●	●	●	●
30	500×14	●	●	●	●	●	●	●	●	●
30	500×18	●	●	●	●	●	●	●	●	●
35	400×14	●	●	●	●	●	●	●	●	●

M5.0										
長さ	入り数	鉄								ステンレス
		生地	クロメート	クロメート	三価ホウ酸	三価ホウ酸	ニッケル	クロム	亜鉛黒	三価ホウ酸
6	800×14	●	●	●	●	●	●	●	●	●
8	500×24	●	●	●	●	●	●	●	●	●
8	800×14	●	●	●	●	●	●	●	●	●
10	500×24	●	●	●	●	●	●	●	●	●
10	800×14	●	●	●	●	●	●	●	●	●
12	500×18	●	●	●	●	●	●	●	●	●
12	700×14	●	●	●	●	●	●	●	●	●
14	500×14	●	●	●	●	●	●	●	●	●
15	500×14	●	●	●	●	●	●	●	●	●
15	500×18	●	●	●	●	●	●	●	●	●
16	500×14	●	●	●	●	●	●	●	●	●
16	500×18	●	●	●	●	●	●	●	●	●
20	400×14	●	●	●	●	●	●	●	●	●
20	400×18	●	●	●	●	●	●	●	●	●
25	200×24	●	●	●	●	●	●	●	●	●
25	500×10	●	●	●	●	●	●	●	●	●
30	200×24	●	●	●	●	●	●	●	●	●
30	500×10	●	●	●	●	●	●	●	●	●
35	400×10	●	●	●	●	●	●	●	●	●
40	350×10	●	●	●	●	●	●	●	●	●