


# 六角ボルト (全ねじ)



B0000000	B0240000	B0010000	B0020000	B0110000	B0120000	B0130000	B0060000	B0090000
鉄	SNB7	黄銅	ステンレス	SUS 316	SUS 316L	SUS 310S	アルミ	チタン

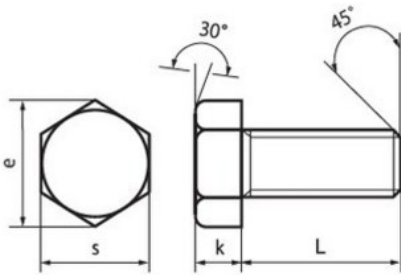

ねじの呼び (d)	ピッチ (p)	k		s		e 約
		基準寸法	許容差	基準寸法	許容差	
M3	0.5	2	±0.1	5.5	0 -0.2	6.4
M4	0.7	2.8		7		8.1
M5	0.8	3.5		8		9.2
M6	1.0	4	±0.15	10	0 -0.25	11.5
M8	1.25	5.5		13		15
M10	1.5	7		17		19.6
M12	1.75	8	±0.2	19	0 -0.35	21.9
(M14)	2.0	9		22		25.4
M16	2.0	10		24		27.7
(M18)	2.5	12		27		31.2
M20	2.5	13		30		34.6
(M22)	2.5	14		32		37
M24	3.0	15	±0.25	36	0 -0.4	41.6
M27	3.0	17		41		47.3
M30	3.5	19		46		53.1
(M33)	3.5	21		50		57.7
M36	4.0	23		55		63.5
M42	4.5	26		65		75

長さ		M3.0																								
長さ	入り数	鉄											黄銅		ステンレス		SUS 316L									
		生地	メッキ	クロメート	三価ホウ酸	三価フッ素	ニッケル	クロム	亜鉛黒	パーカー	グリーン	生地	メッキ	クロム	生地	GBフッ素	BKフッ素									
5	2000×14																									
5	2000×16																									
6	2000×10																									
6	2000×14																									
6	2000×16																									
6	3000×10																									
6	5000×12	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	2000×10																									
8	2000×14																									
8	2000×16																									
8	5000×12	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	2000×10																									
10	2000×14																									
10	4000×12	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	1500×10																									
12	2000×10																									
12	2000×16																									
14	1000×20																									
14	2000×16	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
15	1000×10																									
15	1000×16																									
15	1500×16																									

長さ		M3.0																								
長さ	入り数	鉄											黄銅		ステンレス		SUS 316L									
		生地	メッキ	クロメート	三価ホウ酸	三価フッ素	ニッケル	クロム	亜鉛黒	パーカー	グリーン	生地	メッキ	クロム	生地	GBフッ素	BKフッ素									
15	2000×10																									
15	2000×16	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	1000×10																									
16	1500×16																									
16	2000×16	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
18	1000×10																									
18	2000×16	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
20	1000×10																									
20	1000×16	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
22	1000×16	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
25	1000×10																									
25	1000×14																									
25	1000×16	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
30	1000×12	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
35	1000×10																									
35	1000×9	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
40	1000×10																									
40	500×12	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
45	500×10																									
45	500×12	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
50	400×12	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
50	500×10																									

小ねじ  
メッシュねじ  
組込みねじ  
タツピンねじ  
タツタイト  
ハイテグねじ  
いたすら防止ねじ  
建材用スクリーン  
ボルト  
キャップホウター  
ドリルねじ  
座金  
つまみねじ  
ナット  
樹脂製品  
アンカーボルト