

六角ボルト(全ねじ)(ウイット)

長さ	入り数	5/8										スケンレス
		生地	コラロ	クロマート	三種ホワイト	三種フランク	ニタル	クローム	亜鉛黒	パッカ	ドブ	
25	50×7	●	●	●	●	●	●	●	●	●	●	●
25	50×8									●	●	
30	50×6											●
32	50×5	●										
32	50×7	●	●	●	●	●	●	●	●	●	●	
35	50×6											●
38	50×6	●	●	●	●	●	●	●	●	●	●	
40	50×6										●	
45	40×6										●	
45	50×6	●	●	●	●	●	●	●	●	●	●	
50	40×6										●	
50	50×6	●	●	●	●	●	●	●	●	●	●	
55	40×6	●	●	●	●	●	●	●	●	●	●	
55	50×6									●		
60	30×6										●	
65	30×6										●	
65	40×6	●	●	●	●	●	●	●	●	●	●	
70	30×6										●	
75	30×6										●	
75	40×6	●	●	●	●	●	●	●	●	●	●	
80	30×6										●	
90	1×150	●	●	●	●	●	●	●	●	●	●	
90	25×6										●	
100	1×150	●	●	●	●	●	●	●	●	●	●	
100	25×6										●	
115	1×130	●	●	●	●	●	●	●	●	●	●	
125	1×120	●	●	●	●	●	●	●	●	●	●	
150	1×110	●	●	●	●	●	●	●	●	●	●	


長さ	入り数	3/4										スケンレス
		生地	コラロ	クロマート	三種ホワイト	三種フランク	ニタル	クローム	亜鉛黒	パッカ	ドブ	
30	35×6											●
32	1×200	●	●	●	●	●	●	●	●	●	●	●
35	30×5											●
38	1×190	●	●	●	●	●	●	●	●	●	●	●
40	40×4											●
45	1×170	●	●	●	●	●	●	●	●	●	●	●
45	30×4											●
50	1×160	●	●	●	●	●	●	●	●	●	●	●
50	30×4											●
55	1×160	●	●	●	●	●	●	●	●	●	●	●
55	25×6											●
60	25×6											●
65	1×140	●	●	●	●	●	●	●	●	●	●	●
65	20×6											●
70	15×1											●
75	1×130	●	●	●	●	●	●	●	●	●	●	●
75	20×10											●
80	15×1											●
85	15×1											●
90	1×110	●	●	●	●	●	●	●	●	●	●	●
90	15×1											●
95	15×1											●
100	1×100	●	●	●	●	●	●	●	●	●	●	●
100	15×10											●
115	1×90	●	●	●	●	●	●	●	●	●	●	●
125	1×90	●	●	●	●	●	●	●	●	●	●	●
130	10×1											●
150	1×65	●	●	●	●	●	●	●	●	●	●	●
150	10×1											●
200	5×1											●



鉄 六角ボルト(全ねじ)(日規)

B0000003

鉄

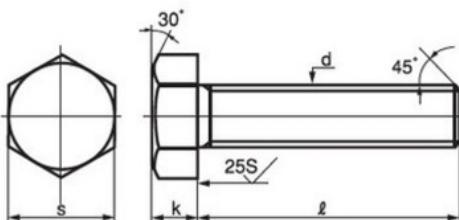

ねじの呼び(d)	W 5/16	W 3/8	W 1/2	W 5/8	W 3/4	W 7/8	W 1"	
	頭寸法	平径(s)	14	17	21	26	32	35
	厚み(k)	5.5	6	9	11	13	17	19

長さ	入り数	5/16										スケンレス
		生地	コラロ	クロマート	三種ホワイト	三種フランク	ニタル	クローム	亜鉛黒	パッカ	ドブ	
16	300×9	●	●	●	●	●	●	●	●	●	●	●
20	300×7	●	●	●	●	●	●	●	●	●	●	●
25	300×6	●	●	●	●	●	●	●	●	●	●	●
32	200×9	●	●	●	●	●	●	●	●	●	●	●
38	200×9	●	●	●	●	●	●	●	●	●	●	●
45	200×8	●	●	●	●	●	●	●	●	●	●	●
50	200×6	●	●	●	●	●	●	●	●	●	●	●
65	100×10	●	●	●	●	●	●	●	●	●	●	●
75	100×9	●	●	●	●	●	●	●	●	●	●	●

長さ	入り数	3/8										スケンレス
		生地	コラロ	クロマート	三種ホワイト	三種フランク	ニタル	クローム	亜鉛黒	パッカ	ドブ	
16	200×9	●	●	●	●	●	●	●	●	●	●	●
18	200×6	●	●									
20	200×7	●	●	●	●	●	●	●	●	●	●	●
25	200×7	●	●	●	●	●	●	●	●	●	●	●
32	100×12	●	●	●	●	●	●	●	●	●	●	●
35	100×12	●	●	●	●	●	●	●	●	●	●	●
38	100×10	●	●	●	●	●	●	●	●	●	●	●
45	100×9	●	●	●	●	●	●	●	●	●	●	●
50	100×9	●	●	●	●	●	●	●	●	●	●	●
55	100×7	●	●	●	●	●	●	●	●	●	●	●
60	100×7	●	●	●	●	●	●	●	●	●	●	●
65	100×7	●	●	●	●	●	●	●	●	●	●	●
70	100×6	●	●	●	●	●	●	●	●	●	●	●
75	100×5	●	●	●	●	●	●	●	●	●	●	●
90	100×5	●	●	●	●	●	●	●	●	●	●	●
100	100×4	●	●	●	●	●	●	●	●	●	●	●

長さ	入り数	1/2										スケンレス
		生地	コラロ	クロマート	三種ホワイト	三種フランク	ニタル	クローム	亜鉛黒	パッカ	ドブ	
140	1×200	●	●									
150	1×170	●	●									

小ねじ
 マイクロねじ
 組込みねじ
 タッピングねじ
 ハイドロねじ
 いたずら防止ねじ
 建材用スクリュー
 ボルト
 キャップ・ナット
 ドリルねじ
 座金
 つまみねじ
 ナット
 樹脂製品
 アンカーボルト