


鉄 カットボルト ウィット



B0000009

鉄

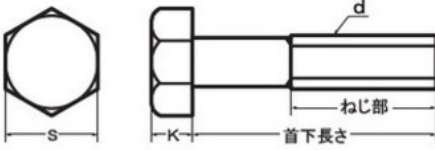

単位：mm

| ねじ呼び (d) | 山数 | 頭寸法 | | | |
|-------------|----|-------|------|-------|------|
| | | 平径(S) | | 厚さ(k) | |
| W1/4 | 20 | 10 | | 4.5 | |
| | | 0 | -0.6 | 0 | -0.6 |
| W5/16 | 18 | 14 | | 5.5 | |
| | | 0 | -0.7 | 0 | -0.6 |
| W3/8 | 16 | 17 | | 6 | |
| | | 0 | -0.7 | 0 | -0.8 |
| W1/2 | 12 | 21 | | 9 | |
| | | 0 | -0.8 | 0 | -0.8 |
| W5/8 | 11 | 26 | | 11 | |
| | | 0 | -0.8 | 0 | -0.8 |
| W3/4 | 10 | 32 | | 13 | |
| | | 0 | -0.8 | 0 | -0.9 |
| W7/8 | 9 | 35 | | 15 | |
| | | 0 | -1 | 0 | -0.9 |

| 3/8 | | | | | |
|-----|--------|----|-----|-------|----|
| 長さ | 入り数 | 生地 | ユテロ | クロメイト | ドブ |
| 20 | 1600×1 | ● | ● | ● | ● |
| 25 | 1500×1 | ● | ● | ● | ● |
| 32 | 1200×1 | ● | ● | ● | ● |
| 38 | 1000×1 | ● | ● | ● | ● |
| 45 | 1×900 | ● | ● | ● | ● |
| 50 | 1×800 | ● | ● | ● | ● |
| 55 | 1×800 | ● | ● | ● | ● |
| 60 | 1×700 | ● | ● | ● | ● |
| 65 | 1×650 | ● | ● | ● | ● |
| 70 | 1×600 | ● | ● | ● | ● |
| 75 | 1×550 | ● | ● | ● | ● |
| 80 | 1×450 | ● | ● | ● | ● |
| 85 | 1×450 | ● | ● | ● | ● |
| 90 | 1×450 | ● | ● | ● | ● |
| 100 | 1×400 | ● | ● | ● | ● |
| 115 | 1×400 | ● | ● | ● | ● |
| 125 | 1×350 | ● | ● | ● | ● |
| 140 | 1×300 | ● | ● | ● | ● |
| 150 | 1×300 | ● | ● | ● | ● |
| 165 | 1×250 | ● | ● | ● | ● |
| 180 | 1×250 | ● | ● | ● | ● |
| 195 | 1×200 | ● | ● | ● | ● |
| 210 | 1×200 | ● | ● | ● | ● |
| 225 | 1×200 | ● | ● | ● | ● |
| 240 | 1×200 | ● | ● | ● | ● |
| 255 | 1×150 | ● | ● | ● | ● |
| 270 | 1×150 | ● | ● | ● | ● |
| 285 | 1×150 | ● | ● | ● | ● |
| 300 | 1×150 | ● | ● | ● | ● |

| 1/2 | | | | | |
|-----|-------|----|-----|----|---|
| 長さ | 入り数 | 生地 | ユテロ | ドブ | |
| 20 | 1×850 | ● | ● | ● | ● |
| 25 | 1×700 | ● | ● | ● | ● |
| 32 | 1×550 | ● | ● | ● | ● |
| 38 | 1×500 | ● | ● | ● | ● |
| 45 | 1×450 | ● | ● | ● | ● |
| 50 | 1×400 | ● | ● | ● | ● |
| 55 | 1×400 | ● | ● | ● | ● |
| 60 | 1×350 | ● | ● | ● | ● |
| 65 | 1×350 | ● | ● | ● | ● |
| 70 | 1×350 | ● | ● | ● | ● |
| 75 | 1×300 | ● | ● | ● | ● |
| 80 | 1×270 | ● | ● | ● | ● |
| 85 | 1×250 | ● | ● | ● | ● |
| 90 | 1×250 | ● | ● | ● | ● |
| 100 | 1×230 | ● | ● | ● | ● |
| 115 | 1×200 | ● | ● | ● | ● |
| 125 | 1×200 | ● | ● | ● | ● |
| 140 | 1×200 | ● | ● | ● | ● |
| 150 | 1×170 | ● | ● | ● | ● |
| 165 | 1×160 | ● | ● | ● | ● |
| 180 | 1×150 | ● | ● | ● | ● |
| 195 | 1×130 | ● | ● | ● | ● |
| 210 | 1×100 | ● | ● | ● | ● |
| 225 | 1×100 | ● | ● | ● | ● |
| 240 | 1×100 | ● | ● | ● | ● |
| 255 | 1×100 | ● | ● | ● | ● |
| 270 | 1×100 | ● | ● | ● | ● |
| 285 | 1×100 | ● | ● | ● | ● |
| 300 | 1×100 | ● | ● | ● | ● |
| 315 | 1×50 | ● | ● | ● | ● |
| 330 | 1×50 | ● | ● | ● | ● |
| 345 | 1×50 | ● | ● | ● | ● |
| 360 | 1×50 | ● | ● | ● | ● |
| 375 | 1×50 | ● | ● | ● | ● |
| 390 | 1×50 | ● | ● | ● | ● |
| 405 | 1×50 | ● | ● | ● | ● |
| 420 | 1×50 | ● | ● | ● | ● |
| 435 | 1×50 | ● | ● | ● | ● |
| 450 | 1×50 | ● | ● | ● | ● |
| 480 | 1×50 | ● | ● | ● | ● |

| 5/8 | | | | | |
|-----|-------|----|-----|----|---|
| 長さ | 入り数 | 生地 | ユテロ | ドブ | |
| 25 | 1×380 | ● | ● | ● | ● |
| 32 | 1×350 | ● | ● | ● | ● |
| 38 | 1×300 | ● | ● | ● | ● |
| 45 | 1×250 | ● | ● | ● | ● |
| 50 | 1×250 | ● | ● | ● | ● |
| 55 | 1×240 | ● | ● | ● | ● |
| 60 | 1×200 | ● | ● | ● | ● |
| 65 | 1×200 | ● | ● | ● | ● |
| 70 | 1×180 | ● | ● | ● | ● |
| 75 | 1×180 | ● | ● | ● | ● |
| 80 | 1×170 | ● | ● | ● | ● |
| 85 | 1×150 | ● | ● | ● | ● |
| 90 | 1×150 | ● | ● | ● | ● |
| 100 | 1×150 | ● | ● | ● | ● |
| 115 | 1×140 | ● | ● | ● | ● |
| 125 | 1×140 | ● | ● | ● | ● |
| 140 | 1×120 | ● | ● | ● | ● |
| 150 | 1×110 | ● | ● | ● | ● |
| 165 | 1×50 | ● | ● | ● | ● |
| 180 | 1×50 | ● | ● | ● | ● |
| 195 | 1×50 | ● | ● | ● | ● |
| 210 | 1×50 | ● | ● | ● | ● |
| 225 | 1×50 | ● | ● | ● | ● |
| 240 | 1×50 | ● | ● | ● | ● |
| 255 | 1×50 | ● | ● | ● | ● |
| 270 | 1×50 | ● | ● | ● | ● |
| 285 | 1×50 | ● | ● | ● | ● |
| 300 | 1×50 | ● | ● | ● | ● |
| 315 | 1×25 | ● | ● | ● | ● |
| 330 | 1×25 | ● | ● | ● | ● |
| 345 | 1×25 | ● | ● | ● | ● |
| 360 | 1×25 | ● | ● | ● | ● |
| 375 | 1×25 | ● | ● | ● | ● |
| 390 | 1×25 | ● | ● | ● | ● |
| 405 | 1×25 | ● | ● | ● | ● |
| 420 | 1×25 | ● | ● | ● | ● |
| 435 | 1×25 | ● | ● | ● | ● |
| 450 | 1×25 | ● | ● | ● | ● |
| 480 | 1×25 | ● | ● | ● | ● |

| 3/4 | | | | | |
|-----|-------|----|-----|----|---|
| 長さ | 入り数 | 生地 | ユテロ | ドブ | |
| 32 | 1×210 | ● | ● | ● | ● |
| 38 | 1×200 | ● | ● | ● | ● |
| 45 | 1×160 | ● | ● | ● | ● |
| 50 | 1×150 | ● | ● | ● | ● |
| 55 | 1×150 | ● | ● | ● | ● |
| 60 | 1×130 | ● | ● | ● | ● |
| 65 | 1×130 | ● | ● | ● | ● |
| 70 | 1×120 | ● | ● | ● | ● |
| 75 | 1×110 | ● | ● | ● | ● |
| 80 | 1×110 | ● | ● | ● | ● |
| 85 | 1×100 | ● | ● | ● | ● |
| 90 | 1×100 | ● | ● | ● | ● |
| 100 | 1×90 | ● | ● | ● | ● |
| 115 | 1×80 | ● | ● | ● | ● |
| 125 | 1×80 | ● | ● | ● | ● |
| 140 | 1×70 | ● | ● | ● | ● |
| 150 | 1×70 | ● | ● | ● | ● |

| 7/8 | | | | | |
|-----|-------|----|-----|----|---|
| 長さ | 入り数 | 生地 | ユテロ | ドブ | |
| 45 | 1×110 | ● | ● | ● | ● |
| 50 | 1×110 | ● | ● | ● | ● |
| 55 | 1×110 | ● | ● | ● | ● |
| 60 | 1×100 | ● | ● | ● | ● |
| 65 | 1×90 | ● | ● | ● | ● |
| 70 | 1×90 | ● | ● | ● | ● |
| 75 | 1×90 | ● | ● | ● | ● |
| 80 | 1×80 | ● | ● | ● | ● |
| 85 | 1×80 | ● | ● | ● | ● |
| 90 | 1×80 | ● | ● | ● | ● |
| 100 | 1×70 | ● | ● | ● | ● |
| 115 | 1×60 | ● | ● | ● | ● |
| 125 | 1×55 | ● | ● | ● | ● |
| 140 | 1×50 | ● | ● | ● | ● |
| 150 | 1×50 | ● | ● | ● | ● |