

鉄 六角ボルト(半ねじ)(細目・P-1.5)



小ねじ

マフクロねじ

組込みねじ

タッピンねじ

タツタイト
ハイテクねじ

いたすら防止ねじ
建材用スクリーン

ボルト

キャップホロ

ドリルねじ

座金

つまみねじ

ナット

樹脂製品

アンカーボルト

B0000015

鉄

12.0

長さ	入り数	生地	コワロ	クロメート	三価ホウ酸	ニッケル	クロム	亜鉛黒	パーク	ダクロ	グリーン
35	100×8	●	●	●	●	●	●	●	●	●	●
40	70×8	●	●	●	●	●	●	●	●	●	●
45	65×8	●	●	●	●	●	●	●	●	●	●
50	60×8	●	●	●	●	●	●	●	●	●	●
55	50×8	●	●	●	●	●	●	●	●	●	●
60	50×8	●	●	●	●	●	●	●	●	●	●
65	50×8	●	●	●	●	●	●	●	●	●	●
70	45×8	●	●	●	●	●	●	●	●	●	●
75	40×8	●	●	●	●	●	●	●	●	●	●
80	40×8	●	●	●	●	●	●	●	●	●	●
85	50×6	●	●	●	●	●	●	●	●	●	●
90	50×6	●	●	●	●	●	●	●	●	●	●
95	50×6	●	●	●	●	●	●	●	●	●	●
100	50×6	●	●	●	●	●	●	●	●	●	●

六角ボルト(ユニファイ・並目 G-5)




B0000030

鉄

B0020030

ステンレス

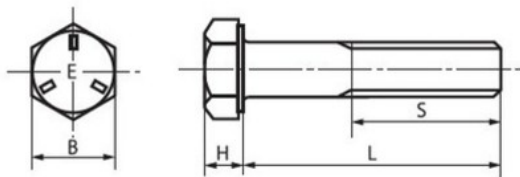

呼び径		#4-40	#6-32	#8-32	#10-24	#10-32	#12-24
B	最大	4.775	6.350	6.350	7.924	7.924	7.924
	最小	4.597	6.197	6.197	7.747	7.747	7.747
H	最大	1.524	2.362	2.794	3.048	3.937	3.937
	最小	1.244	2.032	2.438	2.667	3.530	3.530
スパナサイズ		3/16	1/4	1/4	5/16	5/16	5/16

D	1/4	5/16	3/8	7/16	1/2	9/16	5/8	3/4
B×H	11×4	12.5×5	14×6	16×7	19×8	20.5×9	23.5×10	28×12
P=NC	20	18	16	14	13	12	11	10
P=NF	28	24	24	20	20	18	18	16
S	7/8	1"	1 -1/8	1 -1/4	1 -3/8	1 -1/2	1 -5/8	2"

#4		
長さ	入り数	ステンレス
3/16	100×1	●
1/4	100×1	●
5/16	100×1	●
3/8	100×1	●
1/2	100×1	●
5/8	100×1	●
3/4	100×1	●
1"	100×1	●

#6		
長さ	入り数	ステンレス
1/4	100×1	●
5/16	100×1	●
3/8	100×1	●
1/2	100×1	●
5/8	100×1	●
3/4	100×1	●
7/8	100×1	●
1"	100×1	●
1"1/4	100×1	●
1"1/2	100×1	●

#8		
長さ	入り数	ステンレス
1/4	100×1	●
5/16	100×1	●
3/8	100×1	●
1/2	100×1	●
5/8	100×1	●
3/4	100×1	●
7/8	200×1	●
1"	500×1	●
1"1/4	300×1	●
1"1/2	300×1	●
2"	100×1	●

#10		
長さ	入り数	ステンレス
1/4	100×1	●
3/8	100×1	●
1/2	100×1	●
5/8	100×1	●
3/4	100×1	●
7/8	100×1	●
1"	100×1	●
1"1/4	100×1	●
1"3/8	100×1	●
1"1/2	100×1	●
1"3/4	100×1	●
2"	200×1	●
2"1/2	100×1	●
3"	100×1	●

#12		
長さ	入り数	ステンレス
1/2	100×1	●
5/8	200×1	●
3/4	200×1	●
1"	100×1	●