

六角ボルト(ユニファイ・細目 G-5)




B0000040

鉄

B0020040

ステンレス

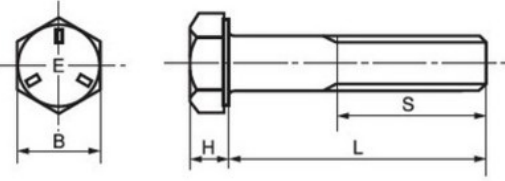

D	1/4	5/16	3/8	7/16	1/2	9/16	5/8	3/4
B×H	11×4	12.5×5	14×6	16×7	19×8	20.5×9	23.5×10	28×12
P=NC	20	18	16	14	13	12	11	10
P=NF	28	24	24	20	20	18	18	16
S	7/8	1"	1 -1/8	1 -1/4	1 -3/8	1 -1/2	1 -5/8	2"

#10		
長さ	入り数	ステンレス
1/4	100×1	●
5/16	100×1	●
3/8	100×1	●
1/2	100×1	●
5/8	200×1	●
3/4	100×1	●
7/8	100×1	●
1"	200×1	●
1 1/4	200×1	●
1 1/2	200×1	●
1 3/4	200×1	●
2"	100×1	●
2 1/2	100×1	●
3"	100×1	●

1/4										
長さ	入り数	鉄							ステンレス	
		生地	コクロ	クロメート	三価ホウ酸	三価フッ素	ニッケル	クロム		亜鉛黒
3/8	100×1								●	
1/2	100×1								●	
1/2	650×8	●	●	●	●	●	●	●	●	
5/8	100×1								●	
5/8	600×8	●	●	●	●	●	●	●	●	
3/4	100×1								●	
3/4	550×8	●	●	●	●	●	●	●	●	
7/8	500×1								●	
1"	400×8	●	●	●	●	●	●	●	●	
1"	500×1								●	
1 1/4	100×1								●	
1 1/2	200×1								●	
1 3/4	100×1								●	
2"	100×1								●	
2 1/4	100×1								●	
2 1/2	100×1								●	
3"	100×1								●	
3-1/2	100×1								●	
4"	100×1								●	
5"	100×1								●	

5/16										
長さ	入り数	鉄							ステンレス	
		生地	コクロ	クロメート	三価ホウ酸	三価フッ素	ニッケル	クロム		亜鉛黒
3/8	100×1								●	
1/2	100×1								●	
5/8	100×1								●	
5/8	400×8	●	●	●	●	●	●	●	●	
3/4	100×1								●	
3/4	350×8	●	●	●	●	●	●	●	●	
7/8	100×1								●	
1"	100×1								●	
1"	250×8	●	●	●	●	●	●	●	●	
1 1/4	100×1								●	
1 1/4	230×8	●	●	●	●	●	●	●	●	
1 1/2	100×1								●	
1 1/2	200×8	●	●	●	●	●	●	●	●	
1 3/4	100×1								●	
1 3/4	150×8	●	●	●	●	●	●	●	●	
2"	100×1								●	
2"	130×8	●	●	●	●	●	●	●	●	
2 1/4	100×1								●	
2 1/2	100×1								●	
3"	100×1								●	
3-1/2	100×1								●	
4"	100×1								●	
4 1/2	100×1								●	
5"	100×1								●	

3/8										
長さ	入り数	鉄							ステンレス	
		生地	コクロ	クロメート	三価ホウ酸	三価フッ素	ニッケル	クロム		亜鉛黒
450	100×8								●	
1/2	100×1								●	
5/8	100×1								●	
3/4	100×1								●	
3/4	250×8	●	●	●	●	●	●	●	●	
7/8	100×1								●	
1"	100×1								●	
1"	200×8	●	●	●	●	●	●	●	●	
1 1/4	150×8	●	●	●	●	●	●	●	●	
1 1/4	200×1								●	
1 3/8	100×1								●	
1 1/2	100×1								●	
1 1/2	130×8	●	●	●	●	●	●	●	●	
1 3/4	100×1								●	
1 3/4	120×8	●	●	●	●	●	●	●	●	
2"	100×1								●	
2"	100×8	●	●	●	●	●	●	●	●	
2 1/2	50×1								●	
2 1/2	80×8	●	●	●	●	●	●	●	●	
3"	50×1								●	
3"	75×8	●	●	●	●	●	●	●	●	
3 1/4	100×1								●	
3-1/2	50×1								●	
4"	50×1								●	
4 1/2	50×1								●	
6"	100×1								●	