

六角ボルト(全ネジ)



B0000050


鉄

B0010050

黄銅

B0020050

ステンレス

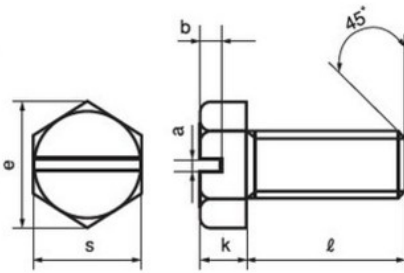

ねじの呼び (d)	ピッチ (p)	k		s		e		すり割り	
		基準寸法	基準寸法	基準寸法	基準寸法	幅 a	深さ b		
M4	0.7	2.8	7	8.1	1.0	1.2			
M5	0.8	3.5	8	9.2	1.2	1.8			
M6	1.0	4	10	11.5	1.2	2.1			
M8	1.25	5.5	13	15	1.6	2.5			
M10	1.5	7	17	19.6	2.0	2.5			

		M4.0																		
長さ	入り数	鉄							黄銅			ステンレス								
		生地	クロメート	三価ホワイト	三価ブラック	ラケル	クロム	亜鉛黒	生地	ラケル	クロム	生地	クロム	316	304					
6	1000×16																			
6	1500×12																			
6	2000×10																			
8	1000×10																			
8	1000×16																			
8	1500×12																			
10	1000×10																			
10	1000×16																			
10	1000×18																			
12	1000×10																			
12	1000×13																			
12	1000×18																			
14	1000×12																			
15	1000×10																			
15	1000×12																			
15	1000×16																			
16	1000×12																			
16	1000×16																			
20	1000×10																			
20	1000×12																			
20	500×16																			
25	1000×6																			
25	500×10																			
25	500×18																			
30	1000×6																			
30	500×18																			
35	800×10																			
40	500×12																			
50	300×16																			

		M5.0																			
長さ	入り数	鉄							黄銅			ステンレス									
		生地	クロメート	クロメート	三価ホワイト	三価ブラック	ラケル	クロム	亜鉛黒	生地	ラケル	クロム	生地	クロム	316	304					
6	1000×18																				
8	1000×10																				
8	1000×12																				
10	1000×10																				
10	500×10																				
10	800×12																				
12	500×10																				
12	500×16																				
12	800×12																				
14	800×10																				
15	500×10																				
15	500×13																				
15	500×16																				
16	500×10																				
16	500×13																				
16	500×16																				
18	500×18																				
20	500×10																				
20	500×12																				
20	500×16																				
25	300×13																				
25	500×10																				
25	500×14																				
30	300×13																				
30	500×10																				
30	500×12																				
35	200×10																				
35	300×10																				
35	500×9																				
40	200×10																				
40	200×12																				
40	500×9																				
45	200×10																				
45	200×12																				
45	300×12																				
50	200×10																				
50	200×16																				
60	200×12																				
65	200×9																				