

鋼 8マーク六角ボルト (全ねじ)



小ねじ

マフクロねじ

組込みねじ

タツピンねじ

タツタイト・
ハイエックねじ

いたすら防止ねじ 建材用スクリー

ボルト

キャップホー

ドリルねじ

座金

つまみねじ


ナット

樹脂製品

アンカーボルト

B0008000

鉄

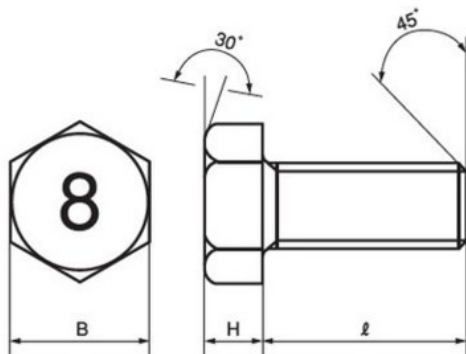

呼径	M6	M8	M10	M12	M14	M16	M20
B×H	10×4	13×5.5	17×7	19×8	22×9	24×10	30×13
ピッチ	1.0	1.25	1.5	1.75	2.0	2.0	2.5

M6.0

長さ	入り数	生地	クロメイト	クロメイト	三価ホウイ	三価ホウイ	ニッケル	クロム	亜鉛黒	ダクロ	グリーン
8	1000×8	●	●	●	●	●	●	●	●	●	●
14	700×8	●	●	●	●	●	●	●	●	●	●
16	700×8	●	●	●	●	●	●	●	●	●	●

M8.0

長さ	入り数	生地	クロメイト	クロメイト	三価ホウイ	三価ホウイ	ニッケル	クロム	亜鉛黒	ダクロ	グリーン
10	400×8	●	●	●	●	●	●	●	●	●	●
12	400×8	●	●	●	●	●	●	●	●	●	●
14	350×8	●	●	●	●	●	●	●	●	●	●
15	350×8	●	●	●	●	●	●	●	●	●	●
16	350×8	●	●	●	●	●	●	●	●	●	●
18	300×8	●	●	●	●	●	●	●	●	●	●
20	300×8	●	●	●	●	●	●	●	●	●	●
22	250×8	●	●	●	●	●	●	●	●	●	●
25	250×8	●	●	●	●	●	●	●	●	●	●
30	200×8	●	●	●	●	●	●	●	●	●	●
35	180×8	●	●	●	●	●	●	●	●	●	●
40	150×8	●	●	●	●	●	●	●	●	●	●
45	150×8	●	●	●	●	●	●	●	●	●	●
50	130×8	●	●	●	●	●	●	●	●	●	●

M10.0

長さ	入り数	生地	クロメイト	クロメイト	三価ホウイ	三価ホウイ	ニッケル	クロム	亜鉛黒	ダクロ	グリーン
14	200×8	●	●	●	●	●	●	●	●	●	●
16	180×8	●	●	●	●	●	●	●	●	●	●
18	180×8	●	●	●	●	●	●	●	●	●	●
20	150×8	●	●	●	●	●	●	●	●	●	●
22	150×8	●	●	●	●	●	●	●	●	●	●
25	140×8	●	●	●	●	●	●	●	●	●	●
30	120×8	●	●	●	●	●	●	●	●	●	●
35	100×8	●	●	●	●	●	●	●	●	●	●
40	100×8	●	●	●	●	●	●	●	●	●	●
45	90×8	●	●	●	●	●	●	●	●	●	●
50	75×8	●	●	●	●	●	●	●	●	●	●
55	75×8	●	●	●	●	●	●	●	●	●	●
80	60×8	●	●	●	●	●	●	●	●	●	●
90	50×8	●	●	●	●	●	●	●	●	●	●

M12.0

長さ	入り数	生地	クロメイト	クロメイト	三価ホウイ	三価ホウイ	ニッケル	クロム	亜鉛黒	ダクロ	グリーン
20	110×8	●	●	●	●	●	●	●	●	●	●
25	100×8	●	●	●	●	●	●	●	●	●	●
30	90×8	●	●	●	●	●	●	●	●	●	●
35	75×8	●	●	●	●	●	●	●	●	●	●
40	70×8	●	●	●	●	●	●	●	●	●	●
45	65×8	●	●	●	●	●	●	●	●	●	●
50	60×8	●	●	●	●	●	●	●	●	●	●
60	50×8	●	●	●	●	●	●	●	●	●	●
70	45×8	●	●	●	●	●	●	●	●	●	●
90	40×8	●	●	●	●	●	●	●	●	●	●
100	35×8	●	●	●	●	●	●	●	●	●	●

M14.0

長さ	入り数	生地	クロメイト	クロメイト	三価ホウイ	三価ホウイ	ニッケル	クロム	亜鉛黒	ダクロ	グリーン
25	1×700	●	●	●	●	●	●	●	●	●	●
30	1×500	●	●	●	●	●	●	●	●	●	●
35	1×450	●	●	●	●	●	●	●	●	●	●

M16.0

長さ	入り数	生地	クロメイト	クロメイト	三価ホウイ	三価ホウイ	ニッケル	クロム	亜鉛黒	ダクロ	グリーン
25	1×450	●	●	●	●	●	●	●	●	●	●
30	1×350	●	●	●	●	●	●	●	●	●	●
35	1×350	●	●	●	●	●	●	●	●	●	●
40	1×300	●	●	●	●	●	●	●	●	●	●

M20.0


長さ	入り数	生地	クロメイト	クロメイト	三価ホウイ	三価ホウイ	ニッケル	クロム	亜鉛黒	ダクロ	グリーン
40	1×190	●	●	●	●	●	●	●	●	●	●
45	1×150	●	●	●	●	●	●	●	●	●	●
50	1×150	●	●	●	●	●	●	●	●	●	●

鋼 8マーク六角ボルト (全ねじ)(細目・P-1.5)



B0008005

鉄

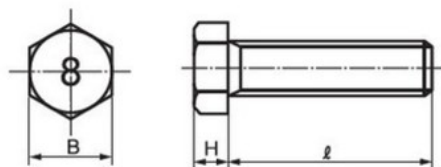

ねじの呼び	ピッチ	H	B
M12	1.5	8	19

M12.0

長さ	入り数	生地	クロメイト	クロメイト	三価ホウイ	三価ホウイ	ニッケル	クロム	亜鉛黒	ダクロ	グリーン
20	110×8	●	●	●	●	●	●	●	●	●	●
25	100×8	●	●	●	●	●	●	●	●	●	●
30	90×8	●	●	●	●	●	●	●	●	●	●
35	75×8	●	●	●	●	●	●	●	●	●	●