

鋼 強度区分8.8 六角ボルト(全ねじ)



小ねじ

マフクロねじ

組込みねじ

タツピンねじ

タツタイト・
ハイテックねじ

いたすら防止ねじ

建材用スクリー

ボルト

キャップホロー

ドリルねじ

座金

つまみねじ


ナット

樹脂製品

アンカーボルト

B0000300

鉄

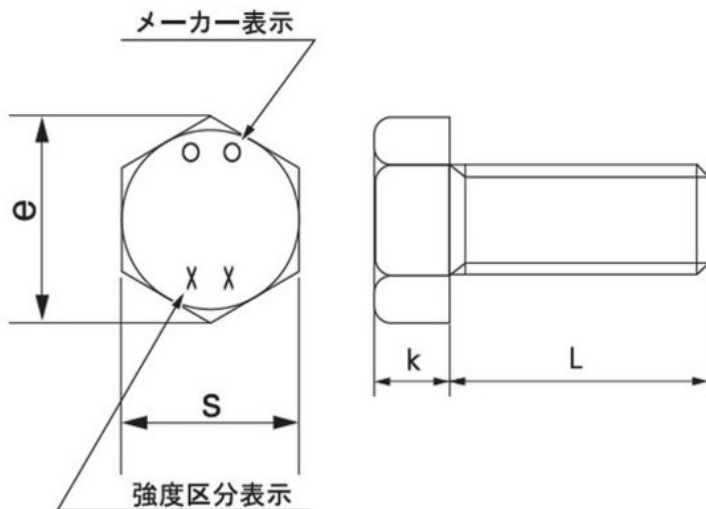

呼び径	K		S		e
	基準寸法	許容差	基準寸法	許容差	
M6	4	±0.25	10	0 -0.6	11.5
M8	5.5		13	0 -0.7	15
M10	7	±0.3	17		19.6
M12	8		19	0 -0.8	21.9
M14	9		22		25.4
M16	10	±0.35	24		27.7
M20	13		30	0 -1	34.6
M22	14		32		37

M6.0										
長さ	入り数	生地	コクロ	クロメイト	三価ホライト	三価フラク	ニッケル	クロム	亜鉛黒	ダクロ
10	200×27	●	●	●	●	●	●	●	●	●
12	200×27	●	●	●	●	●	●	●	●	●
14	200×20	●	●	●	●	●	●	●	●	●
15	200×20	●	●	●	●	●	●	●	●	●
16	200×20	●	●	●	●	●	●	●	●	●
18	200×20	●	●	●	●	●	●	●	●	●
20	200×20	●	●	●	●	●	●	●	●	●
22	200×20	●	●	●	●	●	●	●	●	●

M8.0										
長さ	入り数	生地	コクロ	クロメイト	三価ホライト	三価フラク	ニッケル	クロム	亜鉛黒	ダクロ
10	100×20	●	●	●	●	●	●	●	●	●
14	100×20	●	●	●	●	●	●	●	●	●
15	100×20	●	●	●	●	●	●	●	●	●
16	100×20	●	●	●	●	●	●	●	●	●
18	100×20	●	●	●	●	●	●	●	●	●
20	100×20	●	●	●	●	●	●	●	●	●
22	100×16	●	●	●	●	●	●	●	●	●
25	100×16	●	●	●	●	●	●	●	●	●

M10.0										
長さ	入り数	生地	コクロ	クロメイト	三価ホライト	三価フラク	ニッケル	クロム	亜鉛黒	ダクロ
15	100×10	●	●	●	●	●	●	●	●	●
16	100×10	●	●	●	●	●	●	●	●	●
20	100×10	●	●	●	●	●	●	●	●	●
25	100×10	●	●	●	●	●	●	●	●	●
30	100×8	●	●	●	●	●	●	●	●	●

M12.0										
長さ	入り数	生地	コクロ	クロメイト	三価ホライト	三価フラク	ニッケル	クロム	亜鉛黒	ダクロ
20	100×6	●	●	●	●	●	●	●	●	●
25	100×6	●	●	●	●	●	●	●	●	●
30	100×6	●	●	●	●	●	●	●	●	●
35	50×8	●	●	●	●	●	●	●	●	●

M14.0										
長さ	入り数	生地	コクロ	クロメイト	三価ホライト	三価フラク	ニッケル	クロム	亜鉛黒	ダクロ
25	60×6	●	●	●	●	●	●	●	●	●
30	60×6	●	●	●	●	●	●	●	●	●
35	60×6	●	●	●	●	●	●	●	●	●
40	60×6	●	●	●	●	●	●	●	●	●

M16.0										
長さ	入り数	生地	コクロ	クロメイト	三価ホライト	三価フラク	ニッケル	クロム	亜鉛黒	ダクロ
25	80×4	●	●	●	●	●	●	●	●	●
30	80×4	●	●	●	●	●	●	●	●	●
35	70×4	●	●	●	●	●	●	●	●	●
40	70×4	●	●	●	●	●	●	●	●	●
45	60×4	●	●	●	●	●	●	●	●	●

M20.0										
長さ	入り数	生地	コクロ	クロメイト	三価ホライト	三価フラク	ニッケル	クロム	亜鉛黒	ダクロ
30	40×4	●	●	●	●	●	●	●	●	●
35	40×4	●	●	●	●	●	●	●	●	●
40	30×4	●	●	●	●	●	●	●	●	●
45	30×4	●	●	●	●	●	●	●	●	●
50	30×4	●	●	●	●	●	●	●	●	●
55	30×4	●	●	●	●	●	●	●	●	●

M22.0										
長さ	入り数	生地	コクロ	クロメイト	三価ホライト	三価フラク	ニッケル	クロム	亜鉛黒	ダクロ
45	25×4	●	●	●	●	●	●	●	●	●
50	25×4	●	●	●	●	●	●	●	●	●
55	25×4	●	●	●	●	●	●	●	●	●
60	25×4	●	●	●	●	●	●	●	●	●