

鉄 7マーク付き フランジボルト (セレート付き)(細目)



C0001706

鉄

10.0									
長さ	入り数	コクロ	クロメイト	三価ホウソウ	三価ホウソウ	ニッケル	クロム	亜鉛黒	グリーン
20	130×8	●	●	●	●	●	●	●	●
25	110×8	●	●	●	●	●	●	●	●
30	100×8	●	●	●	●	●	●	●	●
35	90×8	●	●	●	●	●	●	●	●
40	75×8	●	●	●	●	●	●	●	●
50	60×8	●	●	●	●	●	●	●	●

12.0									
長さ	入り数	コクロ	クロメイト	三価ホウソウ	三価ホウソウ	ニッケル	クロム	亜鉛黒	グリーン
30	90×8	●	●	●	●	●	●	●	●
35	80×8	●	●	●	●	●	●	●	●
40	70×8	●	●	●	●	●	●	●	●
50	60×8	●	●	●	●	●	●	●	●

⊕ ⊖ 六角フランジ小ねじ




0000020B

鉄

0002020B

ステンレス

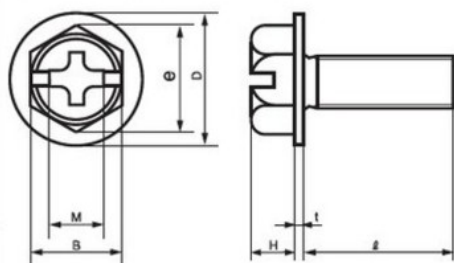

特長

●ボックス・スパナ・モンキー・プラスドライバー・マイナスドライバー等様々な締め付け工具で使用できます。しかもフランジがついている為、座面陥没によるゆるみを防止します。

ねじの呼び径	B		D		H		T		M	e
	基準寸法	許容差	基準寸法	許容差	基準寸法	許容差	基準寸法	許容差	参考	最小
M4	7	0	9	±0.4	2.5	±0.3	0.6	±0.15	4	7.7
M5	8	-0.2	10		3		0.8		4.4	8.7
M6	10	0	13	±0.5	4	±0.5	1.2	±0.2	6.2	10.9
M8	12	-0.25	16		5				7.2	13.1

M4.0		
長さ	入り数	ステンレス
8	500×24	●
10	500×24	●
12	500×24	●
16	500×18	●
20	500×18	●

M5.0									
長さ	入り数	鉄							
		生地	コクロ	クロメイト	三価ホウソウ	三価ホウソウ	ニッケル	クロム	亜鉛黒
10	500×18								●
10	800×14	●	●	●	●	●	●	●	●
12	500×14								●
12	600×14	●	●	●	●	●	●	●	●
16	500×14	●	●	●	●	●	●	●	●
20	200×24								●
20	450×14	●	●	●	●	●	●	●	●
25	200×24								●
25	600×10	●	●	●	●	●	●	●	●
30	200×18								●
30	500×10	●	●	●	●	●	●	●	●

M6.0									
長さ	入り数	鉄							
		生地	コクロ	クロメイト	三価ホウソウ	三価ホウソウ	ニッケル	クロム	亜鉛黒
8	450×14								●
10	200×24								●
10	400×14	●	●	●	●	●	●	●	●
12	200×24								●
12	400×14	●	●	●	●	●	●	●	●
15	200×18								●
15	350×14	●	●	●	●	●	●	●	●
16	200×18								●
16	350×14	●	●	●	●	●	●	●	●
20	200×18								●
20	250×14	●	●	●	●	●	●	●	●
25	200×14								●
25	350×10	●	●	●	●	●	●	●	●
30	100×24								●
30	250×10	●	●	●	●	●	●	●	●
35	250×10	●	●	●	●	●	●	●	●
40	220×10	●	●	●	●	●	●	●	●
45	170×10								●
50	170×10	●	●	●	●	●	●	●	●

M8.0									
長さ	入り数	鉄							
		生地	コクロ	クロメイト	三価ホウソウ	三価ホウソウ	ニッケル	クロム	亜鉛黒
15	100×18								●
16	100×18								●
16	180×14	●	●	●	●	●	●	●	●
20	100×18								●
20	150×14	●	●	●	●	●	●	●	●
25	100×14								●
25	200×10	●	●	●	●	●	●	●	●
30	180×10	●	●	●	●	●	●	●	●