

ウエルドボルト




00000800

鉄

00020800

ステンレス

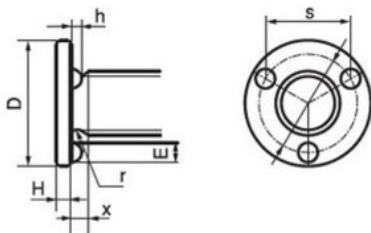

ねじの呼び	突起数	D		H		S	E	h	x		r
		基準寸法	許容差	基準寸法	許容差				基準	許容差	
M4	3	10	0	1.3	±0.2	7	1.5	0.8	2.0	+1.0	0.2
M5		12	-0.5	1.8		8	2.0	0.8	2.0		0.2
M6		14	±0.5	2.0		10.5	2.2	1.0	2.5		0.25
M8	4	17	0 -0.8	2.5	±0.3	13	2.5	1.3	3.0	0	0.4
M10		19		3.0		1.5	3.0	0.4			
M12		24		3.5		1.5	4.0	0.6			

M4.0							
長さ	入り数	鉄					ステンレス
		生地	コクロ	クロメート	三価ホワイト	亜鉛黒	
8	2500×10	●	●	●	●	●	●
10	2000×10	●	●	●	●	●	●
12	1800×10	●	●	●	●	●	●
15	1500×10	●	●	●	●	●	●
16	1500×10	●	●	●	●	●	●
20	1200×10	●	●	●	●	●	●
25	1000×10	●	●	●	●	●	●
30	800×10	●	●	●	●	●	●

M5.0							
長さ	入り数	鉄					ステンレス
		生地	コクロ	クロメート	三価ホワイト	亜鉛黒	
8	1500×10	●	●	●	●	●	●
10	1300×10	●	●	●	●	●	●
12	1100×10	●	●	●	●	●	●
14	1000×10	●	●	●	●	●	●
15	1000×10	●	●	●	●	●	●
16	900×10	●	●	●	●	●	●
18	800×10	●	●	●	●	●	●
20	700×10	●	●	●	●	●	●
25	600×10	●	●	●	●	●	●
30	500×10	●	●	●	●	●	●
35	400×10	●	●	●	●	●	●
40	350×10	●	●	●	●	●	●

M6.0							
長さ	入り数	鉄					ステンレス
		生地	コクロ	クロメート	三価ホワイト	亜鉛黒	
10	800×10	●	●	●	●	●	●
12	700×10	●	●	●	●	●	●
14	600×10	●	●	●	●	●	●
15	500×10	●	●	●	●	●	●
15	600×10	●	●	●	●	●	●
16	500×10	●	●	●	●	●	●
18	450×10	●	●	●	●	●	●
18	500×10	●	●	●	●	●	●
20	450×10	●	●	●	●	●	●
22	400×10	●	●	●	●	●	●
25	350×10	●	●	●	●	●	●
30	300×10	●	●	●	●	●	●
35	250×10	●	●	●	●	●	●
40	200×10	●	●	●	●	●	●
45	200×10	●	●	●	●	●	●
50	170×10	●	●	●	●	●	●
55	150×10	●	●	●	●	●	●
60	150×10	●	●	●	●	●	●

M8.0							
長さ	入り数	鉄					ステンレス
		生地	コクロ	クロメート	三価ホワイト	亜鉛黒	
12	400×10	●	●	●	●	●	●
14	400×10	●	●	●	●	●	●
15	350×10	●	●	●	●	●	●
16	350×10	●	●	●	●	●	●
18	300×10	●	●	●	●	●	●
20	300×10	●	●	●	●	●	●
22	270×10	●	●	●	●	●	●
25	250×10	●	●	●	●	●	●
30	200×10	●	●	●	●	●	●
35	180×10	●	●	●	●	●	●
40	160×10	●	●	●	●	●	●
45	140×10	●	●	●	●	●	●
50	120×10	●	●	●	●	●	●
55	100×10	●	●	●	●	●	●
60	100×10	●	●	●	●	●	●

M10.0							
長さ	入り数	鉄					ステンレス
		生地	コクロ	クロメート	三価ホワイト	亜鉛黒	
16	170×10	●	●	●	●	●	●
16	230×10	●	●	●	●	●	●
18	200×10	●	●	●	●	●	●
20	150×10	●	●	●	●	●	●
20	200×10	●	●	●	●	●	●
25	130×10	●	●	●	●	●	●
25	170×10	●	●	●	●	●	●
30	110×10	●	●	●	●	●	●
30	150×10	●	●	●	●	●	●
35	100×10	●	●	●	●	●	●
35	120×10	●	●	●	●	●	●
40	100×10	●	●	●	●	●	●
40	90×10	●	●	●	●	●	●
45	100×10	●	●	●	●	●	●
50	70×10	●	●	●	●	●	●
50	80×10	●	●	●	●	●	●

M12.0						
長さ	入り数	鉄				
		生地	コクロ	クロメート	三価ホワイト	亜鉛黒
25	100×10	●	●	●	●	●
30	90×10	●	●	●	●	●
35	80×10	●	●	●	●	●
40	70×10	●	●	●	●	●
50	50×10	●	●	●	●	●

小ねじ

マフロねじ

組込みねじ

タツピンねじ

タツタイト
ハイテねじ

いたすら防止ねじ

建材用スクリーン

ボルト

キャップホロ

ドリルねじ

座金

つまみねじ

ナット

樹脂製品

アンカーボルト