


六角穴付きボルト(キャップスクリュー)



小ねじ
メソコねじ
組込みねじ
タッピンねじ
タツタイト
ハイテクねじ
いたすら防止ねじ
建材用スクリュー
ボルト
キャップ・ホーロー
ドリルねじ
座金
つまみねじ
ナット
樹脂製品
アンカーボルト

A0000000	A0020000	A0120000	A0130000	A0170000	A0060000	A0090000	A0200000
鉄	ステンレス	SUS 316L	SUS 310S	SUS 430	アルミ	チタン	64 チタン

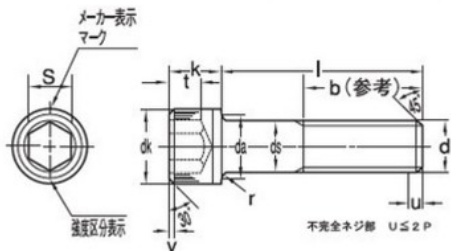

		(mm)																		
ねじの呼び(d)		M1.4	M1.6	M2	M2.5(M2.6)	M3	M4	M5	M6	M8	M10	M12	(M14)	M16	(M18)	M20	M24	M30	M36	M42
ピッチ(P)		0.3	0.35	0.4	0.45	0.5	0.7	0.8	1	1.25	1.5	1.75	2	2	2.5	2.5	3	3.5	4	4.5
b	参考	14	15	16	17	18	20	22	24	28	32	36	40	44	48	52	60	72	84	96
dk	最大(基準寸法(1))	2.6	3.0	3.8	4.5	5.5	7	8.5	10	13	16	18	21	24	27	30	36	45.00	54.00	63.00
	最大(2)	2.74	3.14	3.98	4.68	5.68	7.22	8.72	10.22	13.27	16.27	18.27	21.33	24.33	27.33	30.33	36.39	45.39	54.46	63.46
	最小	2.46	2.86	3.62	4.32	5.32	6.78	8.28	9.78	12.73	15.73	17.73	20.67	23.67	26.67	29.67	35.61	44.61	53.54	62.54
da	最大	1.8	2.0	2.6	3.1(3.2)	3.6	4.7	5.7	6.8	9.2	11.2	13.7	15.7	17.7	20.2	22.4	26.4	33.4	39.4	45.6
	最小(基準寸法)	1.4	1.6	2	2.5(2.6)	3	4	5	6	8	10	12	14	16	18	20	24	30.00	36.00	42.00
ds	最大	1.26	1.46	1.86	2.36(2.46)	2.86	3.82	4.82	5.82	7.78	9.78	11.73	13.73	15.73	17.73	19.67	23.67	29.67	35.61	41.61
	最小	1.5	1.733	1.733	2.303	2.873	3.443	4.583	5.723	6.863	9.149	11.429	13.716	15.996	15.996	19.437	21.734	25.154	30.854	36.571
k	最大(基準寸法)	1.4	1.6	2	2.5(2.6)	3	4	5	6	8	10	12	14	16	18	20	24	30	36	42
	最小	1.26	1.46	1.86	2.36(2.46)	2.86	3.82	4.82	5.70	7.64	9.64	11.57	13.57	15.57	17.57	19.48	23.48	29.48	35.38	41.38
r	最小	0.1	0.1	0.1	0.1	0.1	0.2	0.2	0.25	0.4	0.4	0.6	0.6	0.6	0.6	0.8	0.8	1	1	1.2
	呼び(基準寸法)	1.3	1.5	1.5	2	2.5	3	4	5	6	8	10	12	14	14	17	19	22	27	32
s	最大	1.36	1.56	1.58	2.08	2.58	3.08	4.095	5.14	6.14	8.175	10.175	12.212	14.212	14.212	17.230	19.275	22.275	27.275	32.33
	最小	1.32	1.52	1.52	2.02	2.52	3.02	4.02	5.02	6.02	8.025	10.025	12.032	14.032	14.032	17.050	19.065	22.065	27.065	32.08
t	最小	0.6	0.7	1	1.1	1.3	2	2.5	3	4	5	6	7	8	9	10	12	15.5	19	21
v	最大	0.14	0.16	0.2	0.25	0.3	0.4	0.5	0.6	0.8	1	1.2	1.4	1.6	1.8	2	2.4	3	3.6	4.2

(1) ローレットなしの最大径 (2) ローレット付きの最大径

M1.4			
長さ	入り数	鉄	ステンレス
3	1000×39	●	●
3	1000×45	●	●
4	1000×39	●	●
4	1000×45	●	●
5	1000×39	●	●
5	1000×45	●	●
6	1000×39	●	●
6	1000×45	●	●
8	1000×39	●	●
8	1000×45	●	●
10	1000×39	●	●
10	1000×45	●	●

M1.6				
長さ	入り数	鉄	ステンレス	SUS 316L
3	1000×39	●	●	●
3	1000×45	●	●	●
4	1000×39	●	●	●
4	1000×45	●	●	●
5	1000×39	●	●	●
5	1000×45	●	●	●
6	1000×39	●	●	●
6	1000×45	●	●	●
8	1000×39	●	●	●
8	1000×45	●	●	●
10	1000×39	●	●	●
10	1000×45	●	●	●
12	1000×39	●	●	●
14	1000×39	●	●	●
15	1000×39	●	●	●
16	1000×39	●	●	●
20	1000×39	●	●	●

M2.0											
長さ	入り数	鉄						ステンレス		SUS 316L	
		生地	三橋ホワイト	三橋ブラック	ラケル	クロム	スニハルト	黒ラケル	無電鍮ラケル		生地
2.5	1000×30	●			●	●	●	●			
2.5	1000×45								●		
3	500×39								●	●	●
3	500×45	●			●	●	●	●			
4	500×39								●	●	●
4	500×45	●			●	●	●	●			
5	500×39								●	●	●
5	500×45	●			●	●	●	●			
6	500×39								●	●	●
6	500×45	●			●	●	●	●			
7	500×45	●	●	●	●	●	●	●			
8	500×39								●	●	●
8	500×45	●			●	●	●	●			
10	500×39								●	●	●
10	500×45	●			●	●	●	●			
12	500×39								●	●	●
12	500×45	●			●	●	●	●			
14	500×39								●	●	●
14	500×45	●			●	●	●	●			
15	500×39								●	●	●
15	500×45	●			●	●	●	●			
16	500×39								●	●	●
16	500×45	●			●	●	●	●			
18	500×30	●			●	●	●	●			
18	500×39								●	●	●
20	500×30	●			●	●	●	●			
20	500×39								●	●	●
25	200×39	●			●	●	●	●			
30	200×39	●			●	●	●	●			
35	200×39								●	●	●
40	200×39								●	●	●