


鋼 六角穴付きボルト(キャップスクリュー) 互省製作所製



小ねじ
マフクロねじ
組込みねじ
タッピンねじ
タツタイト
ハイエックねじ
いたすら防止ねじ
建材用スクリュー
ボルト
キャップ・ホーロー
ドリルねじ
座金
つまみねじ
ナット
樹脂製品
アンカーボルト

A000000G
鉄

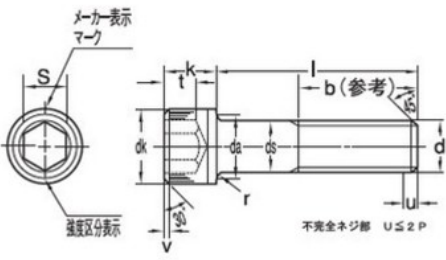

(単位 mm)

ねじの呼び (d)	M3	M4	M5	M6	M8	M10	M12	M14	M16	M18	M20	M22	M24
ねじのピッチ (P)	0.5	0.7	0.8	1.0	1.25	1.5	1.75	2.0	2.0	2.5	2.5	2.5	3.0
b	参考	18	20	22	24	28	32	36	40	44	48	52	56
dk	最大	5.68	7.22	8.72	10.22	13.27	16.27	18.27	21.33	24.33	27.33	30.33	33.39
	最小	5.32	6.78	8.28	9.78	12.73	15.73	17.73	20.67	23.67	26.67	29.67	32.61
da	最大	3.60	4.70	5.70	6.80	9.20	11.2	13.7	15.7	17.7	20.2	22.4	24.4
	最小	3	4	5	6	8	10	12	14	16	18	20	22
ds	最大	3	4	5	6	8	10	12	14	16	18	20	22
	最小	2.86	3.82	4.82	5.82	7.78	9.78	11.73	13.73	15.73	17.73	19.67	21.67
k	最大	3	4	5	6	8	10	12	14	16	18	20	22
	最小	2.86	3.82	4.82	5.70	7.64	9.64	11.57	13.57	15.57	17.57	19.48	21.48
r	最小	0.1	0.2	0.2	0.25	0.4	0.4	0.6	0.6	0.6	0.8	0.8	0.8
S	呼び寸法	2.5	3.0	4.0	5.0	6.0	8.0	10.0	12.0	14.0	14.0	17.0	19.0
	最大	2.58	3.08	4.095	5.14	6.14	8.175	10.175	12.212	14.212	14.212	17.23	19.275
	最小	2.52	3.02	4.02	5.02	6.02	8.025	10.025	12.032	14.032	14.032	17.05	19.065
t	最小	1.3	2	2.5	3	4	5	6	7	8	9	10	11
v	最大	0.3	0.4	0.5	0.6	0.8	1.0	1.2	1.4	1.6	1.8	2.0	2.4

M2.0		
長さ	入り数	生地
8	2000×16	●

M4.0		
長さ	入り数	生地
5	1000×16	●
6	1000×12	●
8	1000×12	●
10	1000×12	●
12	500×20	●
14	500×20	●
15	500×20	●
16	500×20	●
18	500×20	●
20	500×16	●
22	500×16	●
25	500×12	●
30	500×12	●
35	500×9	●
40	200×16	●
45	200×16	●
50	200×16	●
55	200×16	●
60	200×16	●
65	200×16	●
70	200×12	●
75	200×12	●
80	200×12	●
85	100×16	●
90	100×16	●
95	100×16	●
100	100×12	●
105	100×12	●
110	100×12	●
115	100×9	●
120	100×9	●

M5.0		
長さ	入り数	生地
5	500×20	●
6	500×20	●
8	500×20	●
10	500×16	●
12	500×16	●
14	500×12	●
15	500×12	●
16	500×12	●
18	500×12	●
20	500×12	●
22	500×9	●
25	500×9	●
30	500×6	●
35	500×6	●
40	200×12	●
45	200×12	●
50	200×12	●
55	200×12	●
60	200×12	●
65	200×9	●
70	200×9	●

M5.0		
長さ	入り数	生地
75	100×16	●
80	100×16	●
85	100×16	●
90	100×16	●
95	100×16	●
100	100×12	●
105	100×9	●
110	100×9	●
115	100×6	●
120	100×6	●
125	100×6	●
130	100×6	●
135	100×6	●
140	100×6	●
145	100×6	●
150	100×6	●
155	100×6	●
160	100×6	●
165	100×6	●
170	100×6	●

M6.0		
長さ	入り数	生地
6	500×12	●
8	500×12	●
10	500×12	●
12	500×9	●
14	500×9	●
15	500×9	●
16	500×9	●
18	500×6	●
20	500×6	●
22	500×6	●
25	500×6	●
30	200×12	●
35	200×12	●
40	200×9	●
45	200×9	●
50	200×9	●
55	200×6	●
60	200×6	●
65	200×6	●
70	200×6	●

M6.0		
長さ	入り数	生地
75	100×12	●
80	100×12	●
85	100×12	●
90	100×9	●
95	100×9	●
100	100×9	●
105	100×9	●
110	100×9	●
115	100×6	●
120	100×6	●
125	100×6	●
130	100×6	●
135	100×6	●
140	100×6	●
145	100×6	●
150	100×6	●
155	100×6	●
160	100×6	●
165	100×6	●
170	100×6	●

M3.0		
長さ	入り数	生地
5	2000×16	●
6	2000×16	●
8	2000×16	●
10	1000×20	●
12	1000×20	●
14	1000×20	●
15	1000×20	●
16	1000×16	●
18	1000×16	●
20	1000×12	●
22	1000×12	●
25	1000×12	●
30	500×20	●
35	500×16	●
40	200×20	●
45	200×20	●
50	200×20	●