


六角穴付きボルト(キャップスクリュー) 日産ネジ製



A000000N 鉄	A002000N ステンレス
---------------	-------------------

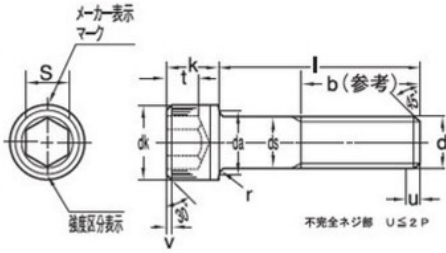

(単位 mm)

ねじの呼び(d)	M1.6	M2	M3	M4	M5	M6	M8	M10	M12	M14	M16	M20
ねじのピッチ(P)	0.35	0.4	0.5	0.7	0.8	1.0	1.25	1.5	1.75	2.0	2.0	2.5
b	参考	15	16	18	20	22	24	28	32	36	40	52
dk	最大(基準寸法)(1)	3	3.8	5.5	7	8.5	10	13	16	18	21	30
	最大(2)	3.14	3.98	5.68	7.22	8.72	10.22	13.27	16.27	18.27	21.33	30.33
	最小	2.86	3.62	5.32	6.78	8.28	9.78	12.73	15.73	17.73	20.67	29.67
da	最大	2.0	2.6	3.6	4.7	5.7	6.8	9.2	11.2	13.7	15.7	22.4
ds	最大(基準寸法)	1.6	2	3.00	4.00	5.00	6.00	8.00	10.00	12.00	14.00	20.00
	最小	1.46	1.86	2.86	3.82	4.82	5.82	7.78	9.78	11.73	13.73	19.67
k	最大(基準寸法)	1.60	2.00	3.00	4.00	5.00	6.00	8.00	10.00	12.00	14.00	20.00
	最小	1.46	1.86	2.86	3.82	4.82	5.70	7.64	9.64	11.57	13.57	19.48
r	最小	0.1	0.1	0.1	0.2	0.2	0.25	0.4	0.4	0.6	0.6	0.8
S	呼び	1.5	1.5	2.5	3.0	4.0	5.0	6.0	8.0	10.0	12.0	17.0
	最大	1.58	1.58	2.58	3.08	4.095	5.14	6.14	8.175	10.175	12.212	17.23
	最小	1.52	1.52	2.52	3.02	4.020	5.02	6.02	8.025	10.025	12.032	17.05
t	最小	0.7	1	1.3	2	2.5	3	4	5	6	7	10
v	最大	0.16	0.2	0.3	0.4	0.5	0.6	0.8	1.0	1.2	1.6	2.0

(1) ローレットがない頭部に適用する。(2) ローレットがある頭部に適用する。

M1.6			M2.0			M3.0							M4.0											
長さ	入り数	鉄	長さ	入り数	鉄	鉄						ステンレス	長さ	入り数	鉄						ステンレス			
						生地	コバルト	クロメイト	三価ホウ素	ニッケル	亜鉛黒				生地	コバルト	クロメイト	三価ホウ素	ニッケル	亜鉛黒				
8	1000×40	●	6	1000×40	●	4	1000×24	●	●	●	●	●	●	●	4	1000×18	●	●	●	●	●	●	●	●
10	1000×40	●	8	1000×40	●	5	1000×24	●	●	●	●	●	●	●	5	1000×18	●	●	●	●	●	●	●	●
			10	1000×40	●	6	1000×24	●	●	●	●	●	●	●	6	1000×18	●	●	●	●	●	●	●	●
			16	1000×40	●	8	1000×24	●	●	●	●	●	●	●	8	1000×15	●	●	●	●	●	●	●	●
						10	1000×24	●	●	●	●	●	●	●	10	1000×15	●	●	●	●	●	●	●	●
						12	1000×24	●	●	●	●	●	●	●	12	1000×12	●	●	●	●	●	●	●	●
						14	1000×24	●	●	●	●	●	●	●	14	1000×12	●	●	●	●	●	●	●	●
						15	1000×24	●	●	●	●	●	●	●	15	1000×12	●	●	●	●	●	●	●	●
						16	1000×24	●	●	●	●	●	●	●	16	1000×12	●	●	●	●	●	●	●	●
						18	1000×18	●	●	●	●	●	●	●	18	500×18	●	●	●	●	●	●	●	●
						20	1000×18	●	●	●	●	●	●	●	20	500×18	●	●	●	●	●	●	●	●
						22	500×24	●	●	●	●	●	●	●	22	500×18	●	●	●	●	●	●	●	●
						25	500×24	●	●	●	●	●	●	●	25	500×18	●	●	●	●	●	●	●	●
						30	500×24	●	●	●	●	●	●	●	30	400×15	●	●	●	●	●	●	●	●
						35	500×18	●	●	●	●	●	●	●	35	400×15	●	●	●	●	●	●	●	●
						40	500×15	●	●	●	●	●	●	●	40	400×12	●	●	●	●	●	●	●	●
						45	500×12	●	●	●	●	●	●	●	45	400×12	●	●	●	●	●	●	●	●
						50	500×12	●	●	●	●	●	●	●	50	400×12	●	●	●	●	●	●	●	●
															55	400×8	●	●	●	●	●	●	●	●
															60	400×8	●	●	●	●	●	●	●	●
															65	300×8	●	●	●	●	●	●	●	●
															70	300×8	●	●	●	●	●	●	●	●
															75	300×8	●	●	●	●	●	●	●	●