

M12.0			
長さ	入り数	生地	ロックワッシャー
20	100×7	●	
25	100×7	●	●
30	100×7	●	●
35	100×6	●	●
40	50×12	●	●
45	50×1	●	●
50	50×12	●	●
55	50×1	●	●
60	50×7	●	●
65	50×1	●	●
70	50×1	●	●
75	50×1	●	●
80	50×1	●	
90	50×1	●	
100	50×1	●	
110	50×1	●	
120	50×1	●	
130	50×1	●	
140	50×1	●	
150	50×1	●	
160	50×1	●	

M14.0			
長さ	入り数	生地	
30	100×1	●	
35	50×1	●	
40	50×1	●	
45	50×1	●	
50	50×1	●	
55	50×1	●	
60	50×1	●	
65	50×1	●	
70	50×1	●	
75	50×1	●	
80	50×1	●	
90	50×1	●	
100	50×1	●	
110	50×1	●	
120	50×1	●	

M16.0			
長さ	入り数	生地	
25	25×1	●	
30	25×1	●	
35	25×12	●	
40	25×12	●	
45	25×12	●	
50	25×12	●	
55	25×1	●	
60	25×7	●	
65	25×7	●	
70	25×1	●	
75	25×1	●	
80	25×1	●	
90	25×1	●	
100	25×1	●	
110	25×1	●	
120	25×1	●	
130	25×1	●	
140	25×1	●	
150	25×1	●	
160	25×1	●	
180	25×1	●	

M18.0			
長さ	入り数	生地	
35	25×1	●	
40	25×1	●	
45	25×1	●	
50	25×1	●	
55	25×1	●	
60	25×1	●	
65	25×1	●	
70	25×1	●	
75	25×1	●	
80	25×1	●	
90	25×1	●	
100	25×1	●	
110	25×1	●	
120	25×1	●	

M20.0			
長さ	入り数	生地	ロックワッシャー
40	25×6	●	
45	25×6	●	
50	25×6	●	
55	25×6	●	
60	25×6	●	
65	25×1	●	
70	25×4	●	
75	25×1	●	
80	25×1	●	
90	25×1	●	●
100	25×1	●	
110	25×1	●	
120	25×1	●	
130	10×1	●	
140	10×1	●	
150	10×1	●	
160	10×1	●	
180	10×1	●	
200	5×1	●	
220	5×1	●	

M24.0			
長さ	入り数	生地	
40	10×1	●	
50	10×7	●	
55	10×1	●	
60	10×7	●	
65	10×1	●	
70	10×7	●	
75	10×1	●	
80	10×6	●	
90	10×6	●	
100	10×1	●	
110	10×1	●	
120	10×1	●	
130	10×1	●	
140	10×1	●	
150	10×1	●	
160	10×1	●	
180	10×1	●	
200	5×1	●	

M27.0			
長さ	入り数	生地	
100	1×15	●	

M30.0			
長さ	入り数	生地	
80	1×10	●	
90	1×10	●	
100	1×10	●	
110	1×10	●	
120	1×10	●	


M30.0			
長さ	入り数	生地	
130	1×10	●	
140	1×10	●	
150	1×10	●	
160	1×10	●	
180	1×10	●	

ステンレス 六角穴付きボルト (キャップスクリュー) 岸和田ステンレス製



A002000S

ステンレス

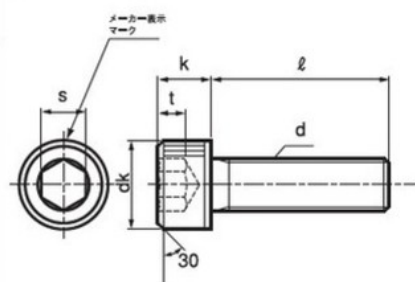

ねじの呼び ピッチ		M5	M6	M8	M10	M12
dk	最大 (基準寸法)	8.5	10	13	16	18
	最大	8.72	10.22	13.27	16.27	18.27
	最小	8.28	9.78	12.73	15.73	17.73
k	最大 (基準寸法)	5	6	8	10	12
	最小	4.82	5.7	7.64	9.64	11.57
s	呼び (基準寸法)	4	5	6	8	10
	最小	4.02	5.02	6.02	8.025	10.025
t	最小	2.5	3	4	5	6

M5.0			
長さ	入り数	生地	
10	400×16	●	
12	400×16	●	
14	400×10	●	
15	400×10	●	
16	400×10	●	
18	400×10	●	
20	400×10	●	
25	300×10	●	
30	300×10	●	

M6.0			
長さ	入り数	生地	
10	200×20	●	
12	200×20	●	
14	200×20	●	
15	200×16	●	
16	200×16	●	
18	200×16	●	
20	200×16	●	
25	200×12	●	
30	200×12	●	
35	200×12	●	
40	200×8	●	
45	200×8	●	
50	200×8	●	

M8.0			
長さ	入り数	生地	
15	100×16	●	
16	100×16	●	
18	100×16	●	
20	100×16	●	
22	100×12	●	
25	100×12	●	
30	100×12	●	
35	100×12	●	
40	100×8	●	
45	100×8	●	
50	100×8	●	

M10.0			
長さ	入り数	生地	
15	100×10	●	
16	100×10	●	
18	100×8	●	
20	100×8	●	
22	100×8	●	
25	100×8	●	
30	50×12	●	
35	50×12	●	
40	50×12	●	
45	50×10	●	
50	50×10	●	

M12.0			
長さ	入り数	生地	
20	50×12	●	
25	50×10	●	
30	50×10	●	
35	50×8	●	
40	50×8	●	
45	50×8	●	
50	40×8	●	