

六角穴付きボルト(キャップスクリュー) (ウィット)




A0000002

A0020002

鉄

ステンレス

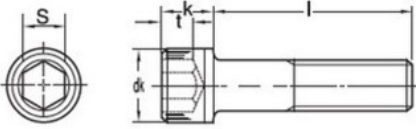

| 呼び | dk | | k | | s | | t |
|--------|------|------------|------|------------|------|-----------------|-----|
| | 基準寸法 | 許容差 | 基準寸法 | 許容差 | 基準寸法 | 許容差 | 最小 |
| W 3/16 | 7.7 | 0 -0.28 | 4.8 | 0 -0.13 | 4 | +0.02 +0.095 | 2.6 |
| W 1/4 | 10 | 0 -0.15 | 6.5 | 0 -0.36 | 5 | +0.03 +0.10 | 3 |
| W 5/16 | 13 | 0 | 8 | 0 -0.18 | 6 | +0.04 +0.13 | 4 |
| W 3/8 | 14 | 0 | 10 | | 8 | | 5 |
| W 1/2 | 18 | 0 | 12.5 | | 10 | | 6.5 |
| W 5/8 | 24 | 0 -0.21 | 16 | 0 -0.43 | 14 | +0.15 +0.16 | 8 |
| W 3/4 | 27 | 0 -0.52 | 19 | 0 -0.52 | | +0.05 +0.16 | 9.5 |

| W3/16 | | | |
|-------|--------|---|-------|
| 長さ | 入り数 | 鉄 | ステンレス |
| 18 | 500×10 | ● | |
| 30 | 200×16 | ● | |
| 45 | 200×8 | ● | |

| W1/4 | | | |
|------|--------|---|-------|
| 長さ | 入り数 | 鉄 | ステンレス |
| 10 | 200×16 | ● | |
| 12 | 200×16 | ● | |
| 15 | 200×16 | ● | |
| 16 | 200×1 | ● | |
| 16 | 200×16 | ● | |
| 20 | 200×1 | ● | |
| 20 | 200×16 | ● | |
| 22 | 200×10 | ● | |
| 25 | 200×1 | ● | |
| 25 | 200×10 | ● | |
| 30 | 200×1 | ● | |
| 30 | 200×8 | ● | |
| 32 | 100×16 | ● | |
| 35 | 100×1 | ● | |
| 35 | 100×16 | ● | |
| 40 | 100×16 | ● | |
| 45 | 100×10 | ● | |
| 50 | 100×10 | ● | |

| W5/16 | | | |
|-------|--------|---|-------|
| 長さ | 入り数 | 鉄 | ステンレス |
| 8 | 100×25 | ● | |
| 10 | 100×25 | ● | |
| 12 | 100×25 | ● | |
| 15 | 100×16 | ● | |
| 16 | 100×16 | ● | |
| 18 | 100×16 | ● | |
| 20 | 100×1 | ● | |
| 20 | 100×16 | ● | |
| 22 | 100×10 | ● | |
| 25 | 100×1 | ● | |
| 25 | 100×10 | ● | |
| 30 | 100×1 | ● | |
| 30 | 100×10 | ● | |
| 35 | 100×10 | ● | |
| 40 | 100×1 | ● | |
| 40 | 100×8 | ● | |
| 45 | 100×8 | ● | |
| 50 | 100×1 | ● | |
| 50 | 100×8 | ● | |
| 55 | 100×5 | ● | |
| 60 | 100×5 | ● | |
| 70 | 100×5 | ● | |
| 85 | 100×5 | ● | |
| 95 | 50×8 | ● | |

| W3/8 | | | |
|------|--------|---|-------|
| 長さ | 入り数 | 鉄 | ステンレス |
| 10 | 100×16 | ● | |
| 12 | 100×16 | ● | |
| 15 | 100×10 | ● | |
| 16 | 100×1 | ● | |
| 16 | 100×10 | ● | |
| 18 | 100×10 | ● | |
| 20 | 100×1 | ● | |
| 20 | 100×10 | ● | |
| 25 | 100×10 | ● | |
| 25 | 100×2 | ● | |
| 30 | 100×8 | ● | |
| 30 | 50×2 | ● | |
| 35 | 100×8 | ● | |
| 35 | 50×2 | ● | |
| 40 | 100×5 | ● | |
| 40 | 50×1 | ● | |
| 45 | 100×5 | ● | |
| 50 | 100×5 | ● | |
| 50 | 50×1 | ● | |
| 55 | 100×5 | ● | |
| 55 | 50×1 | ● | |
| 60 | 100×5 | ● | |
| 70 | 50×8 | ● | |
| 75 | 50×1 | ● | |
| 75 | 50×8 | ● | |
| 80 | 50×8 | ● | |
| 85 | 50×8 | ● | |
| 90 | 50×5 | ● | |
| 100 | 50×5 | ● | |

| W7/16 | | | |
|-------|-------|---|-------|
| 長さ | 入り数 | 鉄 | ステンレス |
| 30 | 100×1 | ● | |
| 35 | 100×1 | ● | |
| 40 | 100×1 | ● | |
| 45 | 100×1 | ● | |
| 50 | 100×1 | ● | |

| W1/2 | | | |
|------|-------|---|-------|
| 長さ | 入り数 | 鉄 | ステンレス |
| 20 | 100×5 | ● | |
| 25 | 100×5 | ● | |
| 25 | 50×1 | ● | |
| 30 | 100×5 | ● | |
| 30 | 50×1 | ● | |
| 35 | 50×1 | ● | |
| 35 | 50×8 | ● | |
| 40 | 50×1 | ● | |
| 40 | 50×8 | ● | |
| 45 | 50×8 | ● | |
| 50 | 50×1 | ● | |
| 50 | 50×5 | ● | |
| 55 | 50×1 | ● | |
| 55 | 50×5 | ● | |
| 60 | 25×1 | ● | |
| 60 | 50×5 | ● | |
| 65 | 50×5 | ● | |
| 70 | 50×5 | ● | |
| 75 | 50×5 | ● | |
| 80 | 50×5 | ● | |
| 85 | 50×5 | ● | |
| 90 | 25×8 | ● | |
| 100 | 25×8 | ● | |
| 120 | 25×8 | ● | |
| 125 | 25×8 | ● | |

| W5/8 | | | |
|------|-------|---|-------|
| 長さ | 入り数 | 鉄 | ステンレス |
| 25 | 40×1 | ● | |
| 25 | 50×8 | ● | |
| 30 | 40×1 | ● | |
| 30 | 50×8 | ● | |
| 35 | 40×1 | ● | |
| 35 | 50×7 | ● | |
| 40 | 30×1 | ● | |
| 40 | 50×10 | ● | |
| 45 | 40×7 | ● | |
| 50 | 30×1 | ● | |
| 50 | 40×10 | ● | |
| 60 | 40×7 | ● | |
| 60 | 50×10 | ● | |
| 65 | 30×5 | ● | |

| W5/8 | | | |
|------|-------|---|-------|
| 長さ | 入り数 | 鉄 | ステンレス |
| 65 | 35×10 | ● | |
| 70 | 30×1 | ● | |
| 75 | 30×10 | ● | |
| 75 | 30×5 | ● | |
| 80 | 30×7 | ● | |
| 100 | 25×1 | ● | |
| 125 | 25×1 | ● | |

| W3/4 | | | |
|------|-------|---|-------|
| 長さ | 入り数 | 鉄 | ステンレス |
| 40 | 20×1 | ● | |
| 40 | 40×3 | ● | |
| 45 | 30×4 | ● | |
| 50 | 15×1 | ● | |
| 50 | 30×4 | ● | |
| 55 | 30×4 | ● | |
| 60 | 30×4 | ● | |
| 65 | 30×4 | ● | |
| 70 | 25×4 | ● | |
| 75 | 25×4 | ● | |
| 80 | 25×4 | ● | |
| 90 | 20×10 | ● | |