


六角穴付きボルト(UNC)キャップスクリュー

9/16				5/8				5/8				3/4				7/8				1"				
長さ	入り数	鉄	ステンレス	長さ	入り数	鉄	ステンレス	長さ	入り数	鉄	ステンレス	長さ	入り数	鉄	ステンレス	長さ	入り数	鉄	ステンレス	長さ	入り数	鉄	ステンレス	
1"	10×1	●	●	1"	10×1	●	●	3 ¹ / ₄ "	10×1	●	●	1 ¹ / ₄ "	10×1	●	●	2"	10×1	●	●	2"	10×1	●	●	
1 ¹ / ₄ "	10×1	●	●	1"	40×1	●	●	3 ¹ / ₄ "	15×1	●	●	1 ¹ / ₂ "	10×1	●	●	2 ¹ / ₄ "	10×1	●	●	2 ¹ / ₄ "	10×1	●	●	
1 ¹ / ₂ "	10×1	●	●	1 ¹ / ₄ "	10×1	●	●	3-1/2"	10×1	●	●	1 ¹ / ₂ "	15×10	●	●	2 ¹ / ₂ "	10×1	●	●	2 ¹ / ₂ "	10×1	●	●	
1 ³ / ₄ "	10×1	●	●	1 ¹ / ₄ "	40×1	●	●	3-1/2"	15×1	●	●	1 ³ / ₄ "	10×1	●	●	2 ³ / ₄ "	10×1	●	●	2 ³ / ₄ "	10×1	●	●	
2"	10×1	●	●	1 ¹ / ₂ "	10×1	●	●	4"	10×1	●	●	2"	10×1	●	●	3"	10×1	●	●	3"	10×1	●	●	
2 ¹ / ₄ "	10×1	●	●	1 ¹ / ₂ "	30×1	●	●	4"	15×1	●	●	2"	15×1	●	●	3 ¹ / ₄ "	10×1	●	●	3 ¹ / ₄ "	10×1	●	●	
2 ¹ / ₂ "	10×1	●	●	1 ³ / ₄ "	10×1	●	●	4 ¹ / ₂ "	10×1	●	●	2 ¹ / ₄ "	10×1	●	●	3-1/2"	10×1	●	●	3-1/2"	10×1	●	●	
2 ³ / ₄ "	10×1	●	●	1 ³ / ₄ "	30×1	●	●	4 ¹ / ₂ "	12×1	●	●	2 ¹ / ₄ "	20×1	●	●	4"	10×1	●	●	4"	10×1	●	●	
3"	10×1	●	●	2"	10×1	●	●	5"	10×1	●	●	2 ¹ / ₂ "	10×1	●	●	4 ¹ / ₂ "	10×1	●	●	4 ¹ / ₂ "	10×1	●	●	
3-1/2"	10×1	●	●	2"	30×1	●	●	5"	12×1	●	●	2 ¹ / ₂ "	15×1	●	●	5"	10×1	●	●	5"	10×1	●	●	
4"	10×1	●	●	2 ¹ / ₄ "	10×1	●	●	5 ¹ / ₂ "	10×1	●	●	2 ³ / ₄ "	10×1	●	●	5 ¹ / ₂ "	10×1	●	●	5 ¹ / ₂ "	10×1	●	●	
4 ¹ / ₂ "	10×1	●	●	2 ¹ / ₄ "	25×1	●	●	5 ¹ / ₂ "	12×1	●	●	3"	10×1	●	●	6"	10×1	●	●	6"	10×1	●	●	
5"	10×1	●	●	2 ¹ / ₂ "	10×1	●	●	6"	10×1	●	●	3"	15×1	●	●	6 ¹ / ₂ "	10×1	●	●	6 ¹ / ₂ "	10×1	●	●	
				2 ¹ / ₂ "	25×1	●	●	6 ¹ / ₂ "	10×1	●	●	3 ¹ / ₄ "	10×1	●	●	7"	10×1	●	●	7"	10×1	●	●	
				2 ³ / ₄ "	10×1	●	●	7"	10×1	●	●	3-1/2"	10×1	●	●	7"	10×1	●	●	7"	10×1	●	●	
				2 ³ / ₄ "	20×1	●	●	8"	10×1	●	●	4"	10×1	●	●	8"	10×1	●	●	8"	10×1	●	●	
				3"	10×1	●	●					4 ¹ / ₂ "	10×1	●	●					9"	10×1	●	●	
				3"	20×1	●	●					5"	10×1	●	●					10"	10×1	●	●	
												5"	8×1	●	●									
												5 ¹ / ₂ "	10×1	●	●									
												6"	10×1	●	●									
												6 ¹ / ₂ "	10×1	●	●									
												7"	10×1	●	●									
												8"	10×1	●	●									

六角穴付きボルト(UNF)キャップスクリュー



A0000040	A0020040
鉄	ステンレス

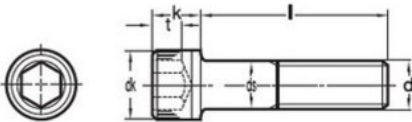

サイズ	UNF #0-80	UNF #1-72	UNF #2-64	UNF #3-56	UNF #4-48	UNF #5-44	UNF #6-40	UNF #8-36	UNF #10-32	UNF #12-28	UNF 1/4-28	UNF 5/16-24	UNF 3/8-24	UNF 7/16-20	UNF 1/2-20	UNF 9/16-18	UNF 3/4-16
d	約 1.5	1.8	2.1	2.5	2.8	3.1	3.5	4.1	4.8	5.4	6.3	7.9	9.5	11.0	12.7	14.2	19.0
ds	最大	1.524	1.854	2.184	2.514	2.844	3.175	3.505	4.165	4.826	5.486	6.35	7.937	9.525	11.112	12.7	14.287
	最小	1.442	1.765	2.087	2.410	2.730	3.053	3.375	4.025	4.673	5.334	6.184	7.754	9.342	10.906	12.494	14.066
dk	最大	2.438	2.997	3.556	4.089	4.648	5.207	5.740	6.858	7.924	8.229	9.525	11.912	14.274	16.662	19.05	21.412
	最小	2.311	2.844	3.403	3.911	4.470	5.029	5.537	6.654	7.696	7.975	9.271	11.607	13.97	16.306	18.669	21.005
k	最大	1.524	1.854	2.184	2.514	2.844	3.175	3.505	4.165	4.826	5.486	6.35	7.924	9.525	11.125	12.7	14.274
	最小	1.447	1.778	2.108	2.413	2.743	3.073	3.403	4.038	4.699	5.334	6.197	7.772	9.347	10.922	12.496	14.071
t	最小	0.635	0.787	0.965	1.117	1.295	1.447	1.625	1.955	2.286	2.616	3.048	3.835	4.622	5.410	6.223	6.604
六角穴サイズ	六角レンチ	0.050	1/16	5/64	5/64	3/32	3/32	7/64	9/64	5/32	5/32	3/16	1/4	5/16	3/8	3/8	7/16

#0				#1				#2				#3				#4						
長さ	入り数	鉄	ステンレス	長さ	入り数	鉄	ステンレス	長さ	入り数	鉄	ステンレス	長さ	入り数	鉄	ステンレス	長さ	入り数	鉄	ステンレス			
3/32	100×1	●	●	1/8	100×1	●	●	1/8	100×1	●	●	3/16	100×1	●	●	1/8	100×1	●	●			
1/8	100×1	●	●	3/16	100×1	●	●	3/16	100×1	●	●	1/4	100×1	●	●	3/16	100×1	●	●			
1/8	500×20	●	●	1/4	100×1	●	●	1/4	100×1	●	●	5/16	100×1	●	●	1/4	100×1	●	●			
5/32	100×1	●	●	5/16	100×1	●	●	5/16	100×1	●	●	3/8	100×1	●	●	5/16	100×1	●	●			
3/16	100×1	●	●	3/8	100×1	●	●	3/8	100×1	●	●	1/2	100×1	●	●	3/8	100×1	●	●			
3/16	1000×39	●	●	1/2	100×1	●	●	1/2	100×1	●	●	5/8	100×1	●	●	1/2	100×1	●	●			
1/4	100×1	●	●	5/8	100×1	●	●	5/8	100×1	●	●	3/4	100×1	●	●	5/8	100×1	●	●			
5/16	100×1	●	●	3/4	100×1	●	●	3/4	100×1	●	●	1"	100×1	●	●	3/4	100×1	●	●			
3/8	100×1	●	●	7/8	100×1	●	●	1"	100×1	●	●					7/8	100×1	●	●			
1/2	100×1	●	●	1"	100×1	●	●									1"	100×1	●	●			
5/8	100×1	●	●													1 ¹ / ₄ "	100×1	●	●			
3/4	100×1	●	●													1 ¹ / ₂ "	100×1	●	●			
1"	100×1	●	●																			