


六角穴付きボタンボルト (ボタンキャップスクリュー)(JIS-B1174)



小ねじ
マフクロねじ
組込みねじ
タツピンねじ
タツタイト
ハイエタねじ
いたすら防止ねじ
建材用スクリュー
ボルト
キャップ・ホーロー
ドリルねじ
座金
つまみねじ
ナット
樹脂製品
アンカーボルト

A0021000
ステンレス

A0091000
チタン

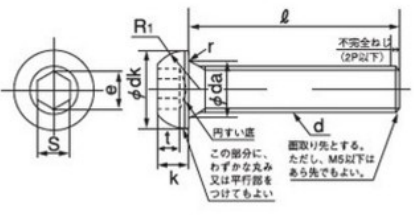

ねじの呼び d	頭部径 dk		頭部高さ k		六角二面幅 S		六角深さ t	
	基準寸法	許容差	基準寸法	許容差	基準寸法	許容差	基準寸法	許容差
M2	3.5	0 -0.3	1.15	±0.15	1.3	0 -0.25	0.7	±0.10
M2.5			1.35		1.5	+0.060 +0.010	0.9	
M3	5.5		2.0		2.0	+0.080 +0.020	1.4	±0.15
M4	7.5		2.6		2.5		1.8	
M5	9.5	0 -0.4	3.4	±0.20	3.0	2.4	±0.20	
M8	14.0	0 -0.5	5.0		5.0	+0.105 +0.030		3.5
M10	18.0		6.0		6.0	+0.130 +0.040		4.2
M12	21.0	0 -0.6	7.0		8.0			4.9

長さ	M2.0		ステンレス 生地 (ハネロ)スロ	チタン
	入り数			
3	1000×20		●	●
3	500×39		●	●
4	1000×20		●	●
4	500×39		●	●
5	1000×20		●	●
5	500×39		●	●
6	1000×20		●	●
6	500×39		●	●
8	1000×20		●	●
8	500×39		●	●
10	1000×20		●	●
10	500×39		●	●
12	1000×20		●	●
12	500×39		●	●
14	500×39		●	●
15	500×39		●	●
16	500×39		●	●
18	500×39		●	●
20	500×39		●	●

長さ	M2.5		ステンレス 生地 B.K.F.メッシュ	チタン
	入り数			
3	500×39		●	●
4	1000×20		●	●
4	500×39		●	●
5	1000×20		●	●
5	500×39		●	●
6	1000×20		●	●
6	500×39		●	●
8	1000×20		●	●
8	500×39		●	●
10	1000×20		●	●
10	500×39		●	●
12	500×39		●	●
14	500×39		●	●
15	500×39		●	●
16	500×39		●	●
20	500×27		●	●

長さ	M3.0		ステンレス 生地 B.K.F.メッシュ	チタン
	入り数			
4	500×39		●	●
5	500×39		●	●
6	1000×14		●	●
6	500×39		●	●
7	500×39		●	●
8	1000×14		●	●
8	500×39		●	●
10	1000×14		●	●
10	500×39		●	●
12	1000×14		●	●
12	500×39		●	●
14	500×27		●	●
15	1000×14		●	●
15	500×27		●	●
16	1000×14		●	●
16	500×27		●	●
18	500×27		●	●
20	1000×14		●	●
20	500×27		●	●
22	500×15		●	●
25	500×15		●	●
30	500×15		●	●
35	500×15		●	●
40	500×10		●	●
45	500×10		●	●
50	500×10		●	●

長さ	M4.0		ステンレス 生地 (ハネロ)スロ	チタン
	入り数			
4	500×39		●	●
5	500×39		●	●
6	500×39		●	●
8	1000×14		●	●
8	500×27		●	●
10	1000×14		●	●
10	500×27		●	●
12	1000×14		●	●
12	500×27		●	●
14	500×15		●	●
15	1000×14		●	●
15	500×15		●	●
16	1000×14		●	●
16	500×15		●	●
18	500×15		●	●
20	1000×14		●	●
20	500×15		●	●
22	500×10		●	●
25	1000×14		●	●
25	500×10		●	●
30	1000×14		●	●
30	500×10		●	●
35	500×10		●	●
40	200×15		●	●
45	200×15		●	●
50	200×15		●	●

長さ	M5.0		ステンレス 生地 B.K.F.メッシュ	チタン
	入り数			
6	500×15		●	●
8	1000×14		●	●
8	500×15		●	●
10	500×10		●	●
10	500×15		●	●
12	500×10		●	●
12	500×15		●	●
14	500×10		●	●
15	500×10		●	●
16	500×10		●	●
18	500×10		●	●
20	500×10		●	●
22	200×15		●	●
25	200×15		●	●
25	500×10		●	●
30	200×15		●	●
30	500×10		●	●
35	200×15		●	●
40	200×15		●	●
45	200×10		●	●
50	200×10		●	●
55	200×10		●	●
65	200×10		●	●
70	200×10		●	●
75	200×10		●	●

長さ	M6.0		ステンレス 生地 (ハネロ)スロ	チタン
	入り数			
6	500×15		●	●
8	500×10		●	●
8	500×15		●	●
10	500×10		●	●
12	500×10		●	●
14	500×10		●	●
15	500×10		●	●
16	500×10		●	●
18	500×10		●	●
20	200×15		●	●
20	500×10		●	●
22	200×15		●	●
25	200×15		●	●
25	500×10		●	●
30	200×15		●	●
30	500×10		●	●
35	200×10		●	●
40	200×10		●	●
45	200×10		●	●
50	200×10		●	●

長さ	M8.0		チタン
	入り数		
12	200×10		●
15	200×10		●
16	200×10		●
20	200×10		●
25	200×10		●
30	250×10		●

長さ	M12.0		ステンレス
	入り数		
16	100×10		●