

六角穴付きボタンボルト (UNF) (ボタンキャップスクリュー)




A0001040

鉄

A0021040

ステンレス

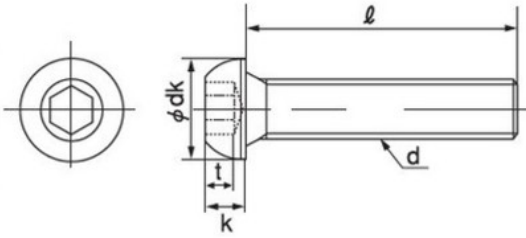

サイズ		UNF #0-80	UNF #1-72	UNF #10-32	UNF 1/4-28	UNF 5/16-24	UNF 3/8-24
呼び径-山数 / 1インチあたり	約	1.5	1.8	4.8	6.3	7.9	9.5
d	最大	2.895	3.530	9.169	11.099	13.893	16.662
	最小	2.641	3.276	8.813	10.642	13.385	16.154
dk	最大	0.812	0.990	2.565	3.352	4.216	5.054
	最小	0.660	0.838	2.311	3.098	3.860	4.699
t	最小	0.508	0.711	1.778	2.209	2.667	3.098
六角穴サイズ	六角レンチ	0.035	0.050	1/8	5/32	3/16	7/32

#0		
長さ	入り数	鉄 ● ●
1/8	100×1	● ●
3/16	100×1	● ●
1/4	100×1	● ●
5/16	100×1	● ●
3/8	100×1	● ●
1/2	100×1	● ●

#1		
長さ	入り数	鉄 ● ●
1/8	100×1	● ●
3/16	100×1	● ●
1/4	100×1	● ●
5/16	100×1	● ●
3/8	100×1	● ●

#10		
長さ	入り数	鉄 ● ●
1/4	100×1	● ●
5/16	100×1	● ●
3/8	100×1	● ●
7/16	100×1	● ●
1/2	100×1	● ●
5/8	100×1	● ●
3/4	100×1	● ●
7/8	100×1	● ●
1"	100×1	● ●
1 1/4"	100×1	● ●
1 1/2"	100×1	● ●
1 3/4"	100×1	● ●
2"	100×1	● ●
2 1/2"	100×1	● ●

1/4		
長さ	入り数	鉄 ● ●
3/8	100×1	● ●
1/2	100×1	● ●
5/8	100×1	● ●
3/4	100×1	● ●
7/8	100×1	● ●
1"	100×1	● ●
1 1/4"	100×1	● ●
1 1/2"	100×1	● ●
1 3/4"	100×1	● ●
2"	100×1	● ●

5/16		
長さ	入り数	鉄 ● ●
1/2	50×1	● ●
5/8	50×1	● ●
3/4	50×1	● ●
7/8	50×1	● ●
1"	50×1	● ●
1 1/4"	50×1	● ●
1 1/2"	50×1	● ●
2"	50×1	● ●


3/8		
長さ	入り数	鉄 ● ●
5/8	50×1	● ●
3/4	50×1	● ●
1"	50×1	● ●
1 1/4"	50×1	● ●
1 1/2"	50×1	● ●

鋼 六角穴付きボタンボルト (UNC) (ボタンキャップスクリュー) アンブラコ製



A000103P

鉄

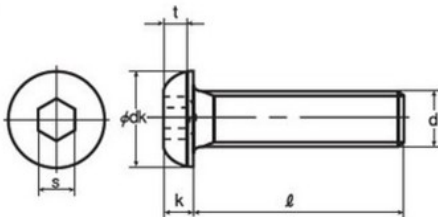

サイズ	インチ当り山数		dk	d	t	k	s
	UNC	UNF	最大	最大	最小	最大	スパナ径
#4	40	48	5.410	2.845	0.889	1.499	1/16
#6	32	40	6.655	3.505	1.118	1.854	5/64
#8	32	36	7.925	4.166	1.321	2.210	3/32
#10	24	32	9.169	4.826	1.778	2.565	1/8
1/4	20	28	11.100	6.350	2.210	3.353	5/32
5/16	18	24	13.894	7.925	2.667	4.216	3/16
3/8	16	24	16.662	9.525	3.099	5.055	7/32
1/2	13	20	22.225	12.700	4.445	6.731	5/16
5/8	11	18	25.400	15.875	5.334	8.407	3/8

#4		
長さ	入り数	生地 ● ●
1/4	100×1	● ●
3/8	100×1	● ●
1/2	100×1	● ●

#6		
長さ	入り数	生地 ● ●
1/4	100×1	● ●
3/8	100×1	● ●
1/2	100×1	● ●
5/8	100×1	● ●

#8		
長さ	入り数	生地 ● ●
1/4	100×1	● ●
3/8	100×1	● ●
1/2	100×1	● ●
5/8	100×1	● ●
3/4	100×1	● ●

#10		
長さ	入り数	生地 ● ●
1/4	100×1	● ●
3/8	100×1	● ●
1/2	100×1	● ●
5/8	100×1	● ●
3/4	100×1	● ●
1"	100×1	● ●

1/4		
長さ	入り数	生地 ● ●
3/8	100×1	● ●
1/2	100×1	● ●
5/8	100×1	● ●
3/4	100×1	● ●
1"	100×1	● ●

5/16		
長さ	入り数	生地 ● ●
3/8	100×1	● ●
1/2	100×1	● ●
5/8	100×1	● ●
3/4	100×1	● ●

3/8		
長さ	入り数	生地 ● ●
1/2	100×1	● ●
5/8	100×1	● ●
3/4	100×1	● ●
1"	100×1	● ●
1 1/4"	100×1	● ●

1/2		
長さ	入り数	生地 ● ●
1"	50×1	● ●
1 1/4"	50×1	● ●
1 1/2"	50×1	● ●
2"	50×1	● ●

5/8		
長さ	入り数	生地 ● ●
1 1/4"	25×1	● ●
1 1/2"	25×1	● ●
2"	25×1	● ●