


六角穴付き皿ボルト (皿キャップスクリュー)(SSS規格)



A0002000	A0022000	A0122000	A0092000
鉄	ステンレス	SUS 316L	チタン

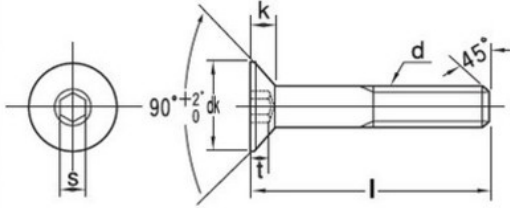

ねじの呼び(d)	M2	M2.5	M3	M4	M5	M6	M8	M10	M12	M16	M20
ピッチ	0.4	0.45	0.5	0.7	0.8	1.0	1.25	1.5	1.75	2	2.5
dk	基準寸法	4	5	6	8	10	12	16	20	24	30
	許容差	0 -0.3		0 -0.36		0 -0.43		0 -0.52		0 -0.62	
k	寸法	1.00 ~1.20	1.25 ~1.50	1.56 ~1.70	2.16 ~2.3	2.66 ~2.80	3.12 ~3.3	4.22 ~4.4	5.32 ~5.5	6.5 ~6.72	7.5 ~7.72
s	寸法	1.27 ~1.30	1.51 ~1.56	2.02 ~2.08	2.52 ~2.58	3.02 ~3.08	4.03 ~4.105	5.03 ~5.105	6.03 ~6.105	8.04 ~8.13	10.04 ~10.13
t	寸法	0.60 ~0.75	0.60 ~0.80	0.95 ~1.20	1.55 ~1.80	2.05 ~2.30	2.25 ~2.50	3.2 ~3.5	4.1 ~4.4	4.3 ~4.6	5.0 ~5.3

M2.0					
長さ	入り数	鉄			チタン
		生地	三層メッキ	SUS 316L	
3	1000×1			●	
3	500×39		●		
4	1000×20				●
4	500×39	●	●		
5	1000×20				●
5	500×39	●	●		
6	1000×20				●
6	500×39	●	●		
8	1000×20				●
8	500×39	●	●		
10	1000×20				●
10	500×39	●	●		
12	1000×20				●
12	500×39	●	●		
15	500×39		●		
16	500×39		●		

M2.5					
長さ	入り数	鉄			チタン
		生地	三層メッキ	SUS 316L	
4	500×39	●	●		
5	1000×20				●
5	500×39	●	●		
6	1000×20				●
6	500×39	●	●		
8	1000×20				●
8	500×39	●	●		
10	500×39	●	●		
12	500×39	●	●		
15	500×39		●		
20	500×27		●		

M3.0								
長さ	入り数	鉄				ステンレス		チタン
		生地	メッキ	クロメート	亜鉛黒	生地	B7(2025)	
4	500×39					●	●	
5	500×39					●	●	
6	1000×14							●
6	500×39					●	●	
7	500×39					●	●	
8	1000×14							●
8	500×39					●	●	
10	1000×14							●
10	500×39					●	●	
12	1000×14							●
12	500×39					●	●	
14	1000×20	●	●	●	●			
14	500×39					●	●	
15	1000×14							●
15	500×39					●	●	
16	1000×14							●
16	500×39					●	●	
18	500×27					●	●	
20	1000×14							●
20	500×27					●	●	
22	500×15					●	●	
25	500×15					●	●	
25	500×20	●	●	●	●			
30	500×15					●	●	
35	500×15					●	●	
40	500×15					●	●	
45	500×10					●	●	
50	500×10					●	●	

M4.0							
長さ	入り数	鉄			ステンレス		チタン
		生地	三層メッキ	SUS 316L	生地	B7(2025)	
5	500×39	●	●				
6	500×39	●	●				
8	1000×14						●
8	1000×20						●
8	500×39	●	●				
10	1000×14						●
10	1000×20						●
10	500×27	●	●				
12	1000×14						●
12	1000×20						●
12	500×27	●	●				
14	500×27	●	●				
15	1000×14						●
15	500×27	●	●				
16	1000×14						●
16	1000×15						●
16	500×27	●	●				
18	500×15	●	●				
20	1000×14						●
20	500×15	●	●				
20	500×20						●
22	500×15	●	●				
25	1000×14						●
25	500×15	●	●				
30	1000×14						●
30	500×10	●	●				
35	500×10	●	●				
40	500×10	●	●				
45	200×15	●	●				
50	200×15	●	●				
55	200×15	●	●				
60	200×15	●	●				
65	200×15	●	●				
70	100×20	●	●				