

六角穴付き皿ボルト(皿キャップスクリュー) (全ねじ)日星精工製




A000201C

鉄

A002201C

ステンレス

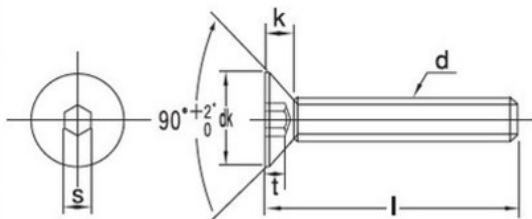

ねじの呼び(d)		M14
dk	基準寸法	27
	許容差	0 -0.27
K	基準寸法	7
S	基準寸法	10
	許容差	+0.175 +0.025
t	最大	4.8
	最小	4.5

14.0			
長さ	入り数	鉄	ステンレス
60	25×8	●	●
65	25×8	●	●
70	20×8	●	●
75	20×8	●	●
80	20×8	●	●
85	20×8	●	●
90	20×8	●	●
95	15×8	●	●
100	15×8	●	●

六角穴付き皿ボルト(UNC)(皿キャップ スクリュー)




A0002030

鉄

A0022030

ステンレス

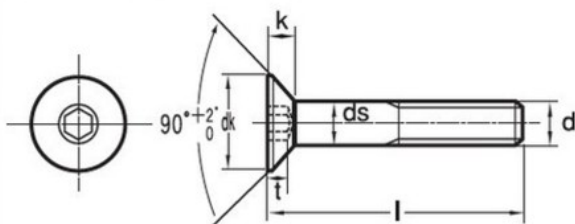

サイズ		UNC #2-56	UNC #3-48	UNC #4-40	UNC #5-40	UNC #6-32	UNC #8-32	UNC #10-24	UNC 1/4-20	UNC 5/16-18	UNC 3/8-16	UNC 7/16-14	UNC 1/2-13	UNC 5/8-11	UNC 3/4-10
d	約	2.1	2.5	2.8	3.1	3.5	4.1	4.8	6.3	7.9	9.5	11.0	12.7	15.8	19.0
ds	最大	2.184	2.514	2.844	3.175	3.505	4.165	4.826	6.35	7.937	9.525	11.112	12.7	15.875	19.05
	最小	2.087	2.410	2.730	3.053	3.375	4.025	4.673	6.184	7.754	9.342	10.906	12.494	15.654	18.81
dk	最大	5.003	5.740	6.477	7.137	7.797	9.118	10.439	13.487	16.662	19.837	21.437	23.825	30.175	36.525
	最小	4.267	4.902	5.537	6.096	6.680	7.899	9.118	12.192	15.24	18.288	19.837	22.148	28.244	34.417
k	参考	1.625	1.854	2.108	2.286	2.463	2.844	3.225	4.089	5.029	5.943	5.943	6.375	8.229	10.058
t	最小	0.965	1.117	1.397	1.549	1.676	1.930	2.209	2.819	3.429	4.038	4.038	4.368	5.588	5.588
六角穴サイズ	六角レンチ	0.050	1/16	1/16	5/64	5/64	3/32	1/8	5/32	3/16	7/32	1/4	5/16	3/8	1/2

#2			
長さ	入り数	鉄	ステンレス
3/16	100×1	●	●
1/4	100×1	●	●
5/16	100×1	●	●
3/8	100×1	●	●
1/2	100×1	●	●
5/8	100×1	●	●
3/4	100×1	●	●
1"	100×1	●	●

#3			
長さ	入り数	鉄	ステンレス
1/4	100×1	●	●
5/16	100×1	●	●
3/8	100×1	●	●
1/2	100×1	●	●

#4			
長さ	入り数	鉄	ステンレス
3/16	100×1	●	●
1/4	100×1	●	●
5/16	100×1	●	●
3/8	100×1	●	●
7/16	100×1	●	●
1/2	100×1	●	●
5/8	100×1	●	●
3/4	100×1	●	●
7/8	100×1	●	●
1"	100×1	●	●
1 1/4	100×1	●	●

#5			
長さ	入り数	鉄	ステンレス
3/16	100×1	●	●
1/4	100×1	●	●
5/16	100×1	●	●
3/8	100×1	●	●
1/2	100×1	●	●
5/8	100×1	●	●
3/4	100×1	●	●
1"	100×1	●	●

#6			
長さ	入り数	鉄	ステンレス
1/4	100×1	●	●
5/16	100×1	●	●
3/8	100×1	●	●
1/2	100×1	●	●
5/8	100×1	●	●
3/4	100×1	●	●
7/8	100×1	●	●
1"	100×1	●	●
1 1/4	100×1	●	●
1 1/2	100×1	●	●
2"	100×1	●	●