


# 六角穴付き止めねじ(ホーローセット) (くぼみ先)



小ねじ  
マフロねじ  
組込みねじ  
タツピンねじ  
タツタイト  
ハイテックねじ  
いたすら防止ねじ  
建材用スクリーン  
ボルト  
キャップ・ボルト  
ドリルねじ  
座金  
つまみねじ  
ナット  
樹脂製品  
アンカーボルト

A0005000 鉄	A0025000 ステンレス	A0125000 SUS 316L	A0095000 チタン
---------------	-------------------	----------------------	-----------------

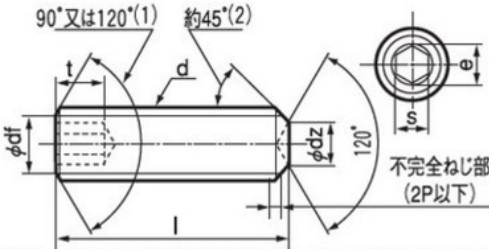

注(1) げ下の表に示す階段状の点線より短いものは、120°の面取りとする。  
 (2) 45°の角度は、おねじの谷の径より下の傾斜部に適用する。

ねじの呼び(d)	M1.2	M1.6 (1.7)	M2	M2.5 (2.6)	M3	M4	M5	M6	M8	M10	M12	M14	M16	M18	M20	M24		
ピッチ(p)	0.3	0.35	0.4	0.45	0.5	0.7	0.8	1.0	1.25	1.5	1.75	2.0	2.0	2.5	2.5	3.0		
dz	最大(基準寸法)	0.7	0.8	1	1.2	1.4	2	2.5	3	5	6	8	9	10	12	13	16	
	最小	0.45	0.55	0.75	0.96	1.15	1.75	2.25	2.75	4.7	5.7	7.64	8.64	9.64	11.57	12.57	15.57	
df	約																	
e	おねじの谷径																	
s	最小	0.803	0.803	1.003	1.427	1.73	2.3	2.87	3.44	4.58	5.72	6.86	—	9.15	—	11.43	13.72	
	呼び(基準寸法)	0.7	0.7	0.9	1.3	1.5	2	2.5	3	4	5	6	6	8	8	10.0	12.0	
	最大	0.711	0.711	0.889	1.27	1.52	2.02	2.52	3.02	4.02	5.02	6.02	6.02	8.025	8.025	10.025	12.032	
t	最小	1欄	0.6	0.7	0.8	1.2	1.2	1.5	2	2	3	4	4.8	5.6	6.4	7.2	8.0	10.0
		2欄	1.4	1.5	1.7	2	2	2.5	3	3.5	5	6	8	9	10	11	12.0	15.0

M1.4		
長さ	入り数	材質
2.5	100×45	●
3	100×45	●
4	100×45	●
5	100×45	●
6	100×45	●

M1.6					
長さ	入り数	材質			
		生地	鉄	ステンレス	チタン
2	1000×39	●	●	●	●
		●	●	●	●
2.5	1000×39	●	●	●	●
		●	●	●	●
2.5	1000×45	●	●	●	●
		●	●	●	●
3	1000×39	●	●	●	●
		●	●	●	●
3	1000×45	●	●	●	●
		●	●	●	●
4	1000×39	●	●	●	●
		●	●	●	●
4	1000×45	●	●	●	●
		●	●	●	●
5	1000×39	●	●	●	●
		●	●	●	●
5	1000×45	●	●	●	●
		●	●	●	●
6	1000×39	●	●	●	●
		●	●	●	●
6	1000×45	●	●	●	●
		●	●	●	●
8	1000×39	●	●	●	●
		●	●	●	●
8	1000×45	●	●	●	●
		●	●	●	●

M2.0											
長さ	入り数	材質									
		生地	クロム	クロム	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	ステンレス	チタン
2	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
2.5	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
3	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
4	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
5	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
6	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
8	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
10	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
15	2000×1	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
16	2000×1	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●

M2.3		
長さ	入り数	材質
3	2000×10	●
4	2000×10	●
5	2000×10	●
6	2000×10	●

M2.5											
長さ	入り数	材質									
		生地	クロム	クロム	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	ステンレス	チタン
2	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
2.5	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
3	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
4	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
5	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
6	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
8	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
10	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
12	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
12	2000×14	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
15	1000×14	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●

M2.6											
長さ	入り数	材質									
		生地	クロム	クロム	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	ステンレス	チタン
2	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
2.5	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
3	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
4	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
5	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
6	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
8	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
10	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●
12	1000×45	●	●	●	●	●	●	●	●	●	●
		●	●	●	●	●	●	●	●	●	●