

六角穴付き止めねじ(ホーローセット) (とがり先)



A0005020


鉄

A0025020

ステンレス

A0125020

SUS 316L

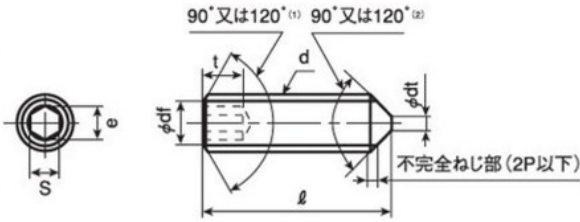

ねじの呼び (d)		M1.6	M2	M2.5 (2.6)	M3	M4	M5	M6	M8	M10	M12	M16
ピッチ (p)		0.35	0.4	0.45	0.5	0.7	0.8	1.0	1.25	1.5	1.75	2.0
dt	最大 (基準寸法)	0.16	0.2	0.25	0.3	0.4	0.5	1.5	2	2.5	3	4
	最小							0.9	1.4	1.9	2.4	3.25
df	約	おねじの谷径										
e	最小	0.803	1.003	1.427	1.73	2.3	2.87	3.44	4.58	5.72	6.86	9.15
	呼び (基準寸法)	0.7	0.9	1.3	1.5	2	2.5	3	4	5	6	8
s	最小	0.711	0.889	1.27	1.52	2.02	2.52	3.02	4.02	5.02	6.02	8.025
	最大	0.724	0.902	1.295	1.545	2.045	2.56	3.08	4.095	5.095	6.095	8.115
t	最小	1欄	0.7	0.8	1.2	1.2	1.5	2	3	4	4.8	6.4
		2欄	1.5	1.7	2	2	2.5	3	3.5	5	6	10

M2.0													
長さ	入り数	鉄								ステンレス			
		生地	クロロ	クロネイト	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	スズパル	黒ツケル	生地	Ｂドラン
2	1000×39											●	●
2	1000×45	●	●	●	●	●	●	●	●	●	●	●	●
3	1000×39											●	●
3	1000×45	●	●	●	●	●	●	●	●	●	●	●	●
4	1000×39											●	●
4	1000×45	●	●	●	●	●	●	●	●	●	●	●	●
5	1000×39											●	●
5	1000×45	●	●	●	●	●	●	●	●	●	●	●	●
6	1000×39											●	●
6	1000×45	●	●	●	●	●	●	●	●	●	●	●	●
8	1000×39											●	●
8	1000×45	●	●	●	●	●	●	●	●	●	●	●	●
10	1000×39											●	●
12	1000×39											●	●

M2.5													
長さ	入り数	鉄								ステンレス			
		生地	クロロ	クロネイト	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	スズパル	黒ツケル	生地	Ｂドラン
3	1000×39											●	●
3	1000×45	●	●	●	●	●	●	●	●	●	●	●	●
4	1000×39											●	●
4	1000×45	●	●	●	●	●	●	●	●	●	●	●	●
5	1000×39											●	●
5	1000×45	●	●	●	●	●	●	●	●	●	●	●	●
6	1000×39											●	●
6	1000×45	●	●	●	●	●	●	●	●	●	●	●	●
8	1000×39											●	●
8	1000×45	●	●	●	●	●	●	●	●	●	●	●	●

M2.6													
長さ	入り数	鉄								ステンレス			
		生地	クロロ	クロネイト	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	スズパル	黒ツケル	生地	Ｂドラン
2.5	1000×39											●	●
3	1000×39											●	●
3	1000×45	●	●	●	●	●	●	●	●	●	●	●	●
3.5	1000×45	●	●	●	●	●	●	●	●	●	●	●	●
4	1000×39											●	●
4	1000×45	●	●	●	●	●	●	●	●	●	●	●	●
5	1000×39											●	●
5	1000×45	●	●	●	●	●	●	●	●	●	●	●	●
6	1000×39											●	●
6	1000×45	●	●	●	●	●	●	●	●	●	●	●	●
8	1000×39											●	●
8	1000×45	●	●	●	●	●	●	●	●	●	●	●	●