

# 六角穴付きボルト(キャップスクリュー) I=3(SW+ISO W組込) 富信製




A0009130

A0029130

鉄

ステンレス

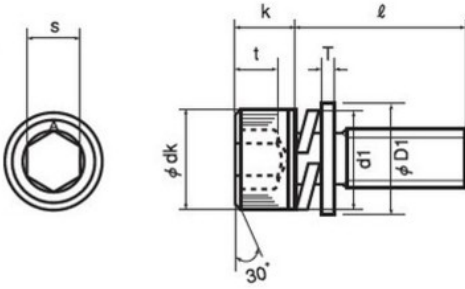

ねじの呼び		M2	M2.5 (2.6)	M3	M4	M5	M6	M8
ピッチ		0.4	0.45	0.5	0.7	0.8	1.0	1.25
b	参考	16	17	18	20	22	24	28
dk	基準寸法	3.8	4.5	5.5	7	8.5	10	13
	最大	3.98	4.68	5.68	7.22	8.72	10.22	13.27
	最小	3.62	4.32	5.32	6.78	8.28	9.78	12.73
k	基準寸法	2	2.5 (2.6)	3	4	5	6	8
	最小	1.86	2.36 (2.46)	2.86	3.82	4.82	5.7	7.64
	最大	2.14	2.64 (2.74)	3.64	4.6	5.6	6.5	8.48
s	基準寸法	1.5	2	2.5	3	4	5	6
	最小	1.52	2.02	2.52	3.02	4.02	5.02	6.02
t	最小	1	1.1	1.3	2	2.5	3	4
平座金D1×T		5×0.3	6.5×0.5	7×0.5	9×0.8	10×1.0	12.5×1.6	17×1.6
ばね座金 d1 (最大)		4	4.8	5.5	7	8.5	11.5	14.5
座面からネジ部までの最大値		2.1	2.7	3.0	4.4	5.4	6.9	8.4

2.0		鉄							ステンレス			
長さ	入り数	生地	クロメ	クロメコート	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	スズハルト	生地	ロクロ
		4	1000×27	●	●	●	●	●	●	●	●	●
5	1000×27	●	●	●	●	●	●	●	●	●	●	●
6	1000×27	●	●	●	●	●	●	●	●	●	●	●
8	1000×27	●	●	●	●	●	●	●	●	●	●	●
10	1000×27	●	●	●	●	●	●	●	●	●	●	●
12	1000×27	●	●	●	●	●	●	●	●	●	●	●

M2.5		ステンレス	
長さ	入り数	生地	ロクロ
		5	1000×27
6	1000×27	●	●
8	1000×27	●	●
10	1000×27	●	●
12	1000×15	●	●

2.6		鉄							ステンレス			
長さ	入り数	生地	クロメ	クロメコート	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	スズハルト	生地	ロクロ
		5	1000×27	●	●	●	●	●	●	●	●	●
6	1000×27	●	●	●	●	●	●	●	●	●	●	●
8	1000×27	●	●	●	●	●	●	●	●	●	●	●
10	1000×27	●	●	●	●	●	●	●	●	●	●	●
12	1000×15	●	●	●	●	●	●	●	●	●	●	●

3.0		鉄							ステンレス			
長さ	入り数	生地	クロメ	クロメコート	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	スズハルト	生地	ロクロ
		4	1000×15	●	●	●	●	●	●	●	●	●
5	1000×15	●	●	●	●	●	●	●	●	●	●	●
6	1000×15	●	●	●	●	●	●	●	●	●	●	●
8	1000×15	●	●	●	●	●	●	●	●	●	●	●
10	1000×15	●	●	●	●	●	●	●	●	●	●	●
12	1000×15	●	●	●	●	●	●	●	●	●	●	●
14	1000×10	●	●	●	●	●	●	●	●	●	●	●
15	1000×10	●	●	●	●	●	●	●	●	●	●	●
16	1000×10	●	●	●	●	●	●	●	●	●	●	●
18	1000×10	●	●	●	●	●	●	●	●	●	●	●
20	1000×10	●	●	●	●	●	●	●	●	●	●	●
22	1000×10	●	●	●	●	●	●	●	●	●	●	●
25	1000×10	●	●	●	●	●	●	●	●	●	●	●
30	1000×10	●	●	●	●	●	●	●	●	●	●	●

4.0		鉄							ステンレス			
長さ	入り数	生地	クロメ	クロメコート	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	スズハルト	生地	ロクロ
		6	1000×10	●	●	●	●	●	●	●	●	●
8	1000×10	●	●	●	●	●	●	●	●	●	●	●
10	1000×10	●	●	●	●	●	●	●	●	●	●	●
12	1000×10	●	●	●	●	●	●	●	●	●	●	●
14	500×10	●	●	●	●	●	●	●	●	●	●	●
15	500×10	●	●	●	●	●	●	●	●	●	●	●
16	500×10	●	●	●	●	●	●	●	●	●	●	●
18	500×10	●	●	●	●	●	●	●	●	●	●	●
20	500×10	●	●	●	●	●	●	●	●	●	●	●
22	500×10	●	●	●	●	●	●	●	●	●	●	●
25	500×10	●	●	●	●	●	●	●	●	●	●	●
30	500×10	●	●	●	●	●	●	●	●	●	●	●
35	500×5	●	●	●	●	●	●	●	●	●	●	●
40	500×5	●	●	●	●	●	●	●	●	●	●	●
45	400×5	●	●	●	●	●	●	●	●	●	●	●
50	400×5	●	●	●	●	●	●	●	●	●	●	●