

# WAソケット Sタイプ 日産ネジ製




小ねじ  
マフロねじ  
組込みねじ  
タッピンねじ  
タツタイド  
ハイエタねじ  
いたすら防止ねじ  
建材用スクリーン  
ボルト  
キャップ・ホーロー  
ドリルねじ  
座金  
つまみねじ  
ナット  
樹脂製品  
アンカーボルト

A0009520

A0029520

鉄

ステンレス

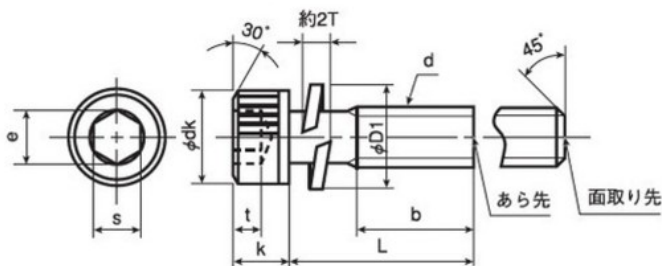

ねじの呼び (d)		並目	M3	M4	M5	M6	M8	M10	M12	
6角穴付きボルト本体	dk		5.5±0.18	7±0.22	8.5±0.22	10±0.22	13±0.27	16±0.27	18±0.27	
	k		3 <sup>0</sup> <sub>-0.14</sub>	4 <sup>0</sup> <sub>-0.18</sub>	5 <sup>0</sup> <sub>-0.18</sub>	6 <sup>0</sup> <sub>-0.3</sub>	8 <sup>0</sup> <sub>-0.36</sub>	10 <sup>0</sup> <sub>-0.36</sub>	12 <sup>0</sup> <sub>-0.43</sub>	
	s	呼び(基準寸法)		2.5	3	4	5	6	8	10
		最小		2.52	3.02	4.02	5.02	6.02	8.025	10.025
		1欄		2.58	3.08	4.095	5.14	6.14	8.175	10.175
		2欄		2.56	3.08	4.095	5.095	6.095	8.115	10.115
		e(最小)		2.87	3.44	4.58	5.72	6.86	9.15	11.43
	t(最大)		1.3	2	2.5	3	4	5	6	
ばね座金	2号	D1(最大)	5.5	7	8.5	11.5	14.5	17.5	20.5	
		B(最小)×T(最小)	1.1×0.7	1.4×1	1.7×1.3	2.7×1.5	3.2×2	3.7×2.5	4.2×3	
		圧力試験後の自由高さ(最小)	1.2	1.7	2.2	2.5	3.35	4.2	5	

M3.0		鉄								ステンレス
長さ	入り数	生地	ユアロ	クロメイト	三価ホワイト	ニッケル	クローム	亜鉛黒	ダクロ	スヘパルト
5	1000×24	●	●	●	●	●	●	●	●	●
6	1000×24	●	●	●	●	●	●	●	●	●
7	1000×24	●	●	●	●	●	●	●	●	●
8	1000×24	●	●	●	●	●	●	●	●	●
10	1000×24	●	●	●	●	●	●	●	●	●
12	1000×24	●	●	●	●	●	●	●	●	●
14	1000×18	●	●	●	●	●	●	●	●	●
15	1000×18	●	●	●	●	●	●	●	●	●
16	1000×18	●	●	●	●	●	●	●	●	●
18	1000×18	●	●	●	●	●	●	●	●	●
20	1000×18	●	●	●	●	●	●	●	●	●
25	1000×12	●	●	●	●	●	●	●	●	●
30	1000×12	●	●	●	●	●	●	●	●	●

M4.0		鉄								ステンレス
長さ	入り数	生地	ユアロ	クロメイト	三価ホワイト	ニッケル	クローム	亜鉛黒	ダクロ	スヘパルト
6	1000×15	●	●	●	●	●	●	●	●	●
8	1000×15	●	●	●	●	●	●	●	●	●
10	1000×12	●	●	●	●	●	●	●	●	●
12	1000×12	●	●	●	●	●	●	●	●	●
14	1000×12	●	●	●	●	●	●	●	●	●
15	1000×12	●	●	●	●	●	●	●	●	●
16	1000×12	●	●	●	●	●	●	●	●	●
18	1000×10	●	●	●	●	●	●	●	●	●
20	1000×10	●	●	●	●	●	●	●	●	●
22	500×15	●	●	●	●	●	●	●	●	●
25	500×15	●	●	●	●	●	●	●	●	●
30	500×12	●	●	●	●	●	●	●	●	●
35	500×12	●	●	●	●	●	●	●	●	●
40	500×12	●	●	●	●	●	●	●	●	●
45	500×10	●	●	●	●	●	●	●	●	●
50	400×10	●	●	●	●	●	●	●	●	●

M5.0		鉄								ステンレス
長さ	入り数	生地	ユアロ	クロメイト	三価ホワイト	ニッケル	クローム	亜鉛黒	ダクロ	スヘパルト
8	500×18	●	●	●	●	●	●	●	●	●
10	500×15	●	●	●	●	●	●	●	●	●
12	500×15	●	●	●	●	●	●	●	●	●
14	500×12	●	●	●	●	●	●	●	●	●
15	500×12	●	●	●	●	●	●	●	●	●
16	500×12	●	●	●	●	●	●	●	●	●
18	500×12	●	●	●	●	●	●	●	●	●
20	400×12	●	●	●	●	●	●	●	●	●
25	400×12	●	●	●	●	●	●	●	●	●
30	300×12	●	●	●	●	●	●	●	●	●
35	300×12	●	●	●	●	●	●	●	●	●
40	300×12	●	●	●	●	●	●	●	●	●
45	300×10	●	●	●	●	●	●	●	●	●
50	300×10	●	●	●	●	●	●	●	●	●

M6.0		鉄								ステンレス
長さ	入り数	生地	ユアロ	クロメイト	三価ホワイト	ニッケル	クローム	亜鉛黒	ダクロ	スヘパルト
10	400×12	●	●	●	●	●	●	●	●	●
12	400×12	●	●	●	●	●	●	●	●	●
14	400×10	●	●	●	●	●	●	●	●	●
15	400×10	●	●	●	●	●	●	●	●	●
16	400×10	●	●	●	●	●	●	●	●	●
18	400×10	●	●	●	●	●	●	●	●	●
20	400×10	●	●	●	●	●	●	●	●	●
22	300×10	●	●	●	●	●	●	●	●	●
25	300×10	●	●	●	●	●	●	●	●	●
30	300×10	●	●	●	●	●	●	●	●	●
35	200×12	●	●	●	●	●	●	●	●	●
40	200×12	●	●	●	●	●	●	●	●	●