

小ねじ
マフクロねじ
組込みねじ
タッピンねじ
タツタイト
ハイエウねじ
いたすら防止ねじ
建材用スクリーナ
ボルト
キャップ・ホーロー
ドリルねじ
座金
つまみねじ
ナット
樹脂製品
アンカーボルト

M4.0											
長さ	入り数	鉄							ステンレス		
		生地	コクロ	クロメート	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	スズメタル	生地
6	100×20	●	●	●	●	●	●	●	●	●	●
8	100×20	●	●	●	●	●	●	●	●	●	●
10	100×20	●	●	●	●	●	●	●	●	●	●
12	100×20	●	●	●	●	●	●	●	●	●	●
16	100×20	●	●	●	●	●	●	●	●	●	●

M5.0											
長さ	入り数	鉄							ステンレス		
		生地	コクロ	クロメート	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	スズメタル	生地
6	100×20	●	●	●	●	●	●	●	●	●	●
8	100×20	●	●	●	●	●	●	●	●	●	●
10	100×20	●	●	●	●	●	●	●	●	●	●
12	100×20	●	●	●	●	●	●	●	●	●	●
16	100×20	●	●	●	●	●	●	●	●	●	●
20	100×20	●	●	●	●	●	●	●	●	●	●

M6.0											
長さ	入り数	鉄							ステンレス		
		生地	コクロ	クロメート	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	スズメタル	生地
6	100×20	●	●	●	●	●	●	●	●	●	●
8	100×20	●	●	●	●	●	●	●	●	●	●
10	100×20	●	●	●	●	●	●	●	●	●	●
12	100×20	●	●	●	●	●	●	●	●	●	●
16	100×20	●	●	●	●	●	●	●	●	●	●
20	100×20	●	●	●	●	●	●	●	●	●	●
25	100×20	●	●	●	●	●	●	●	●	●	●
30	100×20	●	●	●	●	●	●	●	●	●	●


M8.0											
長さ	入り数	鉄							ステンレス		
		生地	コクロ	クロメート	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	スズメタル	生地
8	100×20	●	●	●	●	●	●	●	●	●	●
10	100×20	●	●	●	●	●	●	●	●	●	●
12	100×20	●	●	●	●	●	●	●	●	●	●
16	100×20	●	●	●	●	●	●	●	●	●	●
20	100×20	●	●	●	●	●	●	●	●	●	●
25	100×20	●	●	●	●	●	●	●	●	●	●
30	100×20	●	●	●	●	●	●	●	●	●	●

M10.0											
長さ	入り数	鉄							ステンレス		
		生地	コクロ	クロメート	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	スズメタル	生地
10	100×20	●	●	●	●	●	●	●	●	●	●
12	100×20	●	●	●	●	●	●	●	●	●	●
16	100×20	●	●	●	●	●	●	●	●	●	●
20	100×20	●	●	●	●	●	●	●	●	●	●
25	100×14	●	●	●	●	●	●	●	●	●	●
25	100×20	●	●	●	●	●	●	●	●	●	●
30	100×10	●	●	●	●	●	●	●	●	●	●

極薄NSローヘッド 日産ネジ製



A000L300 鉄
A002L300 ステンレス

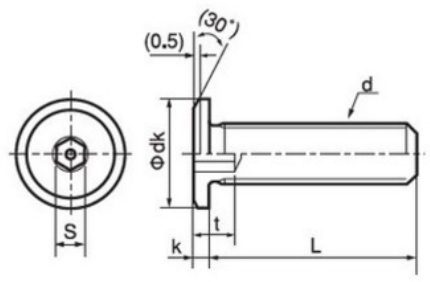

ねじの呼び (d)	ピッチ P	dk	k	S	t
		頭部径	頭部高さ	六角穴対辺	六角穴深さ
M3	0.5	6	1.3	1.5	MIN 1.2
M4	0.7	8	1.5	2.0	MIN 1.7
M5	0.8	9	1.5	3.0	MIN 1.8
M6	1.0	10	1.5	3.0	MIN 2.5
M8	1.25	13	1.5	4.0	MIN 4.2
M10	1.5	16	1.5	5.0	MIN 4.2

M3.0											
長さ	入り数	鉄							ステンレス		
		生地	コクロ	クロメート	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	スズメタル	生地
5	1000×24	●	●	●	●	●	●	●	●	●	●
6	1000×24	●	●	●	●	●	●	●	●	●	●
8	1000×24	●	●	●	●	●	●	●	●	●	●
10	1000×24	●	●	●	●	●	●	●	●	●	●
12	1000×24	●	●	●	●	●	●	●	●	●	●

M4.0											
長さ	入り数	鉄							ステンレス		
		生地	コクロ	クロメート	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	スズメタル	生地
6	1000×18	●	●	●	●	●	●	●	●	●	●
8	1000×15	●	●	●	●	●	●	●	●	●	●
8	1000×18	●	●	●	●	●	●	●	●	●	●
10	1000×15	●	●	●	●	●	●	●	●	●	●
10	1000×18	●	●	●	●	●	●	●	●	●	●
12	1000×12	●	●	●	●	●	●	●	●	●	●
16	1000×12	●	●	●	●	●	●	●	●	●	●
20	500×18	●	●	●	●	●	●	●	●	●	●

M5.0											
長さ	入り数	鉄							ステンレス		
		生地	コクロ	クロメート	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	スズメタル	生地
6	500×18	●	●	●	●	●	●	●	●	●	●
8	500×18	●	●	●	●	●	●	●	●	●	●
10	500×10	●	●	●	●	●	●	●	●	●	●
10	500×18	●	●	●	●	●	●	●	●	●	●
12	400×18	●	●	●	●	●	●	●	●	●	●
16	400×15	●	●	●	●	●	●	●	●	●	●
20	400×15	●	●	●	●	●	●	●	●	●	●
20	500×12	●	●	●	●	●	●	●	●	●	●
25	400×12	●	●	●	●	●	●	●	●	●	●

M6.0											
長さ	入り数	鉄							ステンレス		
		生地	コクロ	クロメート	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	スズメタル	生地
6	500×12	●	●	●	●	●	●	●	●	●	●
8	500×10	●	●	●	●	●	●	●	●	●	●
10	500×10	●	●	●	●	●	●	●	●	●	●
12	500×10	●	●	●	●	●	●	●	●	●	●
16	400×12	●	●	●	●	●	●	●	●	●	●
20	400×10	●	●	●	●	●	●	●	●	●	●
25	200×15	●	●	●	●	●	●	●	●	●	●
30	200×15	●	●	●	●	●	●	●	●	●	●
35	200×12	●	●	●	●	●	●	●	●	●	●

M8.0											
長さ	入り数	鉄							ステンレス		
		生地	コクロ	クロメート	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	スズメタル	生地
8	200×18	●	●	●	●	●	●	●	●	●	●
10	200×18	●	●	●	●	●	●	●	●	●	●
12	200×12	●	●	●	●	●	●	●	●	●	●
16	200×10	●	●	●	●	●	●	●	●	●	●
20	200×10	●	●	●	●	●	●	●	●	●	●
25	100×18	●	●	●	●	●	●	●	●	●	●
30	100×15	●	●	●	●	●	●	●	●	●	●
35	100×15	●	●	●	●	●	●	●	●	●	●

M10.0											
長さ	入り数	鉄							ステンレス		
		生地	コクロ	クロメート	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	スズメタル	生地
10	100×15	●	●	●	●	●	●	●	●	●	●
12	200×12	●	●	●	●	●	●	●	●	●	●
16	100×12	●	●	●	●	●	●	●	●	●	●
20	100×12	●	●	●	●	●	●	●	●	●	●
25	100×10	●	●	●	●	●	●	●	●	●	●
30	100×10	●	●	●	●	●	●	●	●	●	●
35	100×8	●	●	●	●	●	●	●	●	●	●