


鋼 TORX穴付き止めねじTORX-HS (くぼみ先)



小ねじ
マフロねじ
組込みねじ
タツピンねじ
タツタイト
ハイエタねじ
いたすら防止ねじ
建材用スクリュー
ホルト
キャップ・ホーロー
ドリルねじ
座金
つまみねじ
ナット
樹脂製品
アンカーホルト

A000T500

鉄

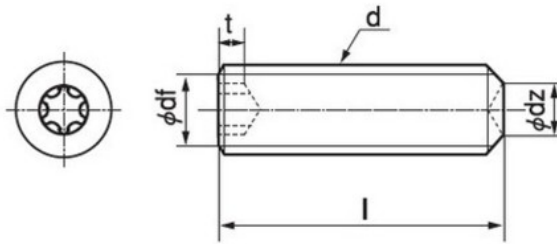

ねじの呼び		M3	M4
ピッチ		0.5	0.7
dz	最大 (基準寸法)	1.4	2.0
	最小(約)	1.15	1.75
t	最小(約)	0.9	1.1
ドライブサイズ		T6	T8

M3.0			M4.0		
ねじの長さ	入り数	仕様	ねじの長さ	入り数	仕様
3	2000×40	●	4	2000×40	●
4	2000×40	●	5	2000×40	●
5	2000×40	●	6	2000×24	●
6	2000×40	●	8	2000×24	●
8	2000×40	●	10	2000×18	●

エア抜きキャップスクリュー (全ねじ)



A002J000


ステンレス

A012J000

SUS 316L

A009J000

チタン

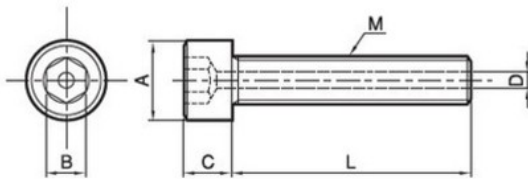

	A	B	C	D
M3	φ 5.5	2.5	3.0	φ 1.5
M4	φ 7.0	3.0	4.0	φ 1.5
M5	φ 8.5	4.0	5.0	φ 1.5
M6	φ 10.0	5.0	6.0	φ 2.0
M8	φ 13.0	6.0	8.0	φ 2.0
M10	φ 16.0	8.0	10.0	φ 2.0
M12	φ 18.0	10.0	12.0	φ 3.0
M16	φ 24.0	14.0	16.0	φ 3.0

ねじの長さ	M3.0		ステンレス	SUS 316L	チタン
	入り数	仕様			
5	200×20	●	●		
6	100×20	●	●		●
6	200×20	●	●		
8	100×20	●	●		●
8	200×20	●	●		●
10	100×20	●	●		●
10	200×20	●	●		
12	100×20	●	●		●
12	200×20	●	●		●
15	100×20	●	●		●
15	200×20	●	●		●
16	200×20	●	●		
18	200×20	●	●		
20	200×20	●	●		
25	100×20	●	●		
30	100×20	●	●		
35	100×20	●	●		

長さ	M4.0		ステンレス	SUS 316L	チタン
	入り数	仕様			
4	200×20	●	●		
5	200×20	●	●		●
6	200×20	●	●		
8	200×20	●	●		●
10	100×20	●	●		●
10	200×20	●	●		●
12	100×20	●	●		●
12	200×20	●	●		●
15	100×20	●	●		●
15	200×20	●	●		●
16	100×20	●	●		●
16	200×20	●	●		
18	200×20	●	●		
20	100×20	●	●		●
20	200×20	●	●		●
22	150×20	●	●		●
25	100×20	●	●		
30	100×20	●	●		
35	100×20	●	●		
40	100×20	●	●		

長さ	M5.0		ステンレス	SUS 316L	チタン
	入り数	仕様			
6	200×20	●	●		
8	100×20	●	●		●
8	200×20	●	●		
10	100×20	●	●		●
10	200×20	●	●		●
12	100×20	●	●		●
12	200×20	●	●		●
14	200×20	●	●		
15	100×20	●	●		●
15	200×20	●	●		●
16	100×20	●	●		●
16	200×20	●	●		
18	200×20	●	●		
20	100×20	●	●		●
20	200×20	●	●		●
25	100×20	●	●		●
30	100×20	●	●		
35	100×20	●	●		
40	100×20	●	●		

長さ	M6.0		ステンレス	SUS 316L	チタン
	入り数	仕様			
6	200×20	●	●		
8	100×20	●	●		●
8	200×20	●	●		
10	100×20	●	●		●
10	200×20	●	●		●
12	100×20	●	●		●
12	200×20	●	●		●
14	200×20	●	●		
15	100×20	●	●		●
15	200×20	●	●		●
16	100×20	●	●		●
16	200×20	●	●		
18	200×20	●	●		
20	100×20	●	●		●
20	200×20	●	●		●
25	100×20	●	●		●
25	50×20	●	●		●
30	100×20	●	●		
35	100×20	●	●		
40	100×20	●	●		
45	100×20	●	●		
50	50×20	●	●		
55	50×20	●	●		

長さ	M8.0		ステンレス	SUS 316L	チタン
	入り数	仕様			
10	100×20	●	●		
10	50×20	●	●		●
12	50×20	●	●		●
15	100×20	●	●		●
15	50×20	●	●		●
16	100×20	●	●		●
16	50×20	●	●		●
18	80×20	●	●		
20	100×20	●	●		●
25	80×20	●	●		●
30	50×20	●	●		●
35	50×20	●	●		
40	50×20	●	●		
45	50×20	●	●		
50	50×20	●	●		
55	50×20	●	●		
60	50×20	●	●		
70	50×14	●	●		
75	50×14	●	●		
80	50×14	●	●		