

# ノルトロックワッシャー



W000N000


W002N000

W038N000

鉄

ステンレス

ステンレス254SMO

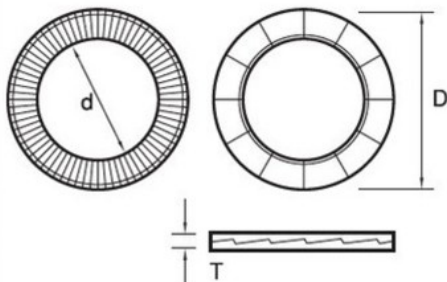

品番	NL3	NL3.5	NL4	NL5	NL6	NL1/4"	NL8	NL3/8"	NL10	NL11	NL12	NL1/2"
内径 (mm)	3.4	3.9	4.4	5.4	6.5	7.2	8.7	10.3	10.7	11.4	13.0	13.5
外形 (mm)	7.0	7.6	7.6	9.0	10.8	11.5	13.5	16.6	16.6	18.5	19.5	19.5
厚さ (mm)	鉄(SC材)	1.8	1.8	1.8	1.8	1.8	2.5	2.5	2.5	2.5	2.5	2.5
	SUS	2.2	2.2	2.2	2.2	2.2	2.0	2.0	2.0	2.2	2.0	2.0

品番	NL14	NL16	NL18	NL3/4"	NL20	NL22	NL24	NL1"	NL27	NL30	NL33	NL36
内径 (mm)	15.2	17.0	19.5	20.0	21.4	23.4	25.3	27.9	28.4	31.4	34.4	37.4
外形 (mm)	23.0	25.4	29.0	30.7	30.7	34.5	39.0	39.0	42.0	47.0	48.5	55.0
厚さ (mm)	鉄(SC材)	3.4	3.4	3.4	3.4	3.4	3.4	3.4	5.8	5.8	5.8	6.6
	SUS	3.0	3.0	3.2	3.2	3.0	3.2	3.2	6.8	6.8	6.8	6.8

品番	NL39	NL42	NL45	NL48	NL52	NL56	NL60	NL64	NL68	NL72	NL76	NL80
内径 (mm)	40.4	43.2	46.2	49.6	53.6	59.1	63.1	67.1	71.1	75.1	79.1	83.1
外形 (mm)	58.5	63.0	70.0	75.0	80.0	85.0	90.0	95.0	100.0	105.0	110.0	115.0
厚さ (mm)	鉄(SC材)	6.6	6.6	7.0	7.0	7.0	7.0	7.0	9.5	9.5	9.5	9.5
	SUS	6.8	6.8	6.8	6.8	9.0	9.0	9.0	9.0	9.0	9.0	9.0

品番	NL85	NL90	NL95	NL100	NL105	NL110	NL115	NL120	NL125	NL130
内径 (mm)	88.1	92.4	97.4	103.4	108.4	113.4	118.4	123.4	128.4	133.4
外形 (mm)	120.0	130.0	135.0	145.0	150.0	155.0	165.0	170.0	173.0	178.0
厚さ (mm)	鉄(SC材)	9.5	9.5	9.5	9.5	9.5	9.5	9.5	9.5	9.5

呼び	入り数	鉄				254SMO	
		クロメート	三福ホウト	アルミホウト	ステンレス	ステンレス	254SMO
1/4SS-254	200×20				●	●	
3/8SS-254	200×20			●	●	●	
1/2SS-254	200×20			●	●	●	
3/4SS-254	100×10			●	●	●	
1/4NL1/4SS	200×60			●	●	●	
1/2NL1/2SS	200×15			●	●	●	
1"NL1"SS	100×6			●	●	●	
M3(NL3SS)	200×60	●	●	●	●	●	
M4(NL4SS)	200×60			●	●	●	
M5(NL5SS)	200×60	●		●	●	●	
M6(NL6SS)	200×60			●	●	●	
M8(NL8SS)	200×40			●	●	●	
M12(NL12SS)	200×15			●	●	●	
M14(NL14SS)	100×15			●	●	●	
M16(NL16SS)	100×15	●		●	●	●	
M22(NL22SS)	100×6			●	●	●	
M24(NL24SS)	100×6			●	●	●	
M30(NL30SS)	50×4	●		●	●	●	
M33(NL33SS)	25×6			●	●	●	
M36(NL36SS)	25×6			●	●	●	
M39(NL39SS)	25×6	●	●	●	●	●	
M42(NL42SS)	25×6			●	●	●	
M45(NL45SS)	1×1	●		●	●	●	
M48(NL48SS)	1×1			●	●	●	
M52(NL52SS)	1×1	●		●	●	●	

呼び	入り数	鉄				254SMO	
		クロメート	三福ホウト	アルミホウト	ステンレス	ステンレス	254SMO
M56(NL56SS)	1×1			●	●	●	
M60(NL60SS)	1×1	●		●	●	●	
M64(NL64SS)	1×1	●		●	●	●	
M68(NL68SS)	1×1	●		●	●	●	
M72(NL72SS)	1×1	●		●	●	●	
M76(NL76SS)	1×1	●		●	●	●	
M80(NL80SS)	1×1	●		●	●	●	
M85(NL85)	1×1	●		●	●	●	
M90(NL90)	1×1	●		●	●	●	
M95(NL95)	1×1	●		●	●	●	
M100(NL100)	1×1	●		●	●	●	
M105(NL105)	1×1	●		●	●	●	
M110(NL110)	1×1	●		●	●	●	
M115(NL115)	1×1	●		●	●	●	
M120(NL120)	1×1	●		●	●	●	
M125(NL125)	1×1	●		●	●	●	
M130(NL130)	1×1	●		●	●	●	
1"SS-254	100×10					●	
NL3SS-254	200×20					●	
NL4SS-254	200×20					●	
NL5SS-254	200×20					●	
NL6SS-254	200×20					●	
NL8SS-254	200×20					●	
NL10SS-254	200×20			●	●	●	
NL11SS-254	200×20			●	●	●	

呼び	入り数	鉄				254SMO	
		クロメート	三福ホウト	アルミホウト	ステンレス	ステンレス	254SMO
NL12SS-254	100×10					●	
NL14SS-254	100×10					●	
NL16SS-254	100×10					●	
NL18SS-254	100×10			●	●	●	
NL20SS-254	100×10	●	●	●	●	●	
NL22SS-254	100×10					●	
NL24SS-254	100×10					●	
NL27SS-254	50×6	●		●	●	●	
NL30SS-254	50×6					●	
NL33SS-254	50×6					●	
NL36SS-254	50×6					●	
NL39SS-254	50×6					●	