

# テーパワッシャー (5°チャンネル用)



W000T000

W002T000

W011T000


W012T000

鉄

ステンレス

SUS 316

SUS 316L

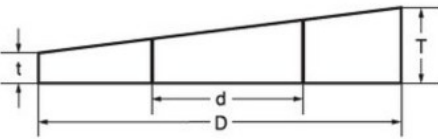

呼び径	d	D	T	t
M6	7	22	4.5	2.5
M8	9	22	4.5	2.5
M10	11	22	4.5	2.5
M12	14	26	4.5	2
M14	15.5	31	6	3
M16	17.5	31	6	3
M18	19.5	39	6	2.5
M20	22	39	6	2.5
M22	24	43	6	2
M24	26	48	7	2.5
M27	28	50	7	2.5
M30	32	58	8	3
M33	34	60	8	2.5
M36	38	68	9	2
M39	42	72	9	3
M42	45	78	12	4


呼び	入り数	鉄										SUS 316	SUS 316L
		生地	クロロ	クロメイト	三層ホワイト	三層ブラック	ニッケル	亜鉛黒	ドブ	グリーン	ステンレス		
M6-5° D16	500×10												
M6-5° D22	230×10	●	●	●	●	●	●	●	●	●	●		
M8-5° D18	500×10											●	
M8-5° D18	500×8												●
M8-5° D22	230×10	●	●	●	●	●	●	●	●	●	●		
M10-5° D22	230×10	●	●	●	●	●	●	●	●	●	●		
M10-5° D22	300×10											●	
M10-5° D22	300×8												●
M12-5° D25	150×10	●	●	●	●	●	●	●	●	●	●		
M12-5° D26	200×10											●	
M12-5° D26	200×8												●
M14-5° D31	80×10	●	●	●	●	●	●	●	●	●	●		
M14-5° D32	100×10											●	
M16-5° D31	80×10	●	●	●	●	●	●	●	●	●	●		
M16-5° D32	100×10											●	
M16-5° D32	100×8												●
M18-5° D39	70×10		●										
M18-5° D40	50×10	●	●	●	●	●	●	●	●	●	●		
M20-5° D40	50×10	●	●	●	●	●	●	●	●	●	●		
M20-5° D40	50×8												●
M22-5° D44	40×10	●	●	●	●	●	●	●	●	●	●		
M24-5° D50	30×10	●	●	●	●	●	●	●	●	●	●		
M27-5° D50	30×10	●	●	●	●	●	●	●	●	●	●		
M30-5° D60	20×10	●	●	●	●	●	●	●	●	●	●		
M33-5° D60	18×10			●									
M33-5° D60	20×10	●	●				●	●	●	●	●		
M36-5° D68	15×10											●	
M36-5° D68	20×10	●	●	●									
M42-5° D78	1×50	●	●	●									

# 鉄 テーパーワッシャー (8°アイビーム用)



W000T001

鉄

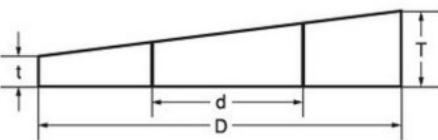

呼び径	d	D	T	t
M10	11	22	5	2
M12	14	26	6	2.5
M16	17.5	31	7	2.5
M20	22	39	8	2.5

呼び	入り数	生地	クロロ	クロメイト	三層ホワイト	三層ブラック	ニッケル	亜鉛黒	ドブ	グリーン
M8-8° D22	250×10	●	●	●	●	●	●	●	●	●
M10-8° D22	250×10	●	●	●	●	●	●	●	●	●
M12-8° D25	200×10	●	●	●	●	●	●	●	●	●
M16-8° D31	100×10	●	●	●	●	●	●	●	●	●
M18-8° D39	70×10	●	●	●	●	●	●	●	●	●
M20-8° D39	70×10	●	●	●	●	●	●	●	●	●
M22-8° D43	50×10	●	●	●			●	●	●	●
M24-8° D48	40×10	●	●	●			●	●	●	●
M27-8° D50	40×10	●	●	●			●	●	●	●
M30-8° D58	20×10	●								