

ばね座金(スプリングワッシャー)2号



W1000000

鉄

W1040000

燐青銅

W1020000

ステンレス

W1120000


SUS 316L

W1130000

SUS 310S

W1090000

チタン

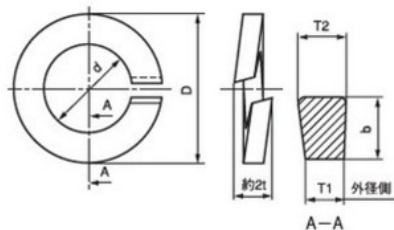

呼び		内径 (d)		外径 (D)	幅 (b)×厚さ (t) (最小)
メートル ねじ用	ウィット ねじ用	基準 寸法	許容差	2号	
2	-	2.1	+0.25 -0	4.4	0.9×0.5
2.3	-	2.4		4.9	1.0×0.6
2.5	-	2.6		5.2	1.0×0.6
2.6	-	2.7	+0.3 0	5.3	1.0×0.6
3	-	3.1		5.9	1.1×0.7
(3.5)	-	3.6		6.6	1.2×0.8
4	-	4.1		7.6	1.4×1.0
5	-	5.1	+0.4 0	9.2	1.7×1.3
6	-	6.1		12.2	2.7×1.5
-	(1/4)	6.5		12.8	2.8×1.6
(7)	-	7.1		13.4	2.8×1.6
8	(5/16)	8.2		15.4	3.2×2.0
-	3/8	9.8	+0.5 0	17.8	3.6×2.4
10	-	10.2		18.4	3.7×2.5
-	(7/16)	11.4		20.2	4.0×2.8
12	-	12.2	+0.6 0	21.5	4.2×3.0
-	1/2	13		22.7	4.4×3.2
(14)	-	14.2		24.5	4.7×3.5
16	5/8	16.2		28	5.2×4.0
(18)	-	18.2	+0.8 0	31	5.7×4.6
-	3/4	19.5		32.7	5.9×4.8
20	-	20.2		33.8	6.1×5.1
(22)	7/8	22.5		37.7	6.8×5.6
24	-	24.5	+1.0 0	40.3	7.1×5.9
-	1"	26		42.8	7.5×6.4
(27)	-	27.5		45.3	7.9×6.8
-	1"1/8	29.3	+1.2 0	47.9	8.3×7.1
30	-	30.5		49.9	8.7×7.5
-	1"1/4	32.5		52.7	9.1×7.9
(33)	-	33.5		54.7	9.5×8.2
-	1"3/8	35.8	+1.4 0	57.8	9.9×8.7
36	-	36.5		59.1	10.2×9.0
(39)	1"1/2	39.5		63.1	10.7×9.5
42	-	42.5		67	10.7×9.5
45	-	46		70	10.7×9.5
48	-	49	+2.0 0	73	10.7×9.5
52	-	53		80	12.0×10
56	-	57		84	12.0×10