

スパック




W1000S00

鉄

W1020S00

ステンレス

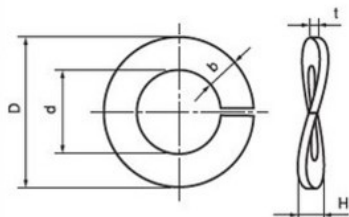

呼び	入り数	鉄					ステンレス	
		マクロ	クロメート	三価ホワイト	ニッケル	亜鉛黒	生地	クロメート
M3	20000×5	●	●	●	●	●	●	●
M3.5	20000×5						●	
M4	10000×5	●	●	●	●	●	●	●
M5	8000×5	●	●	●	●	●	●	●
M6	4000×5	●	●	●	●	●	●	●
M8	2000×5	●	●	●	●	●	●	●
M10	1400×5	●	●	●	●	●	●	●
M12	800×5	●	●	●	●	●	●	●
M14	600×5	●	●	●	●	●	●	●
M16	400×5	●	●	●	●	●	●	●
M18	300×5	●	●	●	●	●	●	●

呼び	内径		断面寸法		外径	高さ
	(d)		巾(b)	厚さ(t)	(D)	(H)
	基本寸法	許容差	基本寸法	基本寸法	約	約
M3	3.1	+0.3 0	1.3	0.7	6.3	1.05
M4	4.1		1.5	0.8	7.7	1.2
M5	5.1		1.8	1.0	9.4	1.5
M6	6.1	+0.4 0	2.5	1.2	11.9	1.8
M8	8.2		3.0	1.6	15.0	2.4
M10	10.2	+0.6 0	3.5	1.8	18.4	2.7
M12	12.2		4.0	2.0	21.6	3.0
M14	14.2	+0.8 0	4.5	2.4	24.6	3.6
M16	16.2		5.0	2.8	27.8	4.2
M18	18.2	+1.0 0	5.5	3.2	30.6	4.6

鉄ばね座金(スプリングワッシャー)
(管用ナット用)東京メタル製

W100000M

鉄

呼び	入り数	生地	マクロ	クロメート	三価ホワイト	ニッケル
M7	7000×8				●	●
M8	5000×10				●	●
M9	5000×10				●	●
M10	4000×10				●	●
M11	3000×10				●	●
M12	3000×10				●	●
M14	2000×10	●	●			●
M15	2000×10					●
M16	2000×10				●	●
M17	2000×10				●	●
M18	1500×10	●				●

鉄ばね座金(スプリングワッシャー)
(管用ナット用)

W100000N

鉄

呼び	入り数	クロメート
M13	1500×10	●