


黄銅 六角ナット(1種)(旧JIS)(切削)



M0010011

黄銅

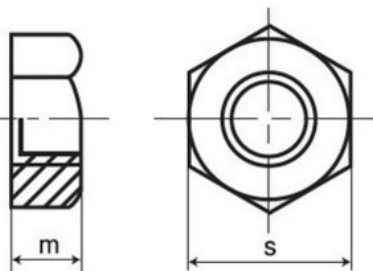

ねじの呼び	ピッチ	s	m
		基準寸法	基準寸法
M3	0.6	6	3
M4	0.75	8	4
M5	0.9	9	4.5
M6	1.0	10	5.5
M8	1.25	14	7

呼び	入り数	生地	ニッケル	クロム
M3(P=0.6)	5000×10	●	●	●
M4(P=0.75)	1500×20	●	●	●
M5(P=0.9)	1500×12	●	●	●
M6(P=1.0)	1000×10	●		
M8(P=1.25)	500×10	●		

六角ナット(1種)(ウィット)



M0000002

鉄

M0080002

S45C(H)

M0020002

ステンレス

M0110002

SUS 316

M0120002

SUS 316L

M0130002


SUS 310S

M0140002

SUS 403

M0060002

アルミ

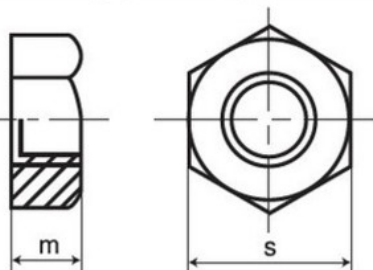

呼び	W 1/8	W 5/32	W 3/16	W 1/4	W 5/16	W 3/8	W 7/16	W 1/2	W 5/8	W 3/4	W 7/8
二面幅 (S)	6	8	8	10	14	17	19	21	26	32	35
高さ (m)	3	4	4	5	6.5	8	9	10	13	16	18
並目(山)	40	32	24	20	18	16	14	12	11	10	9

呼び	W 1"	W 1"1/8	W 1"1/4	W 1"3/8	W 1"1/2	W 1"5/8	W 1"3/4	W 1"7/8	W 2"
二面幅 (S)	41	46	50	54	58	63	67	71	77
高さ (m)	20	22	25	28	30	32	35	38	40
並目(山)	8	7	7	6	6	5	5	4 1/2	4 1/2

呼び	入り数	鉄										S45C(H)					ステンレス		アルミ							
		生地	クロロ	クロメート	ニッケル	ニッケル	クロム	亜鉛黒	パーカー	ドフ	生地	クロロ	クロメート	ニッケル	ニッケル	クロム	亜鉛黒	パーカー	グリーン	生地	特性防錆コート	SUS 316	SUS 316L	SUS 310S	SUS 403	
1/8	3500×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5/32	1500×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
3/16	1000×30																			●						
3/16	1500×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
1/4	1500×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5/16	500×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
3/8	300×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
7/16	200×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
7/16	220×10																									
7/16	220×6																									
1/2	150×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
9/16	100×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5/8	1×800																									
5/8	80×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5/8	80×6																									
3/4	1×400																									
3/4	100×4																									
3/4	40×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
3/4	50×10																									
7/8	1×300	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●