


呼び	入り数	鉄										S45C(H)								ステンレス		アルミ						
		生地	クロメ	クロメト	三橋ホイト	三橋フランク	ニッケル	クロム	亜鉛黒	パーカー	ドブ	生地	クロメ	クロメト	三橋ホイト	三橋フランク	ニッケル	クロム	亜鉛黒	パーカー	グリーン	生地	焼付ホイト	SUS 316	SUS 316L	SUS 310S	SUS 303	SUS 403
7/8	40×8																						●	●	●	●		
7/8	75×4																						●	●				
1"	1×200	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●							
1"	21×10																							●	●	●	●	
1"	50×4																						●	●				
1"1/8	1×140	●	●	●						●	●	●	●	●														
1"1/8	18×10																						●	●	●	●	●	
1"1/4	1×120	●	●	●						●	●	●	●	●														
1"1/4	10×10																						●	●	●	●	●	
1"3/8	1×80	●	●	●																								
1"3/8	8×10																						●	●				●
1"1/2	1×60	●	●	●						●	●	●	●	●									●					
1"1/2	8×10																							●				●
1"5/8	1×80	●																										
1"3/4	1×1	●																										
1"7/8	1×50	●																										
2"	1×20	●																										

六角ナット(1種)(ウィット)(切削)



- M0010012 黄銅
- M0020012 ステンレス
- M0090012 チタン

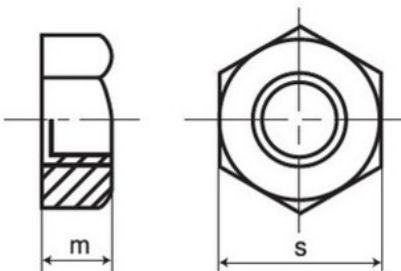

呼び	W 1/8	W 5/32	W 3/16	W 1/4	W 5/16	W 3/8	W 7/16	W 1/2
二面幅 (S)	6	8	8	10	14	17	19	21
高さ (m)	3	4	4	5	6.5	8	9	10
並目(山)	40	32	24	20	18	16	14	12

呼び	W 5/8	W 3/4	W 7/8	W 1"
二面幅 (S)	26	32	35	41
高さ (m)	13	16	18	20
並目(山)	11	10	9	8

呼び	入り数	黄銅	ステンレス	チタン
1/8	2000×30		●	
1/8	5000×12	●		
5/32	4000×12	●		
3/16	1500×12	●		
1/4	1000×13	●		
5/16	400×12	●		
3/8	150×24	●		
3/8	500×1			●
7/16	150×10	●		
7/16	220×10		●	
1/2	100×18	●		
5/8	100×10	●		
3/4	50×10		●	
3/4	75×10	●		
7/8	36×10	●		
1"	27×10	●		
1"1/8	18×6		●	
1"1/8	25×10	●		
1"1/4	25×10	●		

小ねじ
 マフクロねじ
 組込みねじ
 タツピンねじ
 タツタイド
 ハイエタねじ
 いたすら防止ねじ
 建材用スクリーン
 ボルト
 キャップボルト
 ドリルねじ
 座金
 つまみねじ
 ナット
 樹脂製品
 アンカーボルト