

鉄 六角ナット(2種)(左ねじ)



M0000108

鉄

呼び	入り数	生地	ユアロ	クロメート	三価ホウ酸	三価フッ素	ニッケル	クロム	亜鉛黒	パーカー	グリーン
M3	10000×8			●							
M4	5000×8	●	●	●	●	●	●	●	●	●	●
M5	3000×10	●	●	●	●	●	●	●	●	●	●
M6	1500×8	●	●	●	●	●	●	●	●	●	●
M12	200×10	●	●	●	●	●	●	●	●	●	●

六角ナット(3種)



M0000200

鉄

M0080200

S45C(H)

M0010200

黄銅

M0020200

ステンレス

M0110200

SUS 316

M0120200

SUS 316L

M0130200



SUS 310S

M0140200

SUS 403

M0090200

チタン

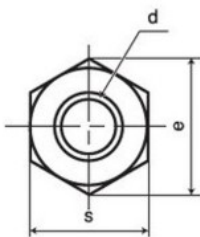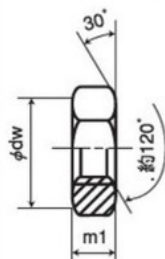

ねじの呼び d	ピッチ 並目 P	m1		s		e 約	dw 約
		基準 寸法	許容差	基準 寸法	許容差		
M2	0.4	1.2	0 -0.25	4	0 -0.2	4.6	3.8
M2.3	0.4	1.4		4.5		5.2	4.3
M2.5	0.45	1.6		5		5.8	4.7
M2.6	0.45	1.6		5		5.8	4.7
M3	0.5	1.8		5.5		6.4	5.3
M3.5	0.6	2		6		6.9	5.8
M4	0.7	2.4		7		8.1	6.8
M4.5	0.75	2.8		8		9.2	7.8
M5	0.8	3.2		8		9.2	7.8
M6	1.0	3.6	0 -0.48	10	0 -0.6	11.5	9.8
M7	1.0	4.2		11	12.7	10.8	
M8	1.25	5		13	0 -0.7	15	12.5
M10	1.5	6	17	19.6	16.5		
M12	1.8	7	0 -0.58	19	0 -0.8	21.9	18
M14	2.0	8		22		25.4	21
M16	2.0	10		24		27.7	23
M18	2.5	11	0 -0.70	27	0 -1.0	31.2	26
M20	2.5	12		30		34.6	29
M22	2.5	13		32		37	31
M24	3.0	14		36		41.6	34
M27	3.0	16	0 -0.84	41	0 -1.2	47.3	39
M30	3.5	18		46		53.1	44
M33	3.5	20		50		57.7	48
M36	4.0	21	0 -1.0	55	0 -1.4	63.5	53
M39	4.0	23		60		69.3	57
M42	4.5	25		65		75	62
M45	4.5	27		70		80.8	67
M48	5.0	29	0 -1.0	75	0 -1.4	86.5	72
M52	5.0	31		80		92.4	77
M56	5.5	34		85		98.1	82
M60	5.5	36		90		104	87
M64	6.0	38	0 -1.0	95	0 -1.4	110	92
M68	6.0	40		100		115	97