

六角ナット(ユニファイ)(UNC)



M0000030


鉄

M0020030

ステンレス

単位:mm

呼び (d)	S		m
	基準 寸法	スパナ サイズ	基準 寸法
#2-56	4.7	3/16	1.6
#4-40	6.3	1/4	2.4
#5-40	8	5/16	2.8
#6-32	8	5/16	2.8
#8-32	8.7	11/32	3.3
#10-24	9.5	3/8	3.3
1/4-20	11.1	7/16	5.7
5/16-18	12.7	1/2	6.9
3/8-16	14.2	9/16	8.5
7/16-14	17.4	11/16	9.5
1/2-13	19	3/4	11.3
9/16-12	22.2	7/8	12.5
5/8-11	23.8	15/16	14.1
3/4-10	28.6	1-1/8	16.8
7/8-9	33.3	1-5/16	19.7

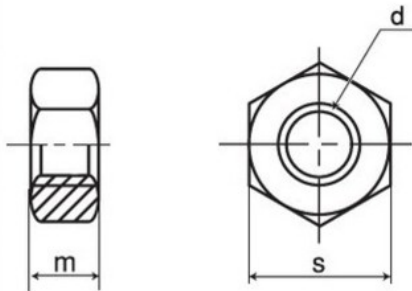

呼び	入り数	鉄										ステンレス A2-70
		生地	クロロ	クロメート	三価ホウ酸	三価フッ素	ニッケル	クロム	亜鉛黒	パーカー	グリーン	
NO.2-56	100×33	●										
NO.2-56	5000×20											●
NO.4-40	100×1				●							
NO.4-40	2000×20											●
NO.5-40	1000×20											●
NO.6-32	100×33	●										
NO.6-32	1000×20											●
NO.8-32	100×33	●										
NO.8-32	1000×20											●
NO.10-24	100×33				●							
NO.10-24	2000×10											●
NO.12-24	1500×1											●
1/4-20	1000×10											●
1/4-20	1200×10	●	●	●	●	●	●	●	●	●	●	
5/16-18	600×10											●
5/16-18	700×10	●	●	●	●	●	●	●	●	●	●	
3/8-16	400×8											●
3/8-16	500×10	●	●	●	●	●	●	●	●	●	●	
7/16-14	200×10											●
7/16-14	250×10	●	●	●	●	●	●	●	●	●	●	
1/2-13	200×10	●	●	●	●	●	●	●	●	●	●	
1/2-13	200×8											●
9/16-12	100×1											●
5/8-11	100×1											●
3/4-10	50×1											●
7/8-9	50×1											●