


鉄 T型溶接ナット (2A)(パイロット付 ダボ無) 太田プレス製



N0000482


鉄

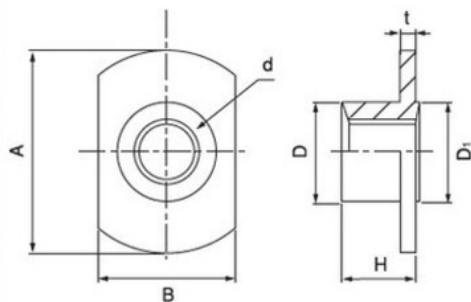

呼び径 (d)	ピッチ	A		B		D		H		D1		t	
		基準 寸法	許容差	基準 寸法	許容差	基準 寸法	許容差	基準 寸法	許容差	基準 寸法	許容差	基準 寸法	許容差
M4	0.7	18	±0.5	9	±0.3	6.2	+0.5 -0	4.1	±0.4	6	-0.1 -0.3	1.6	±0.2
M5	0.8	18		10		6.2		4.1		7		1.6	
M6	1	21		12		8		5		8		1.8	
M8	1.25	23	±1.0	14	±0.3	9.5	+0.5 -0	6.7	±0.4	10	-0.1 -0.3	2.2	
M10	1.5	30		19		12.7		8.8		12		2.3	
M12	1.75	28		21		15		14		14		3.0	


呼び	入り数	生地	コクロ	クロメイト	三価ホワイト	三価ブラック	ニッケル	亜鉛黒
M4	700×14	●	●	●	●	●	●	●
M5	700×14	●	●	●	●	●	●	●
M6	400×14	●	●	●	●	●	●	●
M8	250×14	●	●	●	●	●	●	●
M10	150×10	●	●	●	●	●	●	●
M12	150×8	●	●	●	●	●	●	●

 鉄 T型溶接ナット (1B)(パイロット無 ダボ付) 太田プレス製



N0000483

鉄

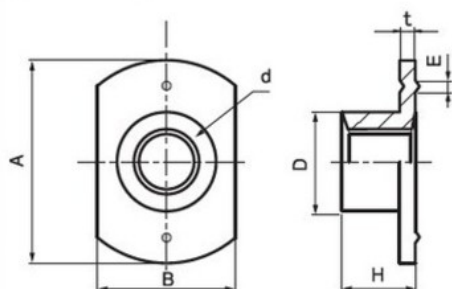

呼び径 (d)	ピッチ	A		B		D		H		E		t	
		基準 寸法	許容差	基準 寸法	許容差	基準 寸法	許容差	基準 寸法	許容差	基準 寸法	許容差	基準 寸法	許容差
M4	0.7	18	±0.5	9	±0.3	6.2	+0.5 -0	5.4	±0.4	3	±0.2	1.6	±0.2
M5	0.8	18		10		6.2		5.4		3		1.6	
M6	1	21		12		8		6		3		1.8	
M8	1.25	23	±1.0	14	±0.3	9.5	+0.5 -0	8.7	±0.4	3.5	±0.2	2.2	
M10	1.5	30		19		12.7		10.3		3.5		2.3	

呼び	入り数	生地	コクロ	クロメイト	三価ホワイト	三価ブラック	ニッケル	亜鉛黒
M4	700×14	●	●	●	●	●	●	●
M5	700×14	●	●	●	●	●	●	●
M6	400×14	●	●	●	●	●	●	●
M8	250×14	●	●	●	●	●	●	●
M10	150×10	●	●	●	●	●	●	●