

高ナット(ウィット)



小ねじ

マフクロねじ

組込みねじ

タツピンねじ

タツタイト・
ハイテックねじ

いたすら防止ねじ

建材用スクリー

ボルト

キャップホー

ドリルねじ

座金

つまみねじ

ナット

樹脂製品



アンカーボルト

N0000H12

鉄

N0020H12

ステンレス

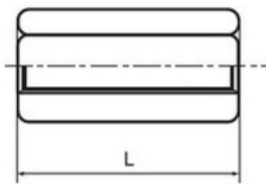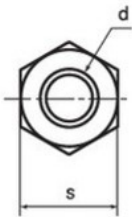

ねじの 呼び (d)	ねじ山 ／ インチ	基準 寸法 S
5/16	18	12
3/8	16	14
1/2	12	19
5/8	11	23
3/4	10	26
7/8	9	35
1"	8	41

呼び	入り数	鉄										ステンレス		
		生地	クロメート	三価クロム	ニッケル	亜鉛黒	ドブ	グリーン	生地	G619	G619	G619	生地	G619
5/16×12×20	250×10	●												
5/16×12×20	300×8	●												
5/16×12×25	200×10													
5/16×12×25	250×8	●												
5/16×12×30	170×10	●												
5/16×12×30	200×8	●												
5/16×12×35	180×8	●												
5/16×12×40	120×10	●												
5/16×12×50	100×10	●												
3/8×14×20	170×10													
3/8×14×20	200×10													
3/8×14×20	220×8	●												
3/8×14×25	130×10	●												
3/8×14×25	175×8													
3/8×14×25	180×8													
3/8×14×30	120×10													
3/8×14×30	150×8	●												
3/8×14×35	100×10	●												
3/8×14×35	125×8													
3/8×14×40	100×8	●												
3/8×14×40	110×8													
3/8×14×40	90×10													
3/8×14×50	60×10													
3/8×14×50	70×10	●												
3/8×14×50	80×8	●												
3/8×14×60	60×8	●												
3/8×14×70	50×8	●												
3/8×14×80	50×8	●												
1/2×19×20	100×10													
1/2×19×20	125×8	●												
1/2×19×25	100×8	●												
1/2×19×25	70×10													
1/2×19×25	80×10													
1/2×19×30	60×10													
1/2×19×30	70×10	●												
1/2×19×30	80×8	●												
1/2×19×35	50×10													
1/2×19×35	60×10	●												
1/2×19×35	70×8	●												
1/2×19×40	45×10													
1/2×19×40	50×10	●												
1/2×19×40	60×8													
1/2×19×45	40×10													
1/2×19×50	40×10													

呼び	入り数	鉄										ステンレス		
		生地	クロメート	三価クロム	ニッケル	亜鉛黒	ドブ	グリーン	生地	G619	G619	G619	生地	G619
1/2×19×50	45×8	●												
1/2×19×60	35×10	●												
1/2×19×60	40×8													
1/2×19×70	30×10	●												
1/2×19×80	25×10	●												
5/8×23×25	130×4	●												
5/8×26×25	50×8													
5/8×26×30	40×10	●												
5/8×23×35	35×10	●												
5/8×26×35	40×9													
5/8×23×40	35×10	●												
5/8×26×40	40×8													
5/8×26×45	30×9													
5/8×26×50	20×10													
5/8×23×50	25×10	●												
5/8×26×60	20×8	●												
5/8×23×70	1×200	●												
5/8×23×80	1×150	●												
3/4×32×30	24×10													
3/4×26×30	90×4	●												
3/4×32×35	24×8													
3/4×26×35	95×4	●												
3/4×32×40	24×8													
3/4×26×40	60×4	●												
3/4×32×45	16×10													
3/4×32×50	12×10													
3/4×26×50	60×4	●												
3/4×32×60	12×10													
3/4×26×60	50×4	●												
3/4×26×70	45×4	●												
3/4×26×80	40×4	●												
7/8×35×35	20×9													
7/8×35×40	20×8													
7/8×35×45	16×9													
7/8×35×50	10×10													
7/8×35×55	10×10													
7/8×35×60	10×10													
1"X41×30	15×10													
1"X41×40	12×8													
1"X41×50	12×8													
1"X41×60	8×10													