
 


# 鉄 高ナット (平径大・ウィット)

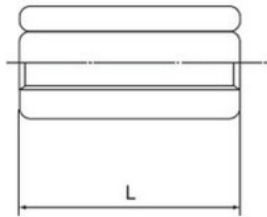

N0000H02

鉄



| ねじの呼び<br>d | ねじ山<br>/<br>インチ | 基準<br>寸法<br>s |
|------------|-----------------|---------------|
| W1/4       | 20              | 10            |
| W5/16      | 18              | 14            |
| W3/8       | 16              | 17            |
| W1/2       | 13              | 21            |
| W5/8       | 11              | 26            |
| W3/4       | 10              | 32            |
| W7/8       | 9               | 35            |
| W1"        | 8               | 41            |

| 呼び         | 入り数   | 生地 | クロロ | クロメート | 三価ホウ酸 | 三価フッ素 | ニッケル | 亜鉛黒 | ドブ | グリーン | 呼び        | 入り数   | 生地 | クロロ | クロメート | 三価ホウ酸 | 三価フッ素 | ニッケル | 亜鉛黒 | ドブ | グリーン |   |   |   |   |
|------------|-------|----|-----|-------|-------|-------|------|-----|----|------|-----------|-------|----|-----|-------|-------|-------|------|-----|----|------|---|---|---|---|
| 1/4×10×20  | 400×8 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 5/8×26×20 | 70×8  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● |   |   |   |
| 1/4×10×25  | 350×8 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 5/8×26×25 | 50×8  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● |   |   |
| 1/4×10×30  | 250×8 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 5/8×26×30 | 40×8  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● |   |
| 1/4×10×35  | 200×8 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 5/8×26×35 | 35×8  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 1/4×10×40  | 200×8 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 5/8×26×40 | 30×8  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 1/4×10×50  | 160×8 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 5/8×26×50 | 25×8  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 5/16×14×20 | 225×8 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 5/8×26×60 | 15×10 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 5/16×14×25 | 175×8 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 5/8×26×70 | 1×150 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 5/16×14×30 | 150×8 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 5/8×26×80 | 1×120 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 5/16×14×35 | 125×8 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 3/4×32×25 | 30×8  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 5/16×14×40 | 110×8 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 3/4×32×30 | 25×8  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 5/16×14×50 | 85×8  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 3/4×32×35 | 20×8  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 3/8×17×20  | 150×8 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 3/4×32×40 | 20×8  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 3/8×17×25  | 120×8 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 3/4×32×50 | 15×8  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 3/8×17×30  | 80×10 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 3/4×32×60 | 15×8  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 3/8×17×35  | 85×8  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 3/4×32×70 | 1×100 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 3/8×17×40  | 70×8  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 3/4×32×80 | 1×80  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 3/8×17×50  | 50×8  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 7/8×35×30 | 20×8  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 3/8×17×60  | 50×8  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 7/8×35×35 | 20×8  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 3/8×17×70  | 1×320 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 7/8×35×40 | 1×150 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 3/8×17×80  | 1×300 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 7/8×35×50 | 1×100 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 1/2×21×20  | 80×10 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 7/8×35×60 | 1×80  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 1/2×21×25  | 80×8  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 7/8×35×70 | 1×80  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 1/2×21×30  | 60×8  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 7/8×35×80 | 1×60  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 1/2×21×35  | 45×10 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 1"X41×35  | 1×100 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 1/2×21×40  | 50×8  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 1"X41×40  | 1×100 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 1/2×21×50  | 35×8  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 1"X41×50  | 1×80  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 1/2×21×60  | 20×10 | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 1"X41×60  | 1×70  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 1/2×21×70  | 35×8  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 1"X41×70  | 1×60  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |
| 1/2×21×80  | 25×8  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | 1"X41×80  | 1×50  | ●  | ●   | ●     | ●     | ●     | ●    | ●   | ●  | ●    | ● | ● | ● | ● |