


ピーク 六角穴付きボルト(キャップスクリュー)



K000A200

樹脂

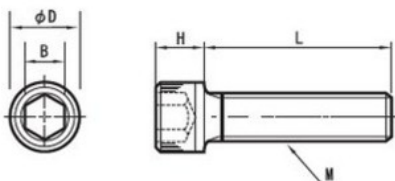

サイズ	D	H	B
M3	5.5	3.0	2.5
M4	7.0	4.0	3.0
M5	8.5	5.0	4.0
M6	10.0	6.0	5.0
M8	13.0	8.0	6.0
M10	16.0	10.0	8.0
M12	18.0	12.0	10.0


M3.0			M4.0			M5.0			M6.0			M8.0			M10.0			M12.0		
長さ	入り数	生地	長さ	入り数	生地	長さ	入り数	生地	長さ	入り数	生地	長さ	入り数	生地	長さ	入り数	生地	長さ	入り数	生地
6	100×20	●	6	100×20	●	6	100×20	●	10	100×20	●	10	100×14	●	15	50×14	●	20	50×14	●
8	100×20	●	8	100×20	●	8	100×20	●	12	100×20	●	12	100×14	●	20	50×14	●	25	50×14	●
10	100×20	●	10	100×20	●	10	100×20	●	15	100×20	●	15	100×14	●	25	50×14	●	30	50×14	●
12	100×20	●	12	100×20	●	12	100×20	●	20	100×20	●	20	100×14	●	30	50×14	●	35	50×14	●
15	100×20	●	15	100×20	●	15	100×20	●	25	100×20	●	25	100×14	●	35	50×14	●	40	50×14	●
20	100×20	●	20	100×20	●	20	100×20	●	30	100×20	●	30	100×14	●	40	50×14	●			
50	50×20	●	25	100×20	●	25	100×20	●	35	100×20	●	35	100×14	●	100	50×10	●			
			30	100×20	●	30	100×20	●	40	100×20	●	40	100×10	●						
			40	100×20	●	100	50×14	●	100	50×10	●									
			100	50×14	●															

ピーク六角ホーローセット



K000A250

樹脂

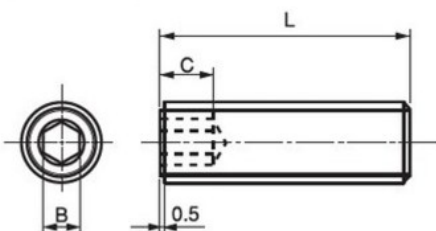

呼び径	M3	M4	M5	M6	M8
ピッチ	0.5	0.7	0.8	1.0	1.25
B	1.5	2	2.5	3	4
C	2	2.5	3	3.5	5

M3.0			M4.0			M5.0			M6.0			M8.0		
長さ	入り数	生地	長さ	入り数	生地	長さ	入り数	生地	長さ	入り数	生地	長さ	入り数	生地
4	100×20	●	5	100×20	●	5	100×20	●	6	100×20	●	10	100×14	●
5	100×20	●	6	100×20	●	6	100×20	●	8	100×20	●	12	100×14	●
6	100×20	●	8	100×20	●	8	100×20	●	10	100×20	●	15	100×14	●
8	100×20	●	10	100×20	●	10	100×20	●	12	100×20	●	20	100×14	●
10	100×20	●	12	100×20	●	12	100×20	●	15	100×20	●	25	100×14	●
12	100×20	●	15	100×20	●	15	100×20	●	20	100×20	●	30	100×14	●
15	100×20	●	20	100×20	●	20	100×20	●	25	100×20	●			

ピーク テーパープラグ



K000A280

樹脂

呼び	入り数	生地
R1/8(シズミ)	100×14	●
R1/4(シズミ)	100×14	●
R3/8(シズミ)	100×14	●