


# ポリアセタール スペーサー



K0005000

樹脂

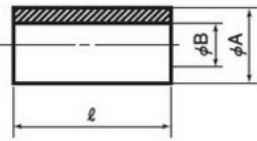

	2	2.6	3	4	5
B	2.1	2.7	3.2	4.3	5.3
A	4	5	6	8	9

呼び	入り数	生地	呼び	入り数	生地	呼び	入り数	生地
2×4×3	1000×20	●	3×6×3	1000×20	●	4×8×8	1000×14	●
2×4×4	1000×20	●	3×6×4	1000×20	●	4×8×10	500×14	●
2×4×5	1000×20	●	3×6×5	1000×20	●	4×8×12	500×14	●
2×4×6	1000×20	●	3×6×6	1000×20	●	4×8×15	500×14	●
2×4×8	1000×20	●	3×6×7	1000×20	●	4×8×18	500×10	●
2×4×10	1000×20	●	3×6×8	1000×20	●	4×8×20	250×14	●
2×4×12	1000×20	●	3×6×10	1000×14	●	4×8×25	250×14	●
2×4×15	1000×20	●	3×6×11	1000×14	●	4×8×30	250×10	●
2×4×20	500×20	●	3×6×12	1000×14	●	4×8×35	200×10	●
2×4×25	500×20	●	3×6×13	1000×10	●	4×8×40	200×10	●
2×4×30	500×20	●	3×6×14	1000×10	●	4×8×45	100×14	●
2×4×40	500×20	●	3×6×15	1000×10	●	4×8×50	100×14	●
2×4×50	250×20	●	3×6×16	500×14	●	5×9×4	1000×20	●
2.6×5×3	1000×20	●	3×6×17	500×14	●	5×9×5	1000×14	●
2.6×5×4	1000×20	●	3×6×18	500×14	●	5×9×6	1000×14	●
2.6×5×5	1000×20	●	3×6×20	500×14	●	5×9×8	500×14	●
2.6×5×6	1000×20	●	3×6×25	500×10	●	5×9×10	500×14	●
2.6×5×8	1000×20	●	3×6×30	500×10	●	5×9×12	500×14	●
2.6×5×10	1000×20	●	3×6×35	250×14	●	5×9×15	500×10	●
2.6×5×12	1000×20	●	3×6×40	250×14	●	5×9×20	250×14	●
2.6×5×15	1000×20	●	3×6×45	200×14	●	5×9×25	250×10	●
2.6×5×20	500×20	●	3×6×50	200×14	●	5×9×30	200×10	●
2.6×5×25	500×20	●	4×8×4	1000×14	●	5×9×35	100×14	●
2.6×5×30	500×20	●	4×8×5	1000×14	●	5×9×40	100×14	●
2.6×5×40	500×20	●	4×8×6	1000×14	●	5×9×45	100×14	●
2.6×5×50	250×20	●	4×8×7	1000×14	●	5×9×50	100×10	●

# アセタール樹脂 E型止め輪



K000EC00

樹脂

呼び	入り数	生地
JRE2.5	2000×20	●
JRE3	2000×20	●
JRE4	2000×20	●
JRE5	2000×20	●
JRE6	2000×14	●
JRE7	2000×20	●